


REV.	DATE	DESCRIPTION	ECO	BY	C'K'D.
C	11/06/17	FORMAT CHANGE	47985	JP	MB

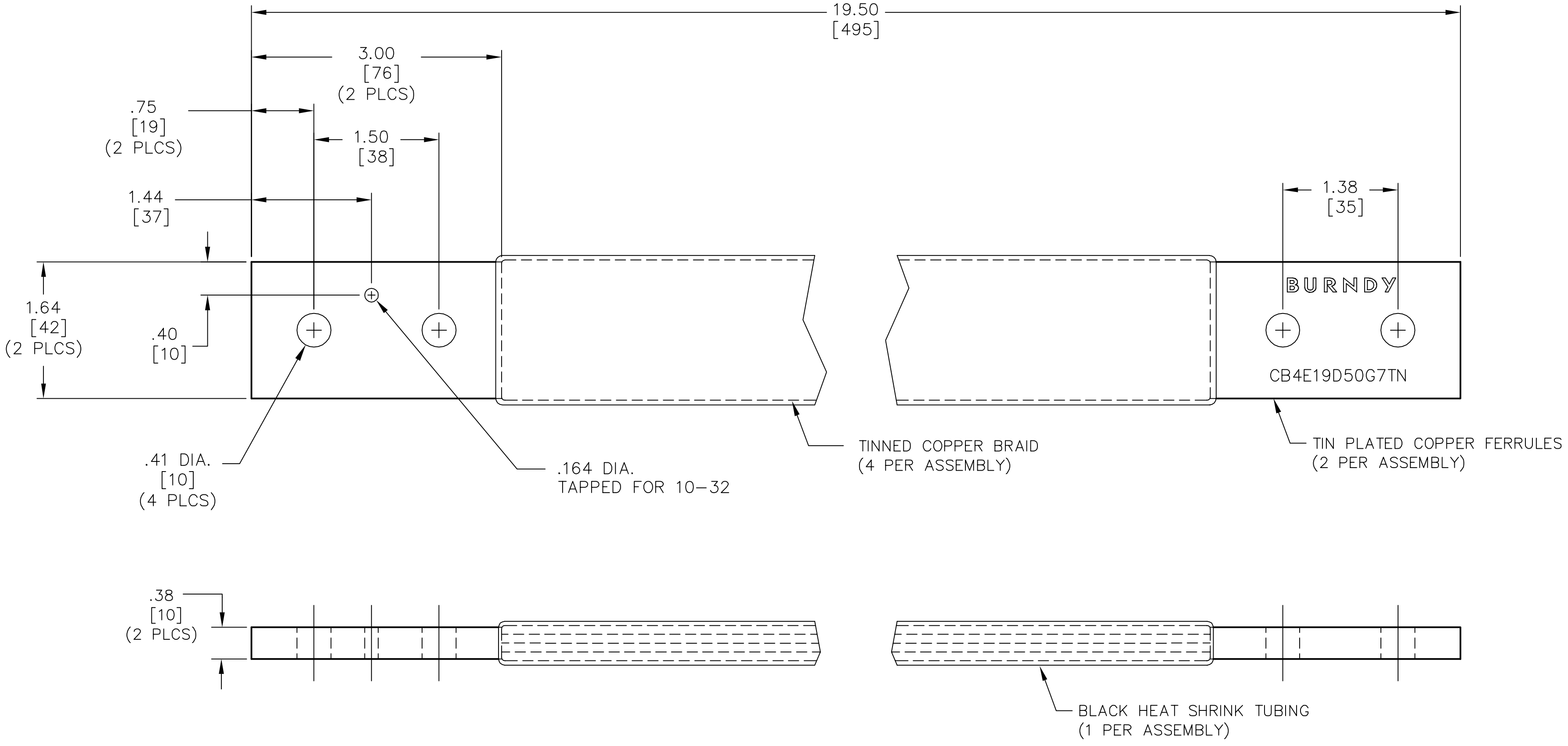

NOTES:

- APPROXIMATE AMP RATING: 800 A. THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID, AND OTHER SERVICE CONDITIONS.
- DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.
- REFERENCE CUSTOMER NUMBER 25-25863-4.

TO ORDER BURNDY® PRODUCTS CALL		BRAID	
UNITED STATES:		ITEM NO: 10034676	
1-800-346-4175 (LONDONDERRY, NH)		CAT NO: CB4E19D50G7TN	
CANADA:		SCALE: 1/1	
1-800-361-6975 (QUEBEC)		DRAWN BY: P LAPONIUS 9/29/03	
1-800-387-6487 (ALL OTHER PROVINCES)		CHECKER: J MICHAUD 9/29/03	
FOR PRODUCT INFO: http://www.burndy.com		DSN APPVL: J MICHAUD 9/29/03	
		MFG APPVL: --	
		QC APPVL: J BRODEUR 9/29/03	
		MKT APPVL: D HAMILTON 9/29/03	
		PROD FAM: --	
		PROJECT #: --	
		SIZE: C	
		DRAWING NO: 10034686	
		REV: C	
		DOCUMENT TYPE: Sales	
		REL LEVEL: Released	
		SHEET 1 of 1	