


CATALOG NUMBER	ITEM NUMBER	LENGTH 'L'
B2F36N1TN	10057489	36.00 [914]
B2F72N1TN	10057488	72.00 [1829]
B2F12D25N1TN	50063265	12.25 [311]

REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
B	8/27/2015	DRAWING RELEASED	41353	MS	MB

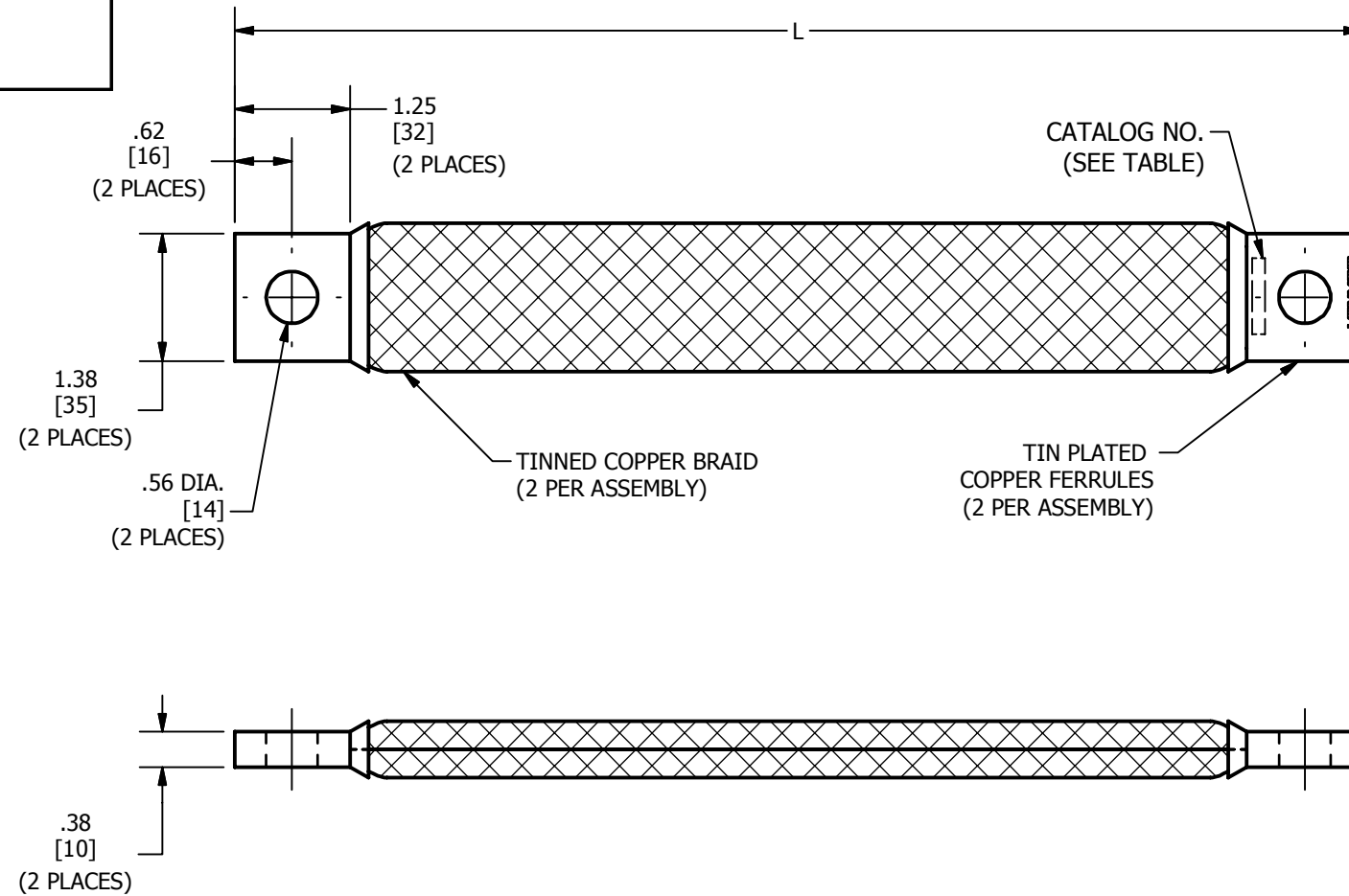

NOTES:

- APPROXIMATE AMP RATING: 600A INDOOR, 720A OUTDOOR. THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID, AND OTHER SERVICE CONDITIONS.
- DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.

TO ORDER BURNDY® PRODUCTS CALL		BRAID, FLEXIBLE	
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: SEE TABLE	
CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)		CAT. NO: SEE TABLE	
FOR PRODUCT INFO: http://www.burndy.com		DRAWN BY: D.BOISVERT 7/26/2005	
		CHECKER: J.MICHAUD 7/26/2005	
		DSN APRVL: J.MICHAUD 7/26/2005	
		MFG APRVL: --	
		QA APRVL: J.BRODUER 7/26/2005	
		MKT APRVL: D.HAMILTON 7/26/2005	
PROD FAM: MECHANICAL GROUNDING	DRAWING NO	REV	
PROJECT #: --	SIZE	10058604	B
DOCUMENT TYPE: SALES	REL LEVEL: Released	B	SHEET 1 OF 1