


CATALOG NO.	GE CATALOG NO	LENGTH(L)
BE7G155TN	391A9445P001	7.00" [178]
BE12G155TN	391A9445P001EB	12.00" [305]
BE18G155TN	391A9445P001EC	18.00" [457]
BE24G155TN	391A9445P001ED	24.00" [610]
BE36G155TN	391A9445P001EE	36.00" [914]

REV	DATE	DESCRIPTION	ECO	BY	CHK.
C	11/09/2018	FPN1811001	50230	BK	VS

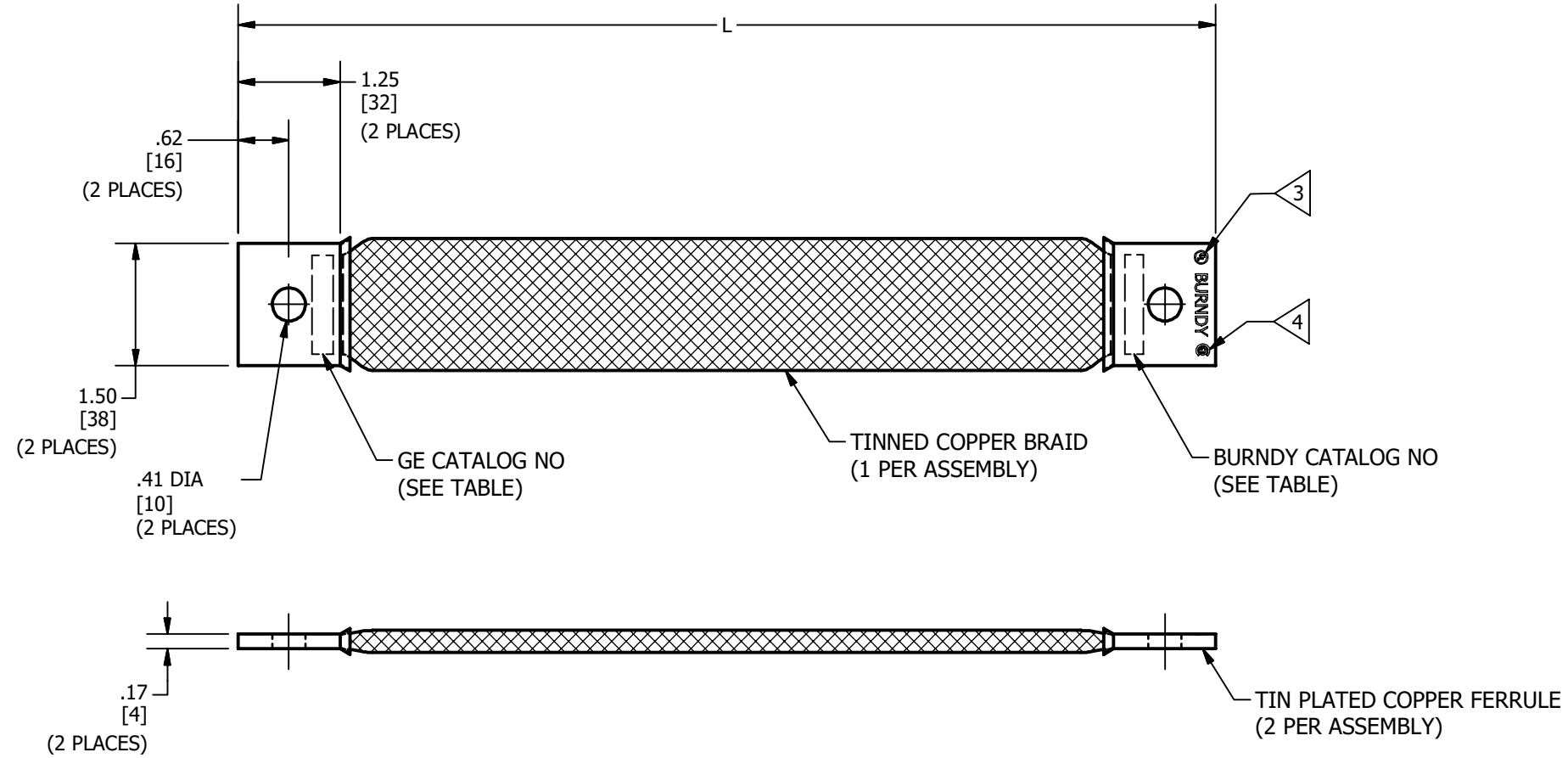

NOTES:

1. APPROXIMATE AMP RATING: 340A INDOOR, 405A OUTDOOR. THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID, AND OTHER SERVICE CONDITIONS.

2. DIMENSIONS IN BRACKETS [ ] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.

3 ALL SIZES ARE LISTED TO UL 467 GROUNDING & BONDING EQUIPMENT STANDARDS.

4 ALL SIZES ARE LISTED TO CSA 22.2 NO.41 GROUNDING & BONDING EQUIPMENT STANDARDS.

TO ORDER BURNDY PRODUCTS CALL

UNITED STATES  
1-800-346-4175 (LONDONDERRY, NH)

CANADA:  
1-800-361-6975 (QUEBEC)  
1-800-387-6487 (ALL OTHER PROVINCES)

FOR PRODUCT INFO: <http://www.burndy.com>

BRAID, FLEXIBLE

ITEM NO: - -

CAT. NO: SEE TABLE

DRAWN BY: R. BOISVERT 02/07/2006

CHECKER: P. LAPONIUS 02/06/2006

DSN APRVL: R. BOISVERT 12/30/1899

MFG APRVL: -- 12/30/1899

QA APRVL: -- 12/30/1899

MKT APRVL: 12/30/1899



PROD FAM: BRAID

PROJECT #: FPN1811001

DOCUMENT TYPE: SALES

REL LEVEL: Released

DRAWING NO

10065812

SIZE

B

SHEET 1 OF 1

REV

C