
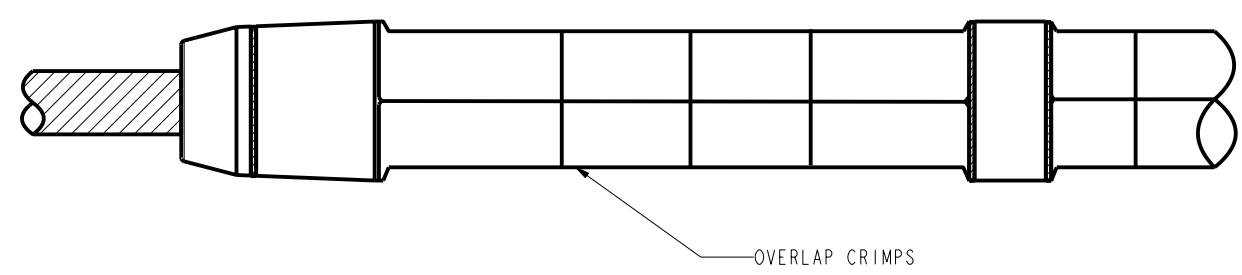


DRAWING NO.
10097739

CONDUCTOR ACSS	ITEM NUMBER	CATALOG NUMBER	L	O.D.	INSTALLATION TOOLING BURNDY HYPRESS & DIE SET	
					DIE INDEX	DIE FOR PRESS Y60B
300-336.4 Kcmil ACSS		YNS32RTHT	16.96 [430.8]	1.19 [30.2]	717	L717
397.5 Kcmil ACSS		YNS34RTHT	17.10 [434.3]	1.30 [33.0]	719	L719
477 Kcmil ACSS		YNS36RTHT	17.64 [448.0]	1.41 [35.7]	720	L720
556.5 Kcmil ACSS		YNS39RTHT	18.26 [463.8]	1.50 [38.1]	722	L722
605-666.6 Kcmil ACSS		YNS43RTHT	18.48 [469.4]	1.61 [40.9]	724	L724
715.5-874.5 Kcmil ACSS	10094236	YNS451RTHT	18.60 [472.4]	1.80 [45.7]	725	L725
900-1113 Kcmil ACSS		YNS49RTHT	18.66 [474.0]	1.97 [50.0]	727	L727
1192.5-1351 Kcmil ACSS		YNS52RTHT	24.20 [614.7]	2.25 [57.2]	728	L728
1431 Kcmil ACSS		YNS54RTHT	24.11 [612.4]	2.25 [57.2]	728	L728
1510.5-1590 Kcmil ACSS		YNS56RTHT	23.58 [598.9]	2.50 [63.5]	729	L729
1780 Kcmil ACSS		YNS58RTHT	23.40 [595.9]	2.50 [63.5]	735	L735
2156-2167 Kcmil ACSS		YNS59RTHT	23.14 [587.8]	2.50 [63.5]	735	L735

REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
A	3/31/2009 12:00:00 AM	NEW DRAWINGS FOR ACSS LOOP SPLICE AND FULL TENSION SPLICE KIT	17679	BT	BSK

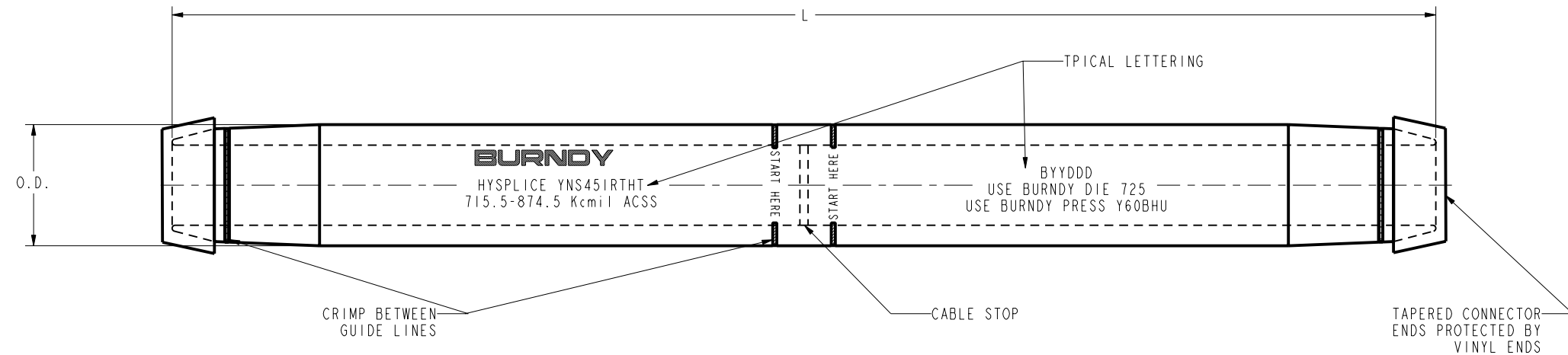

NOTES:

1. MATERIAL: ALUMINIUM ALLOY NO-OX-ID COATED.
2. CONNECTOR IS INDIVIDUALLY PACKAGED & SEALED IN A POLYBAG. THE TAPERED CONNECTOR ENDS ARE PROTECTED BY VINYL CAPS.
3. PENETROX™ PENHT IS REQUIRED FOR INSTALLATION. PENHT IS NOT INCLUDED AND IS PURCHASED SEPARATELY.
4. INSTALLATION TOOLING IS NOT INCLUDED AND IS PURCHASED SEPARATELY.
5. INSTALLATION INSTRUCTION IS DRAWING 10098338.
6. FLASH FORMED DURING CRIMPING SHOULD BE REMOVED BY FILING & SHARP EDGES ROUNDED OFF. THE BARREL PORTION OF THIS CONNECTOR WILL OPERATE QUIETER THAN THE CONDUCTOR AT EXTRA HIGH VOLTAGES.
7. DIMENSIONS IN BRACKETS [] ARE METRIC UNITS [SI UNITS] AND ARE ROUNDED TO THE NEAREST WHOLE NUMBER. UNLESS OTHERWISE SPECIFIED THESE UNITS SHALL BE USED FOR REFERENCE ONLY.

TO ORDER BURNDY® PRODUCTS CALL		LOOP HYSPLICE™ >230KV	
UNITED STATES		ITEM NO: SEE TABLE	
1-800-346-4175 (LONDONDERRY, NH)		CAT. NO: SEE TABLE	
CANADA:		DRAWN BY: BSB 03/30/2009	
1-800-361-6975 (QUEBEC)		CHECKER: --	
1-800-387-6487 (ALL OTHER PROVINCES)		DSN APPVL: --	
FOR PRODUCT INFO: http://www.burndy.com		MFG APPVL: --	
		QA APPVL: --	
		MKT APPVL: --	SCALE: 1:2
		PROJ #: --	DRAWING NO
		DOCUMENT TYPE: Sales	10097739
		REL LEVEL: Released	SHEET 1 OF 1
		SIZE	A
		D	

REV: PE0200