

\*\*\* BILL OF MATERIAL \*\*\*

PT NO.	CATALOG NO.	QTY	DESCRIPTION
1	PATCASELI	1	CASE, TOOL PATRIOT® LITHIUM-ION
2	BATI8VLI	2	BATTERY, LITHIUM ION 18V
3	LIMSDS	1	MSDS, LITHIUM ION BATTERY
4	PATCHGRLI	1	CHARGER, BATTERY LITHIUM ION
5	BATCHGRLIOMI	1	BATTERY CHARGER SAFETY OPERATING MAINTENANCE & INSTRUCTIONS
6	PT208620	1	LANYARD
7	PAT750LIOMI	1	SOMI, PAT750-LI
8	PT2044380I	1	FIVE YEAR WARRANTY CARD

CATALOG NUMBER	DESCRIPTION	CHARGER CATALOG NO.
PAT750-LI	PATRIOT 750 WITH 120V CHARGER	PATCHGRLI
PAT750LINIST	PATRIOT®750 WITH NIST CERTIFICATION	PATCHGRLI
PAT750-LIDC	PATRIOT®750 WITH 12V DC CHARGER	PATCHGRLIDC
PAT750C-LI	PATRIOT®750 (COVERED HEAD) WITH 120V CHARGER	PATCHGRLI
PAT750C-LIDC	PATRIOT®750 (COVERED HEAD) WITH 12V DC CHARGER	PATCHGRLIDC
PAT750-LI250V	PATRIOT®750 WITH 250V CHARGER	PATCHGRLI250V

PATRIOT®

BATTERY ACTUATED TOOL - HYDRAULIC SELF CONTAINED - 12 TON OUTPUT FORCE

SPECIFICATIONS

- CRIMP FORCE: 12 TONS (10.9 METRIC TONS)
- TOOL WEIGHT: 15.7 LBS (7.1 kg)
- LENGTH: 15.75 (40.00 cm)
- WIDTH: 3.50 (8.89 cm)
- HEIGHT: 13.50 (34.29 cm)
- OPERATING VOLTAGE: 18V-DC
- RECHARGE TIME: 30 MINUTES
- RAM OPENING: MINIMUM 1.653 (42 mm)


FEATURES AND BENEFITS

- REFINED HYDRAULIC SYSTEM FOR SUPERIOR PERFORMANCE, SPEED AND RELIABILITY.
- FIELD PROVEN ELECTRONICS FOR ULTIMATE RELIABILITY IN THE HARSHTEST ENVIRONMENTS.
- OVERMOLDED HANDLE FOR COMFORT AND IMPROVED GRIP; ALLOWS FOR ONE-HANDED OPERATION FOR ADVANCE, RETRACT AND HOLD.
- 18 VOLT LITHIUM-ION BATTERIES PROVIDE 2.5 TIMES MORE CHARGE / DISCHARGE CYCLES THAN TRADITIONAL Ni-Cd BATTERIES AND PROVIDE 430% MORE LIFETIME WORK.
- 30 MINUTE CHARGER CONTROLS CURRENT, VOLTAGE AND TEMPERATURE TO MAXIMIZE BATTERY LIFE. FORCED AIR COOLING FAN COOLS THE BATTERY BY FORCING COOL AIR THROUGH THE BATTERY'S BUILT-IN AIR VENTS.
- STATE OF THE ART CRIMPING HEAD DESIGN, 355° ROTATION LETS THE USER GET INTO TIGHT AREAS EASIER.
- ALLOWS USE OF STANDARD BURNDY® DIES ALREADY IN USE.
- ERGONOMICALLY BALANCED TOOL DESIGN EASES OPERATION AND HELPS LESSEN FATIGUE.
- DURABLE HIGH IMPACT FORMED CARRYING CASE PROVIDES SUPERIOR PROTECTION AND STORES ALL ACCESSORIES.
- 5 YEAR LIMITED WARRANTY ON THE TOOL, 3 YEAR LIMITED WARRANTY ON THE BATTERIES AND CHARGER.
- LIFETIME WARRANTY ON THE INFINITY® DRIVE.


NOTES:

- LANYARD IS STORED IN COMPARTMENT UNDER THE LID.
- NIST MODEL SUPPLIED WITH CALIBRATION CERTIFICATE.

REV.	DATE	DESCRIPTION	ECO	BY	C'H'K.
G	2018-07-23 01:00:00 EDT	UPDATED AS PER MARKUP	49436	RS	RM

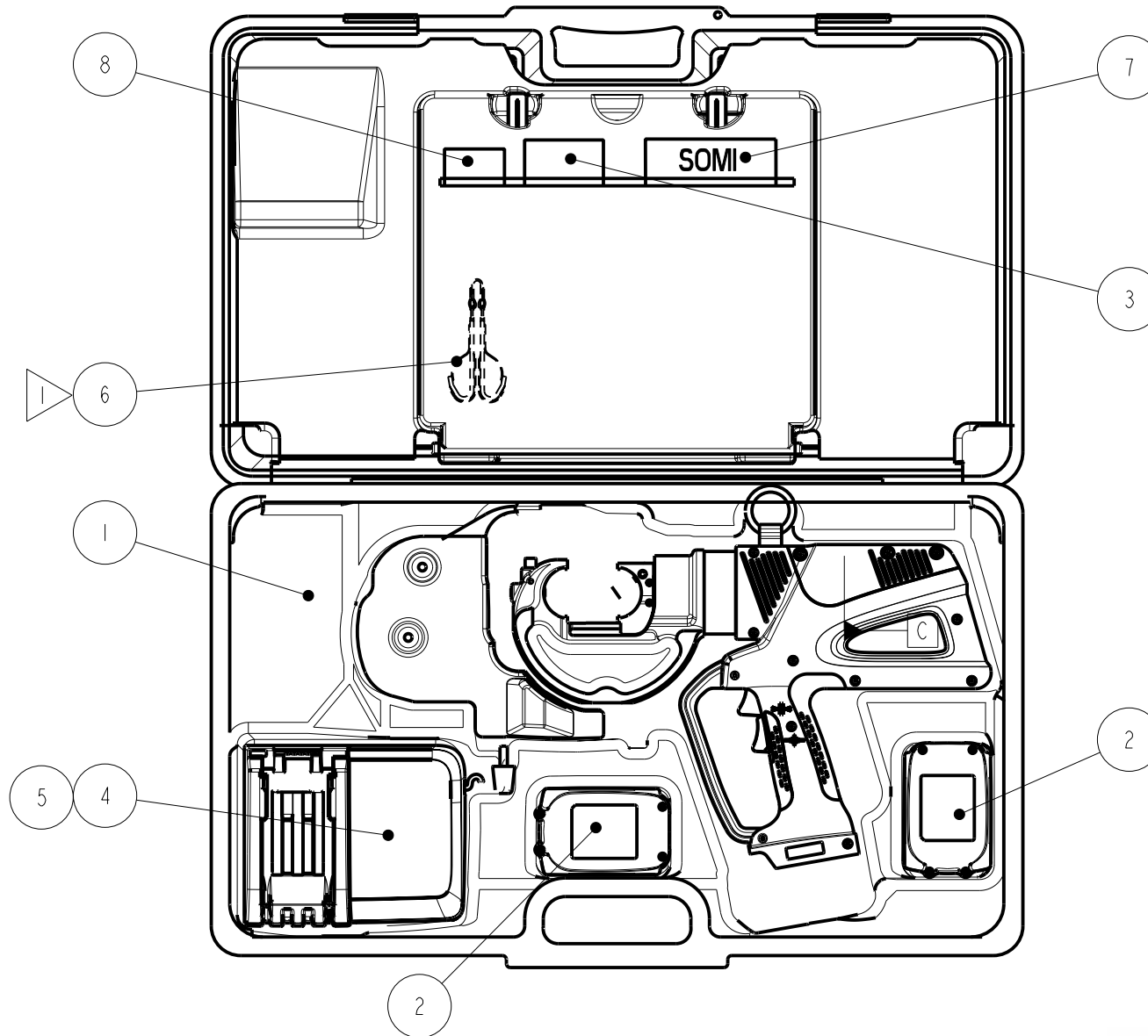

- TOOL ACCEPTS 18V MAKITA LITHIUM ION BATTERIES, BL SERIES OF SIZE 2.0 AHR AND GREATER IF THE PLASTIC BATTERY CLIP IN THE TOOL HAS A "STAR" MOLDED INTO IT. THE "STAR" IDENTIFIES ACCEPTANCE OF THE BL SERIES BATTERIES.
- FOR TOOLS WHICH DO NOT HAVE A "STAR" MOLDED INTO THE PLASTIC BATTERY CLIP, USE IS LIMITED TO THE BL 1830 (3.0AHR) BATTERY. FORCING ANY OTHER BATTERY INTO THIS TOOL WILL VOID THE WARRANTY.

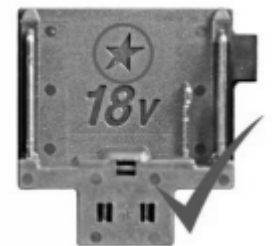

REV: PE0200

TO ORDER BURNDY® PRODUCTS CALL		PATRIOT® BATTERY 12 TON CRIMPING TOOL	
UNITED STATES:		ITEM NO: --	
1-800-346-4175 (LONDONDERRY, NH)		CAT. NO: SEE TABLE	
CANADA:		DRAWN BY: T. FAUCHER 05/06/2010	
1-800-361-6975 (QUEBEC)		CHECKER: R. POIRIER 07/29/2010	
1-800-387-6487 (ALL OTHER PROVINCES)		DSN APPVL: M. CHIASSON 08/05/2010	
FOR PRODUCT INFO: <a href="http://www.burndy.com">http://www.burndy.com</a>		MFG APPVL: S. GONYAW 08/19/2010	
		QA APPVL: J. BRODEUR 08/06/2010	
		MKT APPVL: --	
		SCALE: 1:4	
		PROD FAM: TOOLS, BATTERY	
		PROJECT #: 14074	
		SIZE	
		DRAWING NO	
		30001518	
		DOCUMENT TYPE: Sales	
		REL LEVEL: In Work	
		SHEET 1 OF 1	
		G	

