


DRAWING NO. 30014549		4	3	2	1
CATALOG NUMBER	ITEM NUMBER	L			
B2D12N	332561	12.00 [305]			
B2D15N	332377	15.00 [381]			
B2D16N	332626	16.00 [406]			
B2D18N	25006358	18.00 [457]			
B2D20N	332301	20.00 [508]			
B2D21N	332388	21.00 [533]			
B2D24N	332300	24.00 [610]			
B2D27N	332804	27.00 [686]			
B2D42N	25003362	42.00 [1067]			
B2D96N	10099387	96.00 [2438]			
B2D192N	10099388	192.00 [4877]			

REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
A	4/16/2011 12:00:00 AM	BRAID UPDATE	23847	MRA	JG

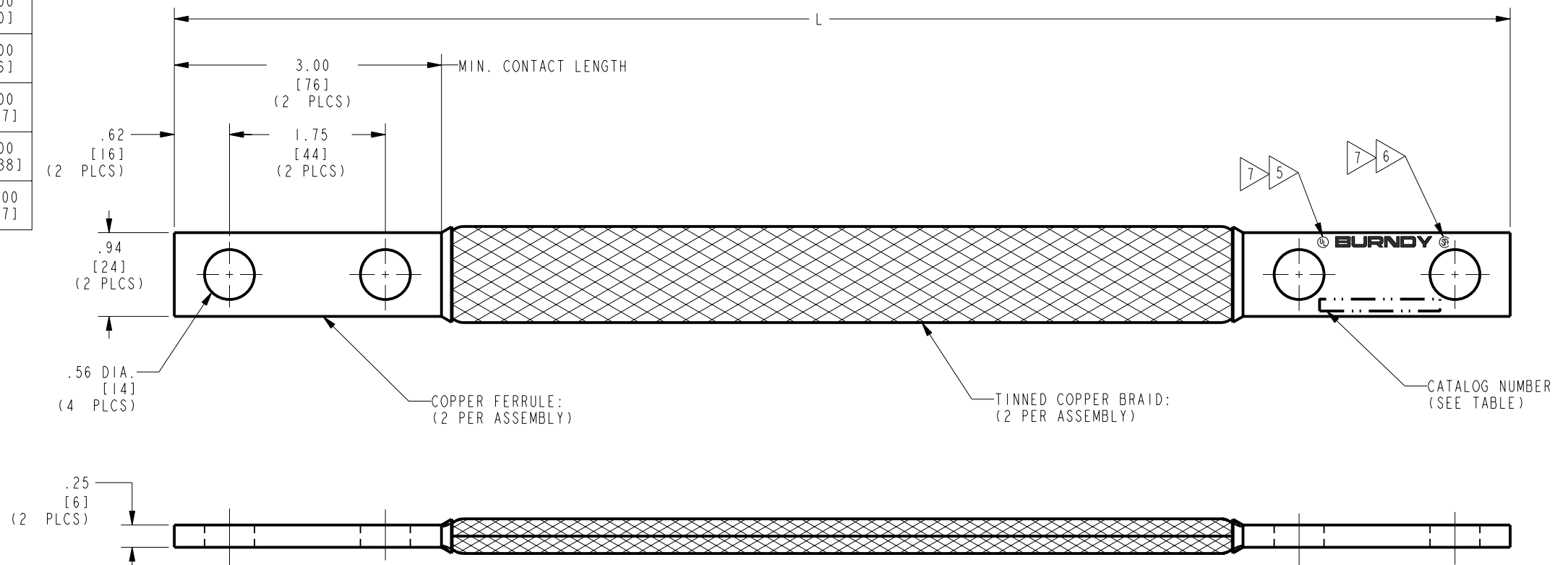

NOTES:

- APPROXIMATE AMP RATING: 380 INDOOR, 455 OUTDOOR
THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID AND OTHER SERVICE CONDITIONS.
- DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.
- CAN BE ORDERED WITH PLATED FERRULES BY ADDING SUFFIX AS SHOWN BELOW:
"NK" - FOR NICKEL PLATING
"SV" - FOR SILVER PLATING
"TN" - FOR TIN PLATING
"W" - FOR HOT TIN DIPPED
- CAN BE ORDERED WITH UNDRILLED FERRULES BY ADDING SUFFIX "U".
- ALL SIZES ARE LISTED TO UL 467 GROUNDING & BONDING EQUIPMENT STANDARDS.
- ALL SIZES ARE LISTED TO CSA C22.2 NO.41 GROUNDING & BONDING EQUIPMENT STANDARDS.
- BRAID SIZES MAY BE DESIGNATED BY SUFFIXES REPRESENTING VARIATIONS IN LENGTH, QUANTITY & SIZE OF MOUNTING HOLES, PAD SIZE AND FINISH. (REF. NOTES 5, 6)

TO ORDER BURNDY® PRODUCTS CALL		BRAID	
UNITED STATES: 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: N/A	
CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)		CAT. NO: B2D--N (TABLE)	
FOR PRODUCT INFO: http://www.burndy.com		DRAWN BY: M. RAMESH 04/16/11	
		CHECKER: E. MARTIN 05/05/11	
		DSN APPVL: E. MARTIN 05/05/11	
		MFG APPVL: O. GUALBERTO 05/10/11	
		QA APPVL: C. ACKEMAN 05/07/11	
		MKT APPVL: -- --	
		SCALE: 1:1	
		DRAWING NO	
		30014549	
		REV	
		A	

REV: PED200