

TABLE				
ITEM #	CATALOG #	DESCRIPTION	CHARGER VOLTS	CHARGER ITEM #
50045619	PAT500SJ68LI	PAT500SJ68LI WITH 120V CHARGER	120	30001520
50045612	PAT500SJ66LI	PAT500SJ66LI WITH 120V CHARGER	120	30001520
50045620	PAT500SJ6LI	PAT500SJ6LI WITH 120V CHARGER	120	30001520
50045616	PAT500SJ68LIDC	PAT500SJ68LI WITH DC CHARGER	12/24	30001523
50045617	PAT500SJ66LIDC	PAT500SJ66LI WITH DC CHARGER	12/24	30001523
50045618	PAT500SJ6LIDC	PAT500SJ6LI WITH DC CHARGER	12/24	30001523
50045613	PAT500SJ68LILCB	PAT500SJ68LI LESS CHARGER & BATTERY	N/A	N/A
50045614	PAT500SJ66LILCB	PAT500SJ66LI LESS CHARGER & BATTERY	N/A	N/A
50045615	PAT500SJ6LILCB	PAT500SJ6LI LESS CHARGER & BATTERY	N/A	N/A
50024947	PAT500SJCUTLI	PAT500SJCUTLI WITH 120V CHARGER	120	30001520
50024954	PAT500SJCUTLIDC	PAT500SJCUTLI WITH DC CHARGER	12/24	30001523
50045621	PAT500SJCUTLILCB	PAT500SJCUTLI LESS CHARGER & BATTERY	N/A	N/A
50054414	PAT500SJ6LICUTKITI	CRMP,6T,OP-HD (BG, D3) SCR,LI, W CUTTER	120	30001520
50054415	PAT500SJ68LICUTKITI	CRMP,6T,OP-HD (O, D3) SCR,LI, W CUTTER	120	30001520

SPECIFICATIONS:

OUTPUT FORCE: 6 TONS (5.4 METRIC TONS)
 TOOL WEIGHT WITH BATTERY: 11.0 LBS (4.9 kg)
 LENGTH: 16.8 IN (42.6 cm)
 WIDTH: 2.9 IN (7.3 cm)
 HEIGHT: 13.4 IN (34.0 cm)
 OPERATING VOLTAGE: 18V-DC
 RECHARGE TIME: 30 MINUTES

FEATURES

- REFINED HYDRAULIC SYSTEM FOR ULTRA PERFORMANCE, SPEED AND RELIABILITY.
- FIELD PROVEN ELECTRONICS FOR ULTIMATE RELIABILITY IN THE HARSHTEST ENVIRONMENTS.
- OVERMOLDED HANDLE FOR COMFORT AND IMPROVED GRIP; ALLOWS FOR ONE HANDED OPERATION FOR ADVANCE RETRACT AND HOLD.
- FORCED AIR COOLING FAN COOLS THE BATTERY BY FORCING COOL AIR THROUGH THE BATTERY'S BUILT IN AIR VENTS.
- 6 TON OUTPUT FORCE.
- STATE OF THE ART CRIMPING HEAD DESIGN, 180° HEAD ROTATION LETS USER GET INTO TIGHT AREAS EASIER.
- AUDIBLE "POP OFF" INDICATES PROPERLY COMPLETED CRIMPS.
- ERGONOMICALLY BALANCED TOOL DESIGN EASES OPERATION AND HELPS LESSEN FATIGUE.
- DURABLE HIGH IMPACT FORMED CARRYING CASE PROVIDES SUPERIOR PROTECTION AND STORES ALL ACCESSORIES.
- 5 YEAR LIMITED WARRANTY ON THE TOOL.
- 3 YEAR LIMITED WARRANTY ON THE BATTERY & CHARGER.

BENEFITS


- VERSATILE TOOL HEAD POSITIONING LETS USER GET INTO TIGHT AREAS.
- LESS DOWN TIME DUE TO HIGH CAPACITY, HIGH VOLTAGE 18 VOLT LITHIUM ION BATTERY.
- ASSURES PROPER CRIMPS WITH AUDIBLE INDICATOR, LEAVING NO DOUBT FOR TOOL USER.
- SMOOTHER, QUIETER, MORE EFFICIENT TOOL OPERATION.
- MAKITA 18 VOLT LITHIUM-ION BATTERIES PROVIDE 2.5 TIMES MORE CHARGE/DISCHARGE CYCLES THAN TRADITIONAL Ni-Cd BATTERIES AND PROVIDE 430% MORE LIFETIME WORK.
- MAKITA 30 MINUTE CHARGER CONTROLS CURRENT, VOLTAGE AND TEMPERATURE TO MAXIMIZE BATTERY LIFE.

NOTES:

1. TOOL ACCEPTS 18V MAKITA LITHIUM-ION BATTERIES, BL SERIES, OF SIZE 2.0 AHR AND GREATER IF THE PLASTIC BATTERY CLIP IN THE TOOL HAS A "STAR" MOLDED INTO IT. THE "STAR" IDENTIFIES ACCEPTANCE OF THE BL SERIES BATTERIES.
2. FOR TOOLS WHICH DO NOT HAVE A "STAR" MOLDED INTO THE PLASTIC BATTERY CLIP, USE IS LIMITED TO THE BL1830 (3.0 AHR) BATTERY. FORCING ANY OTHER BATTERY INTO THIS TOOL WILL VOID THE WARRANTY.



REV.	DATE	DESCRIPTION	ECO	BY	C'H'K.
F	2018-12-03 23:00:00 EST	UPDATED AS PER MARKUP	50432	RS	RM

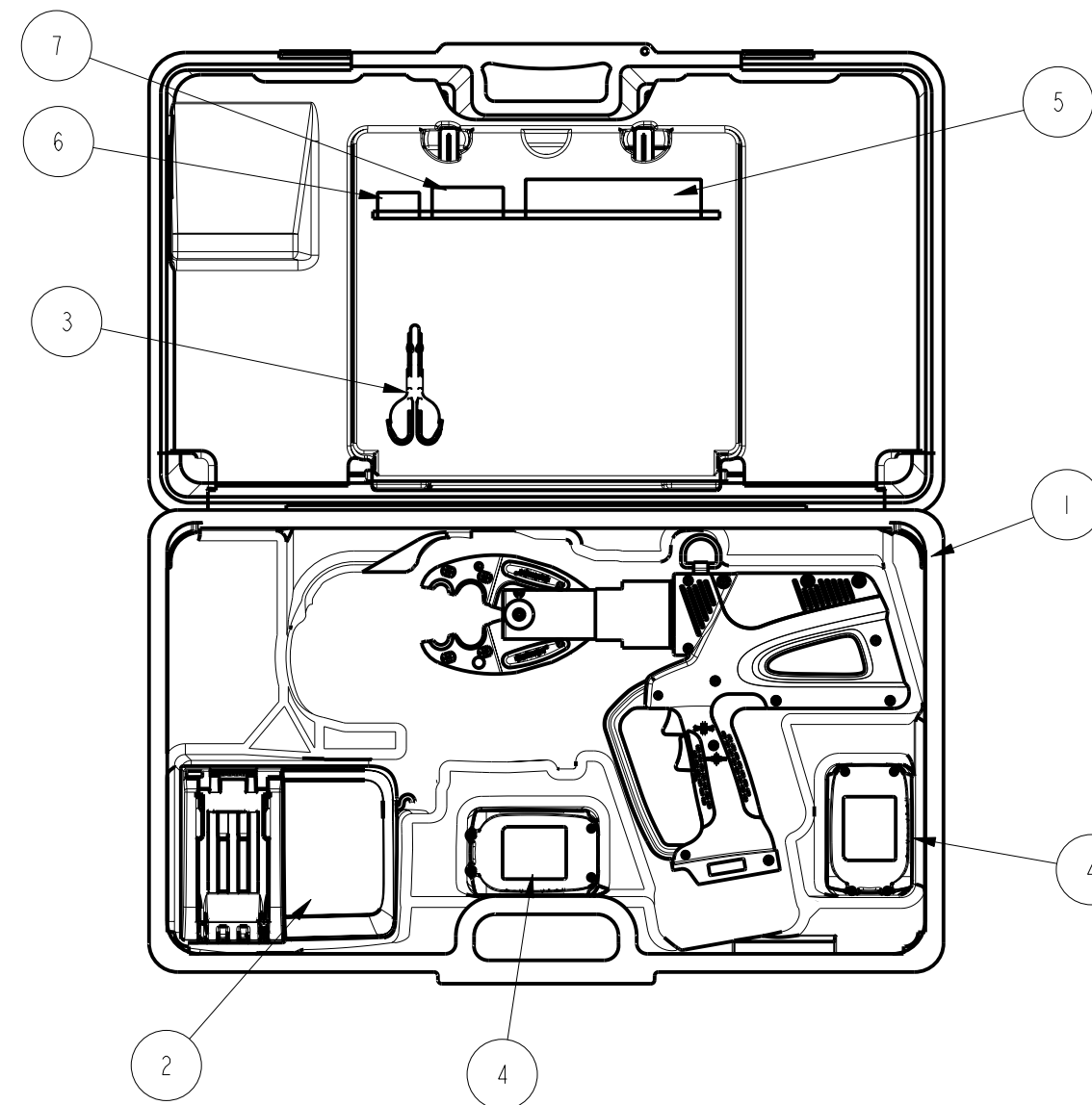

*** BILL OF MATERIAL ***

PT NO.	CATALOG NO.	QTY	DESCRIPTION
1	PATCASELI	1	CASE, TOOL PATRIOT LITHIUM ION
2	PATCHGRLI	1	CHARGER, BATTERY LITHIUM ION
3	PT208620	1	LANYARD
4	BAT18VLI	2	BATTERY, MAKITA LITHIUM ION 18V 3.0 Ah
5	PAT500SJOMI	1	SOMI, PAT500SJ
6	PT20443801	1	WARRANTY CARD
7	LIMSDS	1	MSDS, LITHIUM ION BATTERY

TO ORDER BURNDY® PRODUCTS CALL

UNITED STATES:
1-800-346-4175 (LONDONDERRY, NH)

CANADA:
1-800-361-6975 (QUEBEC)
1-800-387-6487 (ALL OTHER PROVINCES)

FOR PRODUCT INFO: <http://www.burndy.com>

PATRIOT 500 SCISSOR JAW TOOL

ITEM NO: SEE TABLE	
CAT. NO: SEE TABLE	
DRAWN BY: T. FAUCHER 09/30/2014	
CHECKER: L. BROWN 10/01/2014	
DSN APPVL: L. BROWN 11/07/2014	
MFG APPVL: S. GONYAW 11/04/2014	
QA APPVL: C. LINDQUIST 11/11/2014	SCALE: 5:32
MKT APPVL: M. RZASA 11/05/2014	DRAWING NO
PROJECT #: --	50024949
DOCUMENT TYPE: Sales	REV
REL LEVEL: Released	F
SIZE	SHEET 1 OF 1
B	