
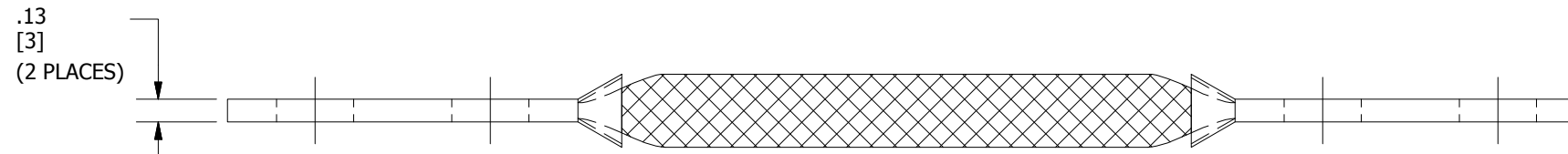


REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
A	10/28/2013	DRAWING RELEASED	33778	RK	MB

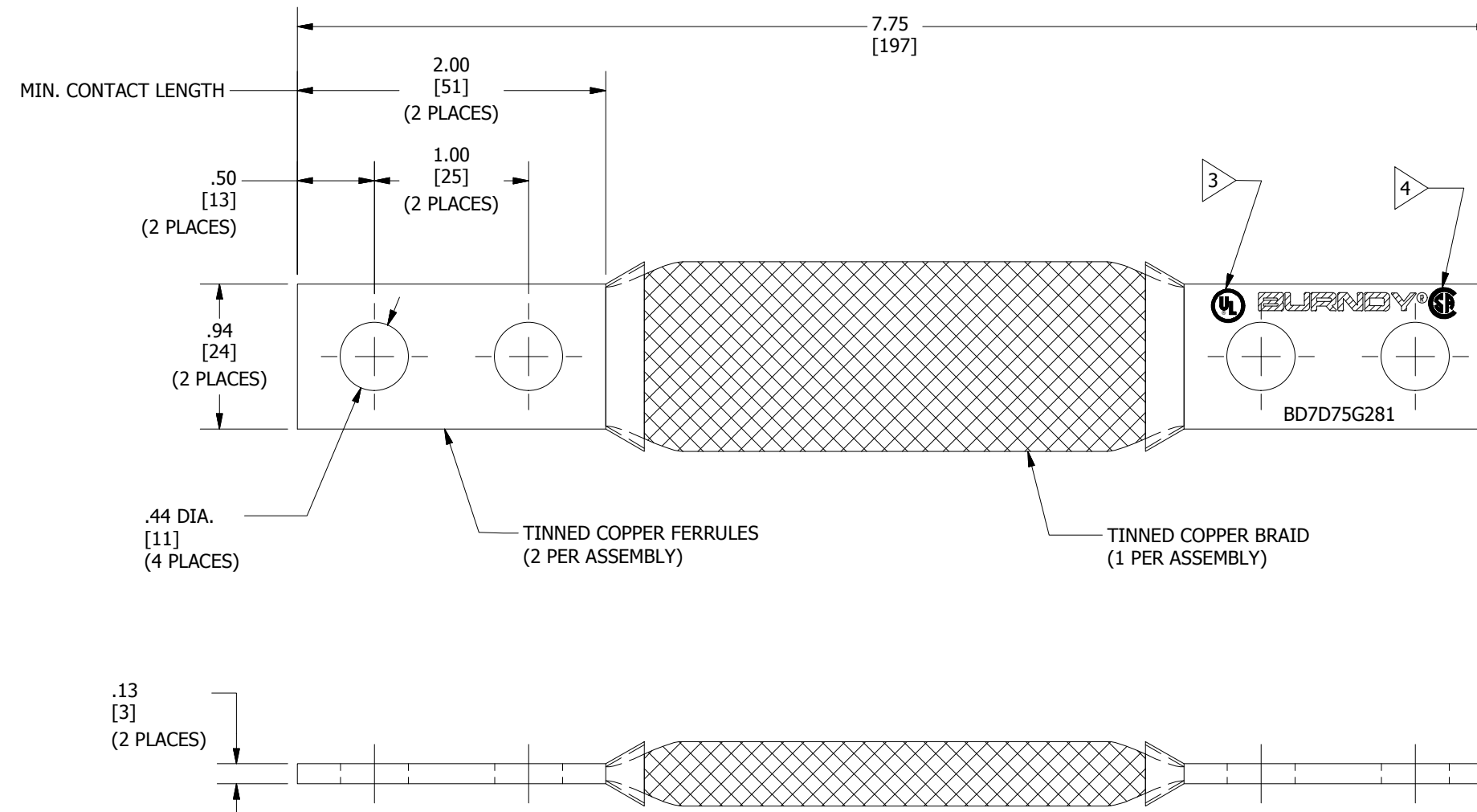

NOTES:

1. APPROXIMATE AMP. RATING: 190 INDOOR, 225 OUTDOOR. THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID AND OTHER SERVICE CONDITIONS.

2. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED, AND ARE FOR REFERENCE ONLY.

3 "UL" SYMBOL PER INTERNAL SPEC. L4219, LOCATION AND SIZE TO BE DETERMINED BY MANUFACTURING.

4 "CSA" SYMBOL PER INTERNAL SPEC. L4591, LOCATION AND SIZE TO BE DETERMINED BY MANUFACTURING.

TO ORDER BURNDY® PRODUCTS CALL		BRAID	
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: 50028091	
CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)		CAT. NO: BD7D75G281	
FOR PRODUCT INFO: http://www.burndy.com		DRAWN BY: R.KONATHALA 10/28/2013 CHECKER: L.TROMBLEY 11/05/2013 DSN APRVL: L.TROMBLEY 11/05/2013 MFG APRVL: S.MATTHEW 11/05/2013 QA APRVL: C.LINDQUIST 11/12/2013 MKT APRVL: K.ROBICHEAU 11/05/2013	
PROJ #:	SIZE	DRAWING NO	REV
SALES	B	50028092	A
REL LEVEL: Released		SHEET 1 OF 1	