


REV	DATE	DESCRIPTION	ECO	BY	C'H'
A	6/2/2015	NEW ASSEMBLY SALES DRAWING CREATED	40444	AS	MB

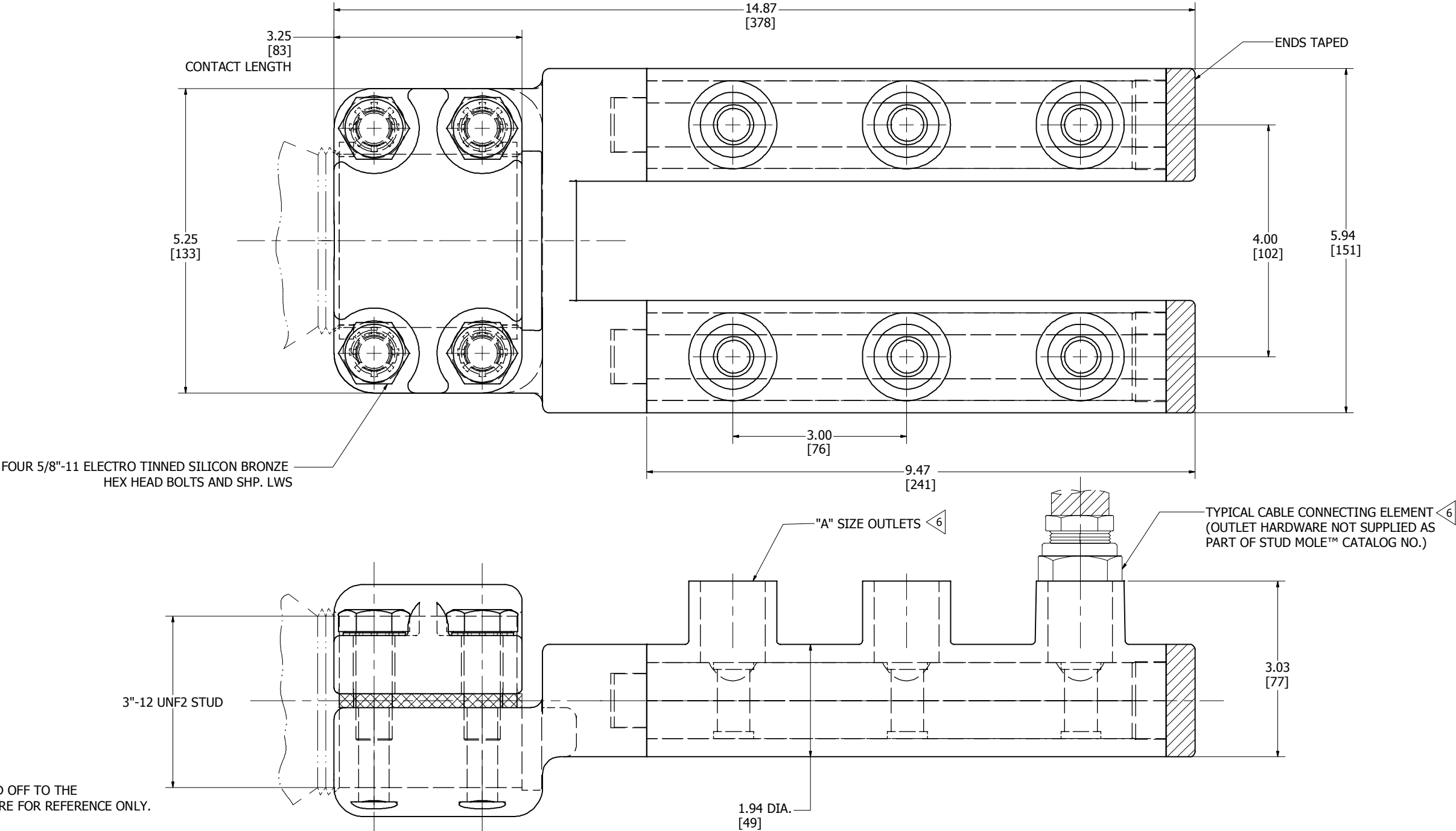

NOTES:

- DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.
- ACCOMMODATES:
STUD: 3" - 12 UNF
OUTLETS(6): "A" SIZE, #2 STR - 1000 kcmil CU. CABLE
- MATERIAL:
STUD CLAMPING ELEMENT: CAST COPPER ALLOY
MOLE INSERT: COPPER ALLOY
INSULATION: DIATEX
- FINISH: METAL COMPONENTS ELECTRO TIN PLATED
- AMPERE CAPACITY: 3000 AMPS
- 6 Z-NR SOCKET AND NUT ASSEMBLIES AND Z-CONES MUST BE ORDERED SEPARATELY TO ACCOMMODATE THE CABLE.
- 7 FOR DIAPRENE INSULATION ADD "N" TO THE CATALOG NUMBER.
- APPROXIMATE WEIGHT: 21.436 lbs

TO ORDER BURNDY® PRODUCTS CALL		STUD MOLE™			
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: 21877K		7	
		CAT. NO: Z2MLDN630			
CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)		DRAWN BY: ARAVIND SWAMY		6/2/2015	
		CHECKER: MANIKANDAN B		6/2/2015	
		DSN APRVL: --			
		MFG APRVL: --			
		QA APRVL: --			
		MKT APRVL: --			
FOR PRODUCT INFO: http://www.burndy.com		PROD FAM: --		DRAWING NO	
		PROJECT #: --		50039639	
		DOCUMENT TYPE: SALES		SHEET 1 OF 1	
		REL LEVEL: Released			