
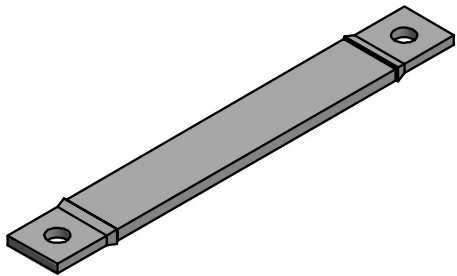


REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
A	11/24/2014	SALES DRAWING RELEASE	38481	DK	MA

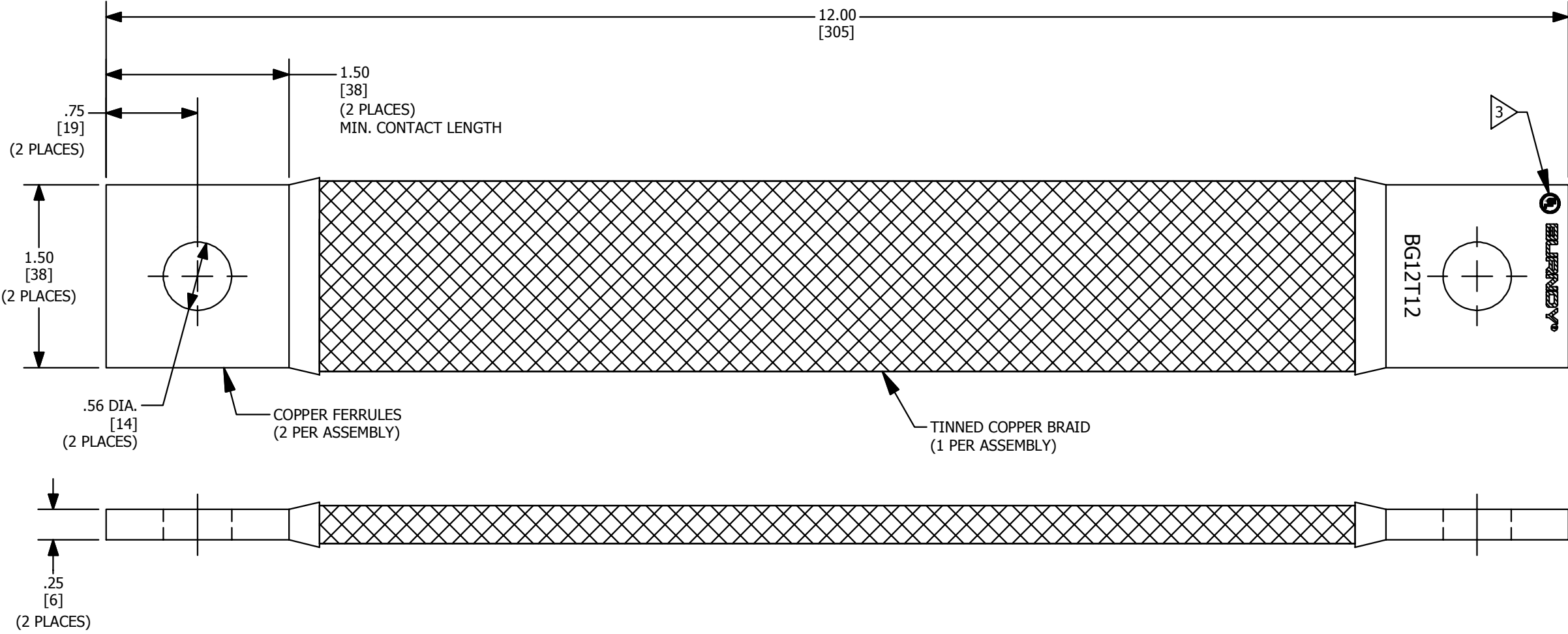

NOTES:

- APPROXIMATE AMP. RATING: 415 INDOOR, 495 OUTDOOR. THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID, AND OTHER SERVICE CONDITIONS.
 - DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.
- 3 ALL SIZES ARE LISTED TO UL 467 GROUNDING & BONDING EQUIPMENT STANDARDS.

TO ORDER BURNDY PRODUCTS CALL		FLEXIBLE BRAID 1/2" STUD	
UNITED STATES		ITEM NO: 50047799	
1-800-346-4175 (LONDONDERRY, NH)		CAT. NO: BG12T12	
CANADA:		DRAWN BY: N.D.KANNAN 11/25/2014	
1-800-361-6975 (QUEBEC)		CHECKER: L.TROMBLEY 12/18/2014	
1-800-387-6487 (ALL OTHER PROVINCES)		DSN APRVL: L.TROMBLEY 12/18/2014	
FOR PRODUCT INFO: http://www.burndy.com		MFG APRVL: M.STEVENS 12/17/2014	
		QA APRVL: C.LINDQUIST 12/22/2014	
		MKT APRVL: K.ROBICHEAU 12/17/2014	
PROJECT #:	---	SIZE	DRAWING NO
DOCUMENT TYPE:	SALES	B	50047630
REL LEVEL:	Released		SHEET 1 OF 1
			REV
			A