

REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
A	07/22/2015	RELEASED	40025	AM	JS

BURNDY ITEM NUMBER	BURNDY CATALOG NUMBER	TENSILE lb / KG	MATERIAL	COLOR	FEATURE	FIGURE	BUNDLE DIA MIN IN / [MM]	BUNDLE DIA MAX IN / [MM]	LENGTH IN / [MM]	WIDTH [IN / MM]	MIN INSTALL TEMP F / C	MIN OPER TEMP F / C	MAX OPER TEMP F / C	PKG QTY	CTN QTY
10023690	CT18075FLC	18 / 8	NYLON 6/6	NATURAL	IDENTIFICATION	3	0.02 / [0.6]	0.75 / [19]	4.1 / [105]	0.10 / [2.5]	32 / 0	-40 / -40	185 / 85	100	20,000
10023689	CT18075IDC	18 / 8	NYLON 6/6	NATURAL	IDENTIFICATION	2	0.06 / [1.5]	0.83 / [21]	3.71 / [96]	0.10 / [2.5]	32 / 0	-40 / -40	185 / 85	100	20,000
50057688	CT18200IDC	18 / 8	NYLON 6/6	NATURAL	IDENTIFICATION	2	0.04 / [1.1]	2.09 / [53]	7.7 / [196]	0.10 / [2.5]	32 / 0	-40 / -40	185 / 85	100	12,500
10023691	CT50175IDC	50 / 22	NYLON 6/6	NATURAL	IDENTIFICATION	1	0.27 / [6.9]	1.97 / [50]	7.8 / [200]	0.18 / [4.58]	32 / 0	-40 / -40	185 / 85	100	7,500
50057689	CT50250IDC	50 / 22	NYLON 6/6	NATURAL	IDENTIFICATION	1	0.28 / [7.1]	2.95 / [75]	10.6 / [270]	0.18 / [4.60]	32 / 0	-40 / -40	185 / 85	100	7,500

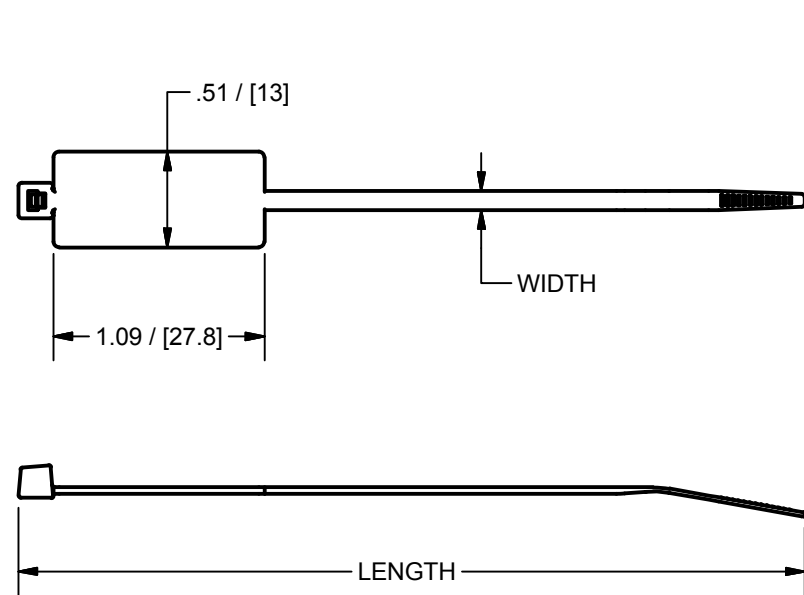


FIG. 1

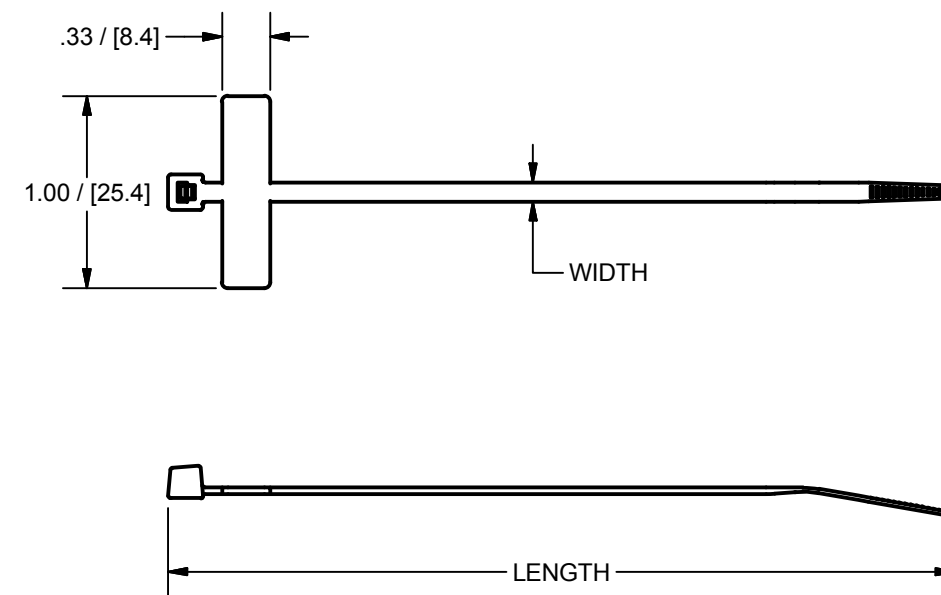


FIG. 2

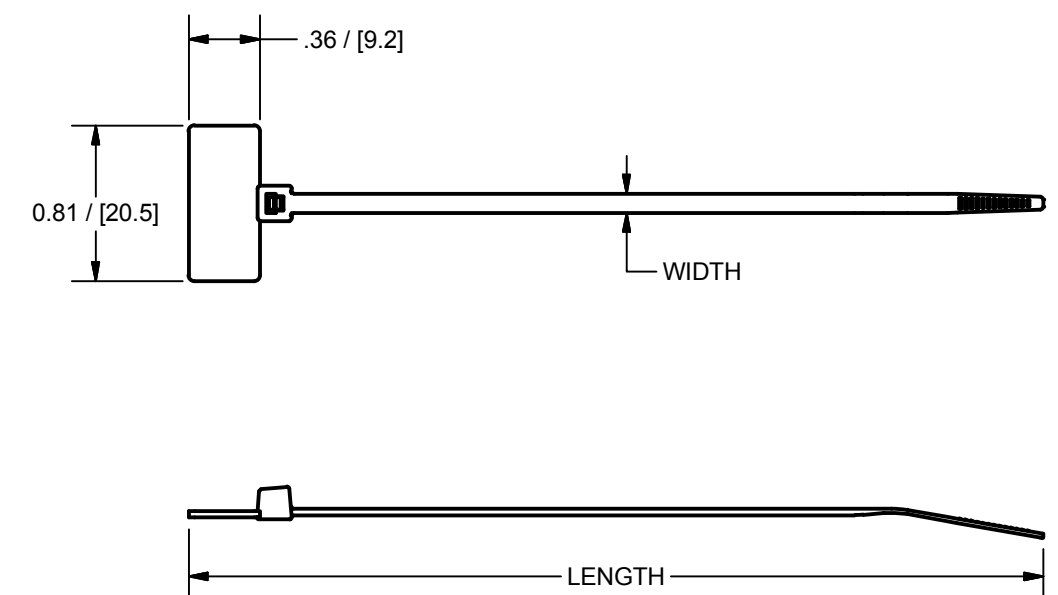


FIG. 3

**NOTES:**

- DIMENSIONS IN BRACKETS [ ] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.
- FLAMMABILITY: UL 94V-2

TO ORDER BURNDY® PRODUCTS CALL		IDENTIFICATION UNIRAP™	
1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: SEE TABLE	
CANADA:		CAT. NO: SEE TABLE	
1-800-361-6975 (QUEBEC)		DRAWN BY: A. MONTMINY 3/26/2015	
1-800-387-6487 (ALL OTHER PROVINCES)		CHECKER: --	
FOR PRODUCT INFO: <a href="http://www.burndy.com">http://www.burndy.com</a>		DSN APRVL: A. MONTMINY 7/22/2015	
		MFG APRVL: E. MONTIJO 7/22/2015	
		QA APRVL: C. KOWALCZYK 7/22/2015	
		MKT APRVL: J. SYLVIA 7/22/2015	
		PROJ #: --	
		SIZE: B	
		DRAWING NO: 50055369	
		REV: A	
		SHEET 1 OF 1	