
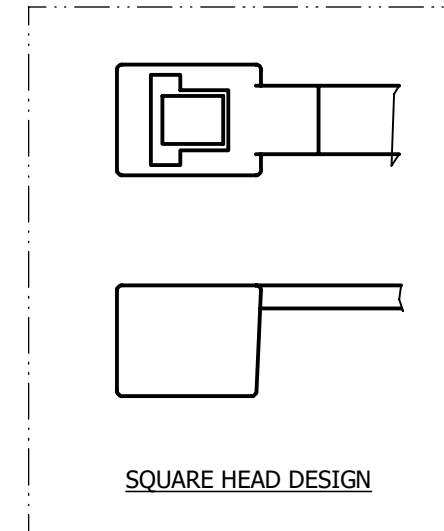



REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
A	07/15/2022	CREATED NEW SALES DRAWING	220715022135	YR	RA

CATALOG NUMBER	ITEM NUMBER	COLOR	PIECES PER BAG	L1 (mm)	L4 (mm)	L9 (mm)
CT40200CUG	10089813	NATURAL	100	200±3	3.6±.20	1.20±.20

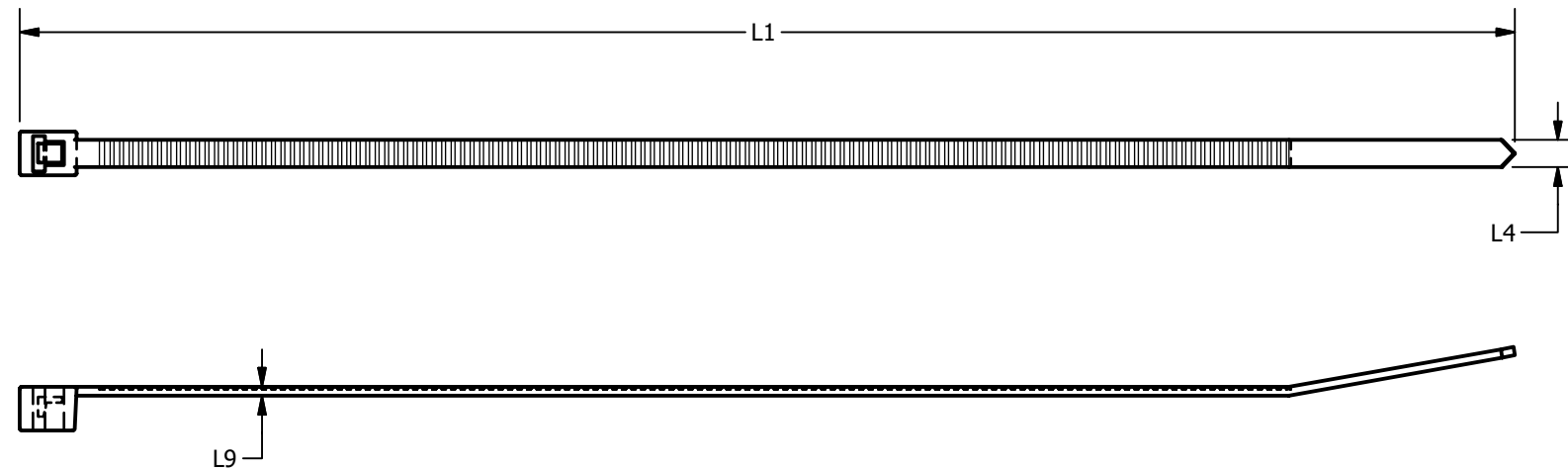

NOTES:

1. ALL DIMENSIONS ARE IN MILLIMETERS.
2. MATERIAL Natural: Polyamide 6.6 natural
3. MATERIAL Black: Polyamide 6.6 natural+~1% carbon black
4. Flammability of raw material: UL 94 -V2
5. Humidity absorption:2,7%-2,8% (23°C - 50% R.H.)
6. Installation temperature: -10°C ÷ +85°C
7. Working temperature: -40°C ÷ +85°C
8. Max sustainable temperature for short time: +110°C
9. Good resistance to bases, oils, greases, oil derivates, chloride solvents. Limited resistance to acids. Not resistant to phenols.
10. Carbon black addiction gives a better UV resistance
11. Comply with UL62275, and EN62275

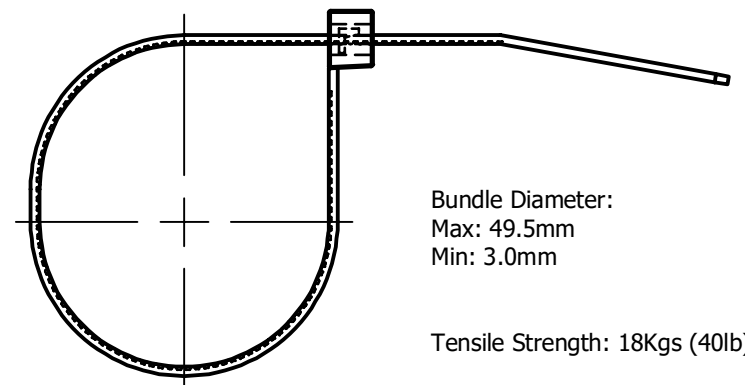

TO ORDER BURNDY® PRODUCTS CALL		UNIRAP™ UNIVERSEL GRADE	
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: SEE TABLE	
CANADA: 1-800-387-6487		CAT. NO: SEE TABLE	
FOR PRODUCT INFO: http://www.burndy.com		DRAWN BY: R.YOGARAJ 07/15/2022	
		CHECKER: K.CASTONGUAY 12/07/2023	
		DSN APRVL: K.CASTONGUAY 12/07/2023	
		MFG APRVL: --	
		QA APRVL: D.LOCKE 12/10/2023	
		MKT APRVL: K.BOUTIN 12/07/2023	
		PROD FAM: --	
		DRAWING NO	
		REV	
		50127260	
		A	
		SHEET 1 OF 1	