

TYPE: HS-TP (Heat Shrink - Thin Polyolefin)

REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

THIN WALL HEAT SHRINK TUBING

Features & Benefits Information

1. Material: Flexible, flame retardant, thin wall crosslinked polyolefin, multi-purpose heat shrink tubing
2. Product is available in 6 inch and 4 foot precut multi packaged lengths and a variety of reel sizes, (1000, 500, 250, 200, 100, 50 & 25)
3. 2:1 shrink ratio for faster shrink recovery *Yellow/Green heat shrink is 3:1 shrink ratio
4. Ideal for industrial and automotive markets as well as for covering copper and aluminum tubular connectors.
5. -55°C to 135°C (-67°F to 275°F) Continuous Operating Temperature
6. Shrink temperature of 90°C min.
7. Rated up to 600 Volts.
8. Colors are flame retardant & UV resistant
9. Resistant to common fluids and solvents
10. Provides mechanical protection for terminal strain relief and wire bonding.

Standards:

ROHS compliant
 UL 224, 125°C (colors)
 CSA C22.2 No. 198.1, 125°C
 AMS.3636, 3637 and 3587
 UL/CSA approval applies to black and colors
 Approved to automotive OEM specifications



Typical Applications:

- * Electrical Insulation of wire splices and terminals
- * Strain Relief of wire terminations
- * Protection against abrasion, fluids and environmental conditions


THIN WALL HEAT SHRINK WIRE ACCOMMODATES MATRIX / 2:1 Shrink Ratio						
NOMINAL SIZE (INCH)	NOMINAL SIZE (ISSUED)	RECOVERY SIZE (SHRUNK)	WALL THICKNESS (SUPPLIED)	COPPER CODE (Terminals & Splices)	COPPER FLEX (Terminals & Splices)	ALUMINUM (Terminals & Splices)
3/64"	0.047	0.023	0.016	-	-	-
1/16"	0.063	0.031	0.017	18 AWG	-	-
3/32"	0.094	0.047	0.020	18 - 16 AWG	-	-
1/8"	0.125	0.063	0.020	18 - 14 AWG	-	-
3/16"	0.187	0.093	0.020	18 - 12 AWG	-	-
1/4"	0.250	0.125	0.025	14 - 10 AWG	-	12 - 10 AWG
3/8"	0.375	0.187	0.025	8 - 6 AWG	14 - 5 AWG	12 - 8 AWG
1/2"	0.500	0.250	0.025	6 - 2 AWG	8 - 3 AWG	8 - 4 AWG
5/8"	0.625	0.313	0.030	2 - 2/0 AWG	3 - 1/0 AWG	4 - 1 AWG
3/4"	0.750	0.375	0.030	1 - 4/0 AWG	4 - 3/0 AWG	4 - 2/0 AWG
1"	1.000	0.500	0.035	2/0 AWG - 350 KCMIL	1/0 AWG - 250 KCMIL I,K,M, 262 DLO	2 AWG - 250 KCMIL
1-1/4"	1.250	0.625	0.035	250 - 500 KCMIL	4/0 AWG G,H,I,K,M, DLO To 350 KCMIL G,H,I,K,M, 373 DLO	3/0 AWG - 300 KCMIL
1-1/2"	1.500	0.750	0.040	350 - 750 KCMIL	250 KCMIL I,K,M, 262 DLO To 600 KCMIL G,H,I,K, 1470/24 DLO	3/0 AWG - 750 KCMIL
2"	2.000	1.000	0.045	600 - 1500 KCMIL	500 KCMIL G,H, 444 DLO To 750 KCMIL G,H, 777 DLO	300 - 1000 KCMIL
3"	3.000	1.500	0.050	1250 - 2000 KCMIL	-	1000 - 2000 KCMIL
4"	4.000	2.000	0.055	-	-	-

* Wires in the table are for reference and the installer should select the proper heat shrink size based on the OD of the wire insulation, terminal or splice being used.

Heat Shrink Thin Wall

Heat Shrink Thin Wall Polyolefin	Color: BK: Black, BL: Blue, CL: Clear, GR: Green, OR: Orange, RD: Red, WH: White, YL: Yellow, YG: Yellow/Green, MX: Mixed	Internal Diameter: 0047: 0.047 (3/64"), 0063: 0.063 (1/16"), 0094: 0.094 (3/32"), 0125: 0.125 (1/8"), 0187: 0.187 (3/16"), 0250: 0.250 (1/4"), 0375: 0.375 (3/8"), 0500: 0.500 (1/2"), 0750: 0.750 (3/4"), 1000: 1.000 (1"), 1250: 1.250 (1-1/4"), 1500: 1.500 (1-1/2"), 2000: 2.000 (2"), 3000: 3.000 (3"), 4000: 4.000 (4")	Length: 6I: 6 Inch Lengths, 4F: 4 Foot Lengths, 1000F: 1000 Feet, 500F: 500 Feet, 250F: 250 Feet, 200F: 200 Feet, 100F: 100 Feet, 50F: 50 Feet, 25F: 25 Feet	Package Type: PK: Package, RL: Reel	Number of Pieces in Multipack: 25	Ordering Suffix: EA: Each
HS TP	BK	0047	4F	PK	25	EA


Catalog Number Scheme: **HSTPBK00474FPK25EA**

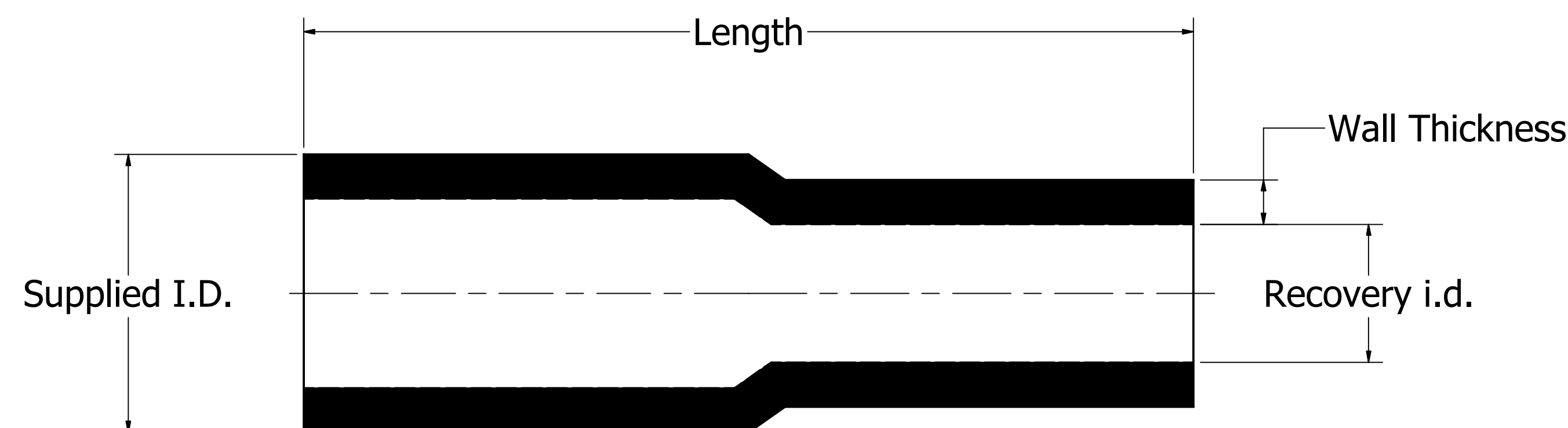



TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-387-6487 FOR PRODUCT INFO: http://www.burndy.com	THIN WALL HEAT SHRINK		
	ITEM NO: SEE TABLE		
	CAT. NO: SEE TABLE		
	DRAWN BY: R.VASANTH	3/16/2023	
	CHECKER: B.NADEAU	3/29/2023	
DSN APRVL: B.NADEAU	4/26/2023		
MFG APRVL: L.RUFFIN	5/26/2023		
QA APRVL: J.BRODEUR	5/4/2023		
MKT APRVL: B.MICHAUD	4/26/2023		
PROJECT #: --	SIZE	DRAWING NO	REV
DOCUMENT TYPE: SALES	D	50139507	A
REL LEVEL: Released		SHEET 1 OF 17	

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Product Color
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
										HSTPMX00476IPK25	3/64"	0.047	0.023	0.016	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	

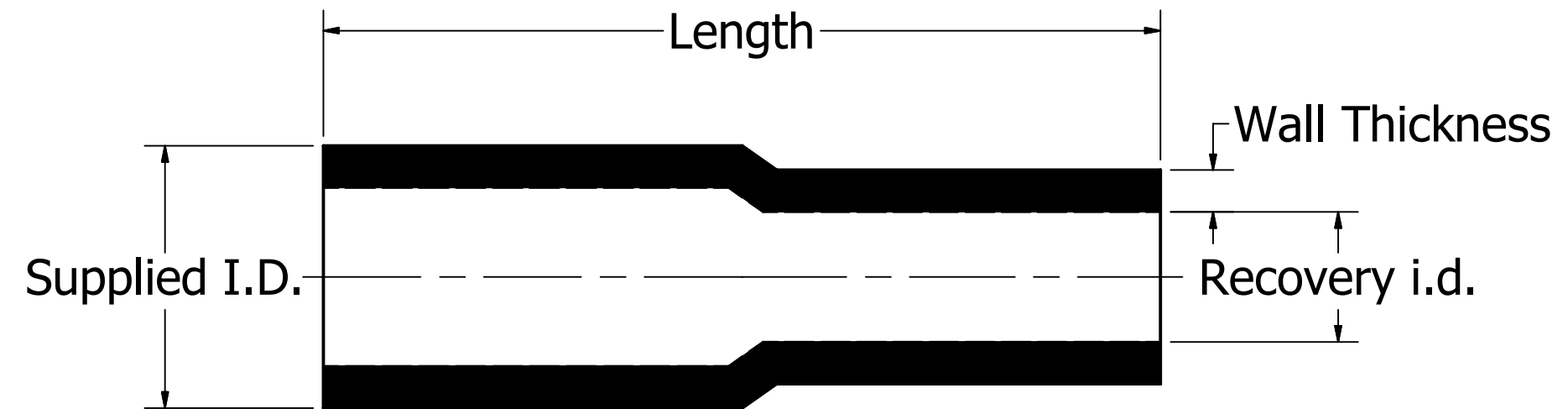
REV	DATE	DESCRIPTION	EC	BY	C'H'K.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR



TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-387-6487 FOR PRODUCT INFO: http://www.burndy.com	THIN WALL HEAT SHRINK			
	ITEM NO: SEE TABLE	CAT. NO: SEE TABLE		
	DRAWN BY: R.VASANTH	3/16/2023		
	CHECKER: B.NADEAU	3/29/2023		
	DSN APRVL: B.NADEAU	4/26/2023		
	MFG APRVL: L.RUFFIN	5/26/2023		
QA APRVL: J.BRODEUR	5/4/2023			
MKT APRVL: B.MICHAUD	4/26/2023			
PROD FAM: --	DRAWING NO	REV		
PROJECT #: --	SIZE	50139507 SHEET 2 OF 17	A	
DOCUMENT TYPE: SALES	D			
REL LEVEL: Released				

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø id Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color										Product Color
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)		
HSTPMX00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed	
HSTPBK00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black	
HSTPBK00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	25	-	-	-	-	-	-	-	-	Black	
HSTPBK00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black	
HSTPBK0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black	
HSTPBK0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black	
HSTPBK0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black	
HSTPBK006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black	
HSTPBK006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black	
HSTPBL00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue	
HSTPBL00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	25	-	-	-	-	-	-	-	Blue	
HSTPBL00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue	
HSTPBL0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue	
HSTPBL0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue	
HSTPBL0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue	
HSTPBL006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue	
HSTPBL006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue	
HSTPCL00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear	
HSTPCL00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	25	-	-	-	-	-	-	Clear	
HSTPCL00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear	
HSTPCL0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear	
HSTPCL0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear	
HSTPCL0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear	
HSTPCL006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear	
HSTPCL006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear	
HSTPGR00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green	
HSTPGR00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	25	-	-	-	-	-	Green	
HSTPGR00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green	
HSTPGR0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green	
HSTPGR0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green	
HSTPGR0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green	
HSTPGR006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green	
HSTPGR006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green	
HSTPOR00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange	
HSTPOR00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	25	-	-	-	-	Orange	
HSTPOR00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange	
HSTPOR0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange	
HSTPOR0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange	
HSTPOR0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange	
HSTPOR006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange	
HSTPOR006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange	
HSTPRD00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red	
HSTPRD00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	25	-	-	-	Red	
HSTPRD00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red	
HSTPRD0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red	
HSTPRD0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red	
HSTPRD0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red	
HSTPRD006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red	
HSTPRD006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red	
HSTPWH00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White	
HSTPWH00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	25	-	-	White	
HSTPWH00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White	
HSTPWH0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White	
HSTPWH0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White	
HSTPWH0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White	
HSTPWH006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White	
HSTPWH006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White	
HSTPYL00636IPK25	1/16"	0.063	0.031	0.017	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow	
HSTPYL00634FPK25EA	1/16"	0.063	0.031	0.017	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	25	-	Yellow	
HSTPYL00631000FRL	1/16"	0.063	0.031	0.017	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow	
HSTPYL0063500FRL	1/16"	0.063	0.031	0.017	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow	
HSTPYL0063250FRL	1/16"	0.063	0.031	0.017	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow	
HSTPYL0063100FRL	1/16"	0.063	0.031	0.017	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow	
HSTPYL006350FRL	1/16"	0.063	0.031	0.017	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow	
HSTPYL006325FRL	1/16"	0.063	0.031	0.017	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow	


REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

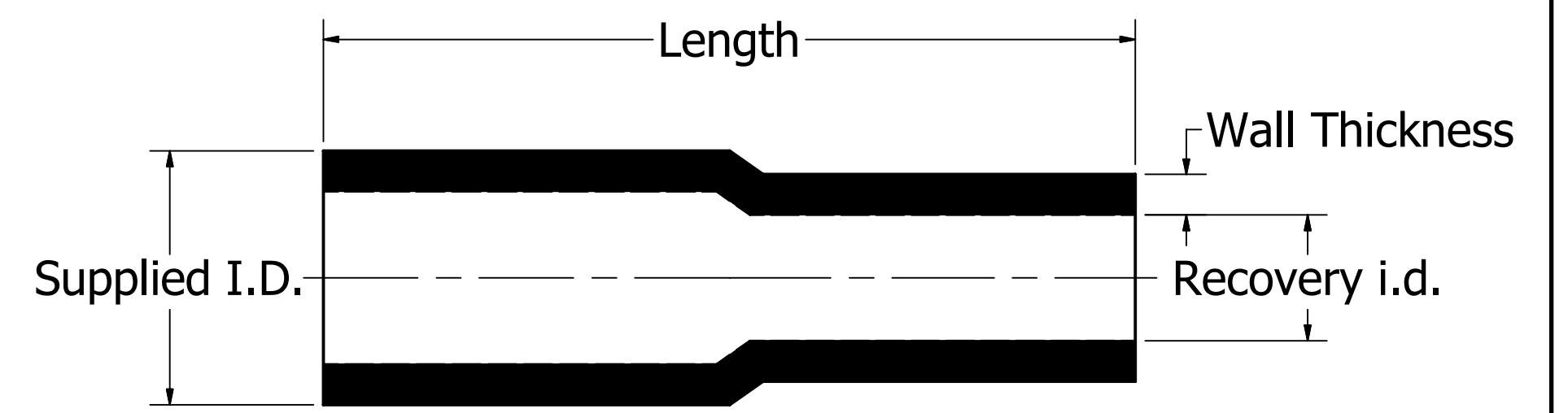


<p>TO ORDER BURNDY® PRODUCTS CALL</p> <p>UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)</p> <p>CANADA: 1-800-387-6487</p> <p>FOR PRODUCT INFO: http://www.burndy.com</p>	THIN WALL HEAT SHRINK			
	ITEM NO: SEE TABLE			
	CAT. NO: SEE TABLE			
	DRAWN BY:	R.VASANTH	3/16/2023	
	CHECKER:	B.NADEAU	3/29/2023	
	DSN APRVL:	B.NADEAU	4/26/2023	
	MFG APRVL:	L.RUFFIN	5/26/2023	
	QA APRVL:	J.BRODEUR	5/4/2023	
	MKT APRVL:	B.MICHAUD	4/26/2023	
	PROD FAM:	--		DRAWING NO
PROJECT #:	--	SIZE	50139507	A
DOCUMENT TYPE:	SALES	D	SHEET 3 OF 17	
REL LEVEL:	Released			


Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Product Color
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
HSTPMX00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
HSTPBK00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBL00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPCL00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCL00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCL00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPGR00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
HSTPGR00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	25	-	-	-	-	-	Green
HSTPGR00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPOR00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Orange
HSTPOR00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	25	-	-	-	Orange
HSTPOR00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPRD00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
HSTPRD00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	25	-	-	-	Red
HSTPRD00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPWH00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
HSTPWH00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	25	-	-	White
HSTPWH00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	White
HSTPWH0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	White
HSTPWH0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	White
HSTPWH0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	White
HSTPWH009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	White
HSTPWH009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	White
HSTPYL00946IPK25	3/32"	0.094	0.047	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
HSTPYL00944FPK25EA	3/32"	0.094	0.047	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	25	-	Yellow
HSTPYL00941000FRL	3/32"	0.094	0.047	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	Yellow
HSTPYL0094500FRL	3/32"	0.094	0.047	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	Yellow
HSTPYL0094250FRL	3/32"	0.094	0.047	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	Yellow
HSTPYL0094100FRL	3/32"	0.094	0.047	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	Yellow
HSTPYL009450FRL	3/32"	0.094	0.047	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	Yellow
HSTPYL009425FRL	3/32"	0.094	0.047	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	Yellow

REV	DATE	DESCRIPTION	EC	BY	C'HK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

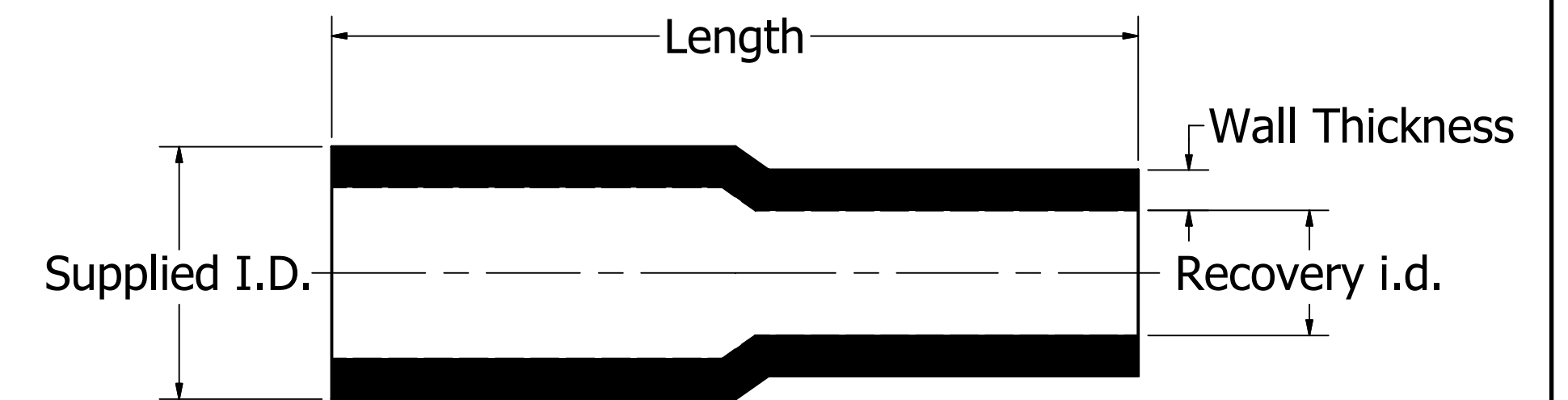

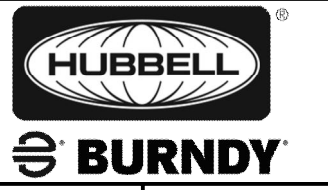TO ORDER BURNDY® PRODUCTS CALL		THIN WALL HEAT SHRINK	
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: SEE TABLE	
CANADA: 1-800-387-6487		CAT. NO: SEE TABLE	
FOR PRODUCT INFO: http://www.burndy.com		DRAWN BY: R.VASANTH 3/16/2023 CHECKER: B.NADEAU 3/29/2023 DSN APRVL: B.NADEAU 4/26/2023 MFG APRVL: L.RUFFIN 5/26/2023 QA APRVL: J.BRODEUR 5/4/2023 MKT APRVL: B.MICHAUD 4/26/2023	
			
		PROJECT #: -- SIZE: D DOCUMENT TYPE: SALES REL LEVEL: Released	
		DRAWING NO: 50139507 SHEET 4 OF 17	
		REV: A	

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color								Product Color	
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)		Yellow/Green (YG)
HSTPMX01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
HSTPBK01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBL01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPCL01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCL01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCL01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPGR01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
HSTPGR01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	25	-	-	-	-	-	Green
HSTPGR01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPOR01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
HSTPOR01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	25	-	-	-	-	Orange
HSTPOR01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPRD01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
HSTPRD01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	25	-	-	-	Red
HSTPRD01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPWH01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
HSTPWH01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	25	-	-	White
HSTPWH01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPYL01256IPK25	1/8"	0.125	0.063	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
HSTPYL01254FPK25EA	1/8"	0.125	0.063	0.020	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	25	-	Yellow
HSTPYL01251000FRL	1/8"	0.125	0.063	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL0125500FRL	1/8"	0.125	0.063	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL0125250FRL	1/8"	0.125	0.063	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL0125100FRL	1/8"	0.125	0.063	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL012550FRL	1/8"	0.125	0.063	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL012525FRL	1/8"	0.125	0.063	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYG01256IPK25	1/8"	0.125	0.039	0.022	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow/Green
HSTPYG01254FPK25EA	1/8"	0.125	0.039	0.022	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	25	-	Yellow/Green
HSTPYG0125500FRL	1/8"	0.125	0.039	0.022	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green
HSTPYG0125250FRL	1/8"	0.125	0.039	0.022	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green
HSTPYG0125100FRL	1/8"	0.125	0.039	0.022	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green
HSTPYG012550FRL	1/8"	0.125	0.039	0.022	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green
HSTPYG012525FRL	1/8"	0.125	0.039	0.022	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green

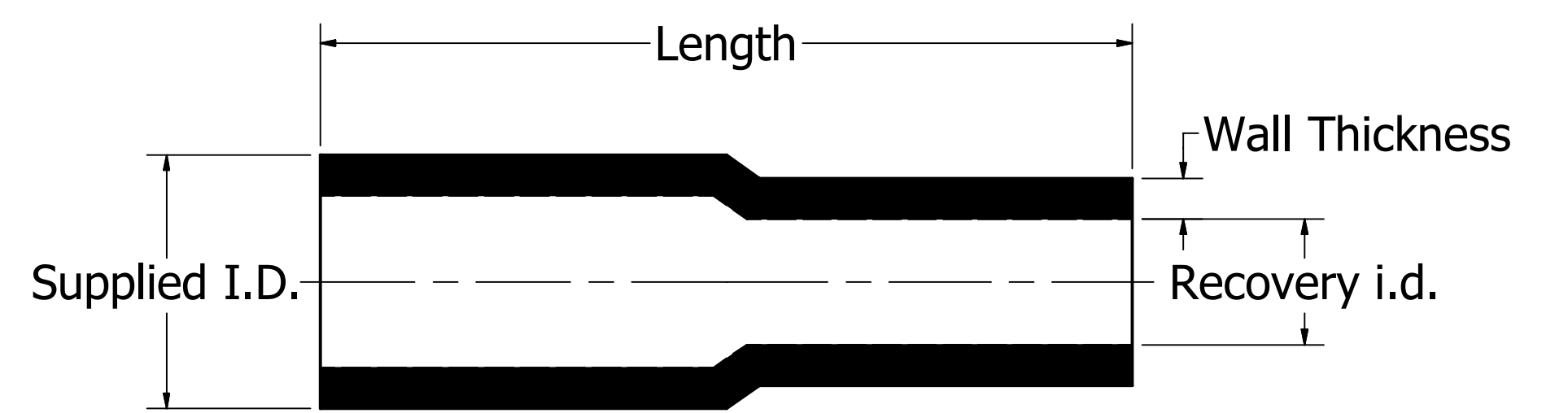


REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-387-6487 FOR PRODUCT INFO: http://www.burndy.com		THIN WALL HEAT SHRINK	
		ITEM NO: SEE TABLE CAT. NO: SEE TABLE DRAWN BY: R.VASANTH 3/16/2023 CHECKER: B.NADEAU 3/29/2023 DSN APRVL: B.NADEAU 4/26/2023 MFG APRVL: L.RUFFIN 5/26/2023 QA APRVL: J.BRODEUR 5/4/2023 MKT APRVL: B.MICHAUD 4/26/2023	
PROJECT #: -- DOCUMENT TYPE: SALES REL LEVEL: Released		DRAWING NO 50139507 SHEET 5 OF 17	
		A	



Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø id Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color								Product Color	
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)		Yellow/Green (YG)
HSTPMX01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
HSTPBK01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBL01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPCL01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCL01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCL01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPGR01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
HSTPGR01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	25	-	-	-	-	-	Green
HSTPGR01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPOR01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
HSTPOR01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	25	-	-	-	-	Orange
HSTPOR01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPRD01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
HSTPRD01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	25	-	-	-	Red
HSTPRD01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPWH01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
HSTPWH01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	25	-	-	White
HSTPWH01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPYL01876IPK25	3/16"	0.187	0.093	0.020	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
HSTPYL01874FPK25EA	3/16"	0.187	0.093	0.020	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	25	-	Yellow
HSTPYL01871000FRL	3/16"	0.187	0.093	0.020	600V	1000 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL0187500FRL	3/16"	0.187	0.093	0.020	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL0187250FRL	3/16"	0.187	0.093	0.020	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL0187100FRL	3/16"	0.187	0.093	0.020	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL018750FRL	3/16"	0.187	0.093	0.020	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL018725FRL	3/16"	0.187	0.093	0.020	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYG01876IPK25	3/16"	0.187	0.059	0.024	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	-	25	Yellow/Green
HSTPYG01874FPK25EA	3/16"	0.187	0.059	0.024	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	-	25	Yellow/Green
HSTPYG0187200FRL	3/16"	0.187	0.059	0.024	600V	200 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYG0187100FRL	3/16"	0.187	0.059	0.024	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYG018750FRL	3/16"	0.187	0.059	0.024	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYG018725FRL	3/16"	0.187	0.059	0.024	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green

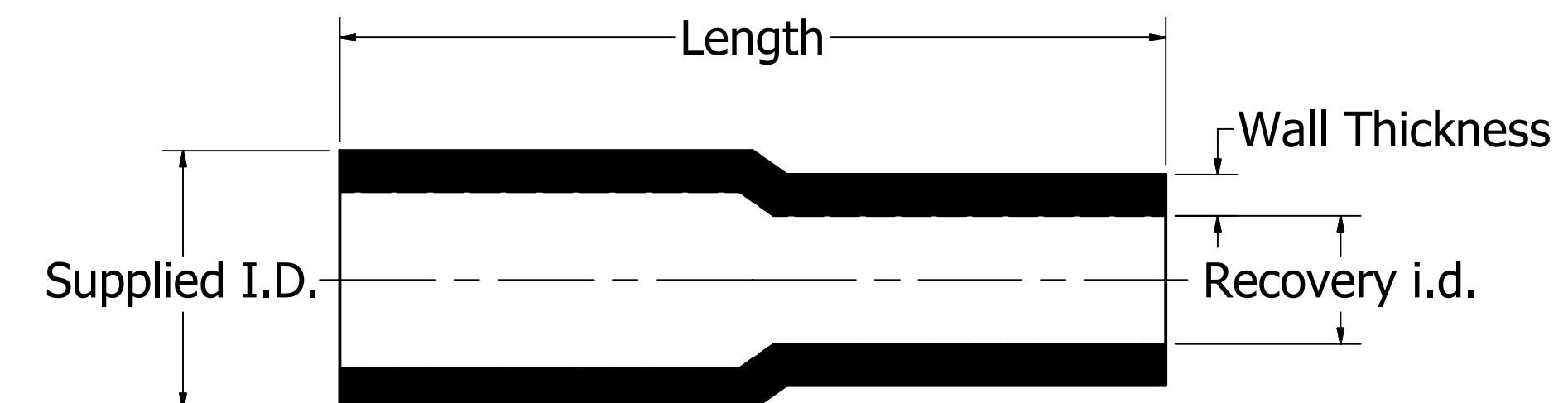


TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-387-6487 FOR PRODUCT INFO: http://www.burndy.com		THIN WALL HEAT SHRINK	
		ITEM NO: SEE TABLE CAT. NO: SEE TABLE DRAWN BY: R.VASANTH 3/16/2023 CHECKER: B.NADEAU 3/29/2023 DSN APRVL: B.NADEAU 4/26/2023 MFG APRVL: L.RUFFIN 5/26/2023 QA APRVL: J.BRODEUR 5/4/2023 MKT APRVL: B.MICHAUD 4/26/2023	
PROJECT #: -- DOCUMENT TYPE: SALES REL LEVEL: Released			
		DRAWING NO: 50139507 SHEET 6 OF 17	

REV	DATE	DESCRIPTION	EC	BY	C'H'K.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Product Color
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)	
HSTPMX02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
HSTPBK02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK02504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK0250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK025050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK025025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBL02506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL02504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL0250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL025050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL025025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPCLO2506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCLO2504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCLO250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCLO250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCLO250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCLO25050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCLO25025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPGRO2506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
HSTPGRO2504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	25	-	-	-	-	-	Green
HSTPGRO250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGRO250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGRO250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGRO25050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGRO25025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPORO2506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
HSTPORO2504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	25	-	-	-	-	Orange
HSTPORO250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPORO250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPORO250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPORO25050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPORO25025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPRDO2506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
HSTPRDO2504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	25	-	-	-	Red
HSTPRDO250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRDO250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRDO250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRDO25050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRDO25025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPWHO2506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
HSTPWHO2504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	25	-	-	White
HSTPWHO250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWHO250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWHO250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWHO25050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWHO25025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPYLO2506IPK25	1/4"	0.250	0.125	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	Yellow
HSTPYLO2504FPK25EA	1/4"	0.250	0.125	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	25	-	Yellow
HSTPYLO250500FRL	1/4"	0.250	0.125	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYLO250250FRL	1/4"	0.250	0.125	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYLO250100FRL	1/4"	0.250	0.125	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYLO25050FRL	1/4"	0.250	0.125	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYLO25025FRL	1/4"	0.250	0.125	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYGO2506IPK25	1/4"	0.250	0.079	0.026	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	-	25	Yellow/Green
HSTPYGO2504FPK25EA	1/4"	0.250	0.079	0.026	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	-	25	Yellow/Green
HSTPYGO250500FRL	1/4"	0.250	0.079	0.026	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYGO250250FRL	1/4"	0.250	0.079	0.026	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYGO250100FRL	1/4"	0.250	0.079	0.026	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYGO25050FRL	1/4"	0.250	0.079	0.026	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYGO25025FRL	1/4"	0.250	0.079	0.026	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green

REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

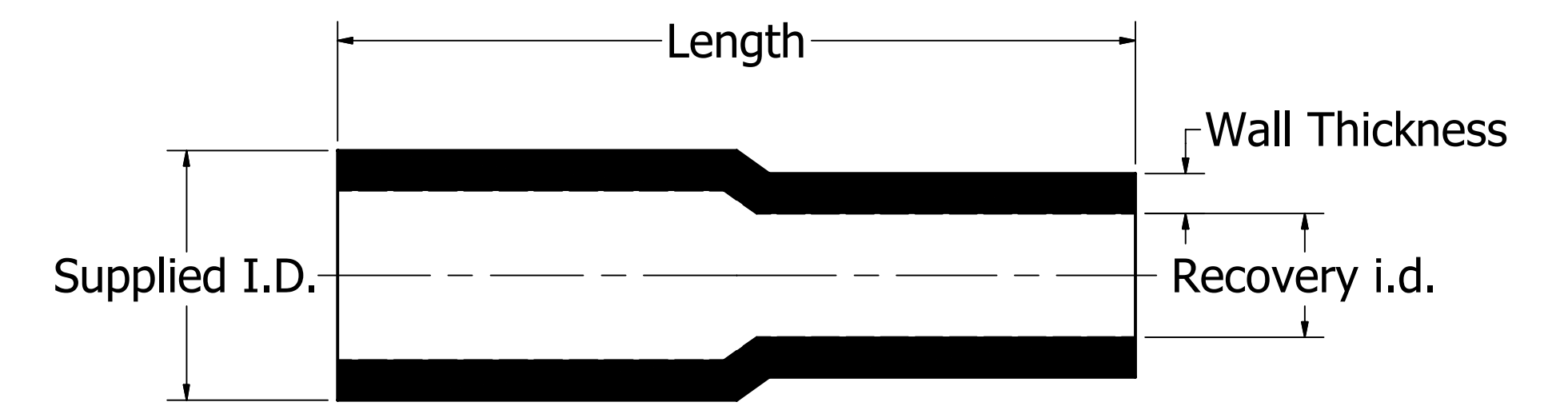


<p>TO ORDER BURNDY® PRODUCTS CALL</p> <p>UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)</p> <p>CANADA: 1-800-387-6487</p> <p>FOR PRODUCT INFO: http://www.burndy.com</p>	THIN WALL HEAT SHRINK	
	ITEM NO: SEE TABLE	
	CAT. NO: SEE TABLE	
	DRAWN BY: R.VASANTH	3/16/2023
	CHECKER: B.NADEAU	3/29/2023
	DSN APRVL: B.NADEAU	4/26/2023
	MFG APRVL: L.RUFFIN	5/26/2023
	QA APRVL: J.BRODEUR	5/4/2023
	MKT APRVL: B.MICHAUD	4/26/2023
	PROD FAM: --	DRAWING NO
PROJECT #: --	SIZE	
DOCUMENT TYPE: SALES	D	
REL LEVEL: Released	SHEET 7 OF 17	
	50139507	
	A	



Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color										Product Color
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)		
HSTPMX03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed	
HSTPBK03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black	
HSTPBK03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	25	-	-	-	-	-	-	-	-	Black	
HSTPBK0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black	
HSTPBK0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black	
HSTPBK0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black	
HSTPBK037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black	
HSTPBK037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black	
HSTPBL03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue	
HSTPBL03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	25	-	-	-	-	-	-	-	Blue	
HSTPBL0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue	
HSTPBL0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue	
HSTPBL0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue	
HSTPBL037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue	
HSTPBL037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue	
HSTPCL03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear	
HSTPCL03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	25	-	-	-	-	-	-	Clear	
HSTPCL0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear	
HSTPCL0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear	
HSTPCL0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear	
HSTPCL037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear	
HSTPCL037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear	
HSTPGR03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green	
HSTPGR03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	25	-	-	-	-	-	Green	
HSTPGR0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green	
HSTPGR0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green	
HSTPGR0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green	
HSTPGR037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green	
HSTPGR037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green	
HSTPOR03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange	
HSTPOR03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	25	-	-	-	-	Orange	
HSTPOR0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange	
HSTPOR0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange	
HSTPOR0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange	
HSTPOR037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange	
HSTPOR037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange	
HSTPRD03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red	
HSTPRD03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	25	-	-	-	Red	
HSTPRD0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red	
HSTPRD0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red	
HSTPRD0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red	
HSTPRD037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red	
HSTPRD037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red	
HSTPWH03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White	
HSTPWH03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	25	-	-	White	
HSTPWH0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White	
HSTPWH0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White	
HSTPWH0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White	
HSTPWH037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White	
HSTPWH037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White	
HSTPYL03756IPK25	3/8"	0.375	0.187	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow	
HSTPYL03754FPK25EA	3/8"	0.375	0.187	0.025	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	25	-	Yellow	
HSTPYL0375500FRL	3/8"	0.375	0.187	0.025	600V	500 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow	
HSTPYL0375250FRL	3/8"	0.375	0.187	0.025	600V	250 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow	
HSTPYL0375100FRL	3/8"	0.375	0.187	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow	
HSTPYL037550FRL	3/8"	0.375	0.187	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow	
HSTPYL037525FRL	3/8"	0.375	0.187	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow	
HSTPYG03756IPK25	3/8"	0.375	0.118	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow/Green	
HSTPYG03754FPK25EA	3/8"	0.375	0.118	0.030	600V	Multi-Pack (4" Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	25	-	Yellow/Green	
HSTPYG0375200FRL	3/8"	0.375	0.118	0.030	600V	200 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green	
HSTPYG0375100FRL	3/8"	0.375	0.118	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green	
HSTPYG037550FRL	3/8"	0.375	0.118	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green	
HSTPYG037525FRL	3/8"	0.375	0.118	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green	


REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

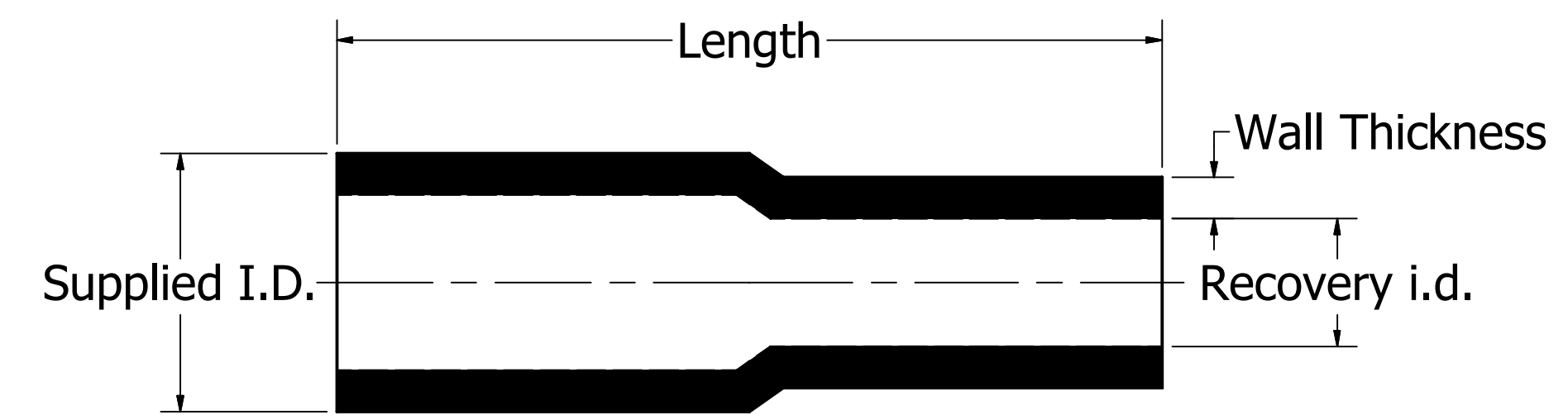

TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-387-6487 FOR PRODUCT INFO: http://www.burndy.com	THIN WALL HEAT SHRINK	
	ITEM NO: SEE TABLE CAT. NO: SEE TABLE DRAWN BY: R.VASANTH 3/16/2023 CHECKER: B.NADEAU 3/29/2023 DSN APRVL: B.NADEAU 4/26/2023 MFG APRVL: L.RUFFIN 5/26/2023 QA APRVL: J.BRODEUR 5/4/2023 MKT APRVL: B.MICHAUD 4/26/2023	
PROJECT #: -- DOCUMENT TYPE: SALES REL LEVEL: Released	SIZE D	DRAWING NO 50139507 SHEET 8 OF 17
		A

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø id Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color								Product Color	
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)		Yellow/Green (YG)
HSTPMX05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
HSTPBK05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBL05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPCL05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCL05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCL0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPGR05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
HSTPGR05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	25	-	-	-	-	-	Green
HSTPGR0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPOR05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
HSTPOR05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	25	-	-	-	-	Orange
HSTPOR0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPRD05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
HSTPRD05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	25	-	-	-	Red
HSTPRD0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPWH05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
HSTPWH05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	25	-	-	White
HSTPWH0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPYL05006IPK25	1/2"	0.500	0.250	0.025	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
HSTPYL05004FPK25EA	1/2"	0.500	0.250	0.025	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	25	-	Yellow
HSTPYL0500200FRL	1/2"	0.500	0.250	0.025	600V	200 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL0500100FRL	1/2"	0.500	0.250	0.025	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL050050FRL	1/2"	0.500	0.250	0.025	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL050025FRL	1/2"	0.500	0.250	0.025	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYG05006IPK25	1/2"	0.500	0.157	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	-	25	Yellow/Green
HSTPYG05004FPK25EA	1/2"	0.500	0.157	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	25	25 piece increments	25	-	-	-	-	-	-	-	-	25	Yellow/Green
HSTPYG0500200FRL	1/2"	0.500	0.157	0.030	600V	200 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYG0500100FRL	1/2"	0.500	0.157	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYG050050FRL	1/2"	0.500	0.157	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYG050025FRL	1/2"	0.500	0.157	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green


REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

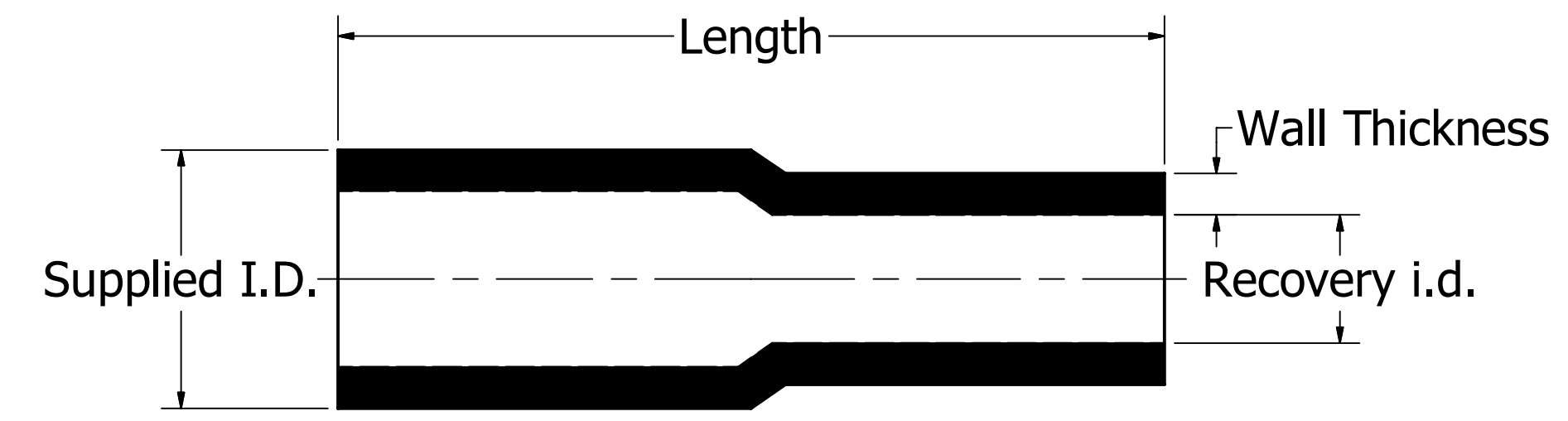


TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-387-6487 FOR PRODUCT INFO: http://www.burndy.com		THIN WALL HEAT SHRINK	
		ITEM NO: SEE TABLE CAT. NO: SEE TABLE	
DRAWN BY: R.VASANTH 3/16/2023			
CHECKER: B.NADEAU 3/29/2023			
DSN APRVL: B.NADEAU 4/26/2023			
MFG APRVL: L.RUFFIN 5/26/2023			
QA APRVL: J.BRODEUR 5/4/2023			
MKT APRVL: B.MICHAUD 4/26/2023		DRAWING NO	
PROJECT #: --		50139507	
DOCUMENT TYPE: SALES		SHEET 9 OF 17	
REL LEVEL: Released		REV A	

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø id Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color								Product Color	
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)		Yellow/Green (YG)
HSTPMX06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
HSTPBK06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	5	-	-	-	-	-	-	-	-	Black
HSTPBK0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBL06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	5	-	-	-	-	-	-	-	Blue
HSTPBL0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPCL06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCL06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	5	-	-	-	-	-	-	Clear
HSTPCL0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPGR06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
HSTPGR06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	5	-	-	-	-	-	Green
HSTPGR0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPOR06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
HSTPOR06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	5	-	-	-	-	Orange
HSTPOR0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPRD06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
HSTPRD06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	5	-	-	-	Red
HSTPRD0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPWH06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
HSTPWH06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	5	-	-	White
HSTPWH0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPYL06256IPK25	5/8"	0.625	0.313	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
HSTPYL06254FPK5EA	5/8"	0.625	0.313	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	-	5	-	Yellow
HSTPYL0625200FRL	5/8"	0.625	0.313	0.030	600V	200 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL0625100FRL	5/8"	0.625	0.313	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL062550FRL	5/8"	0.625	0.313	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL062525FRL	5/8"	0.625	0.313	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow


REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

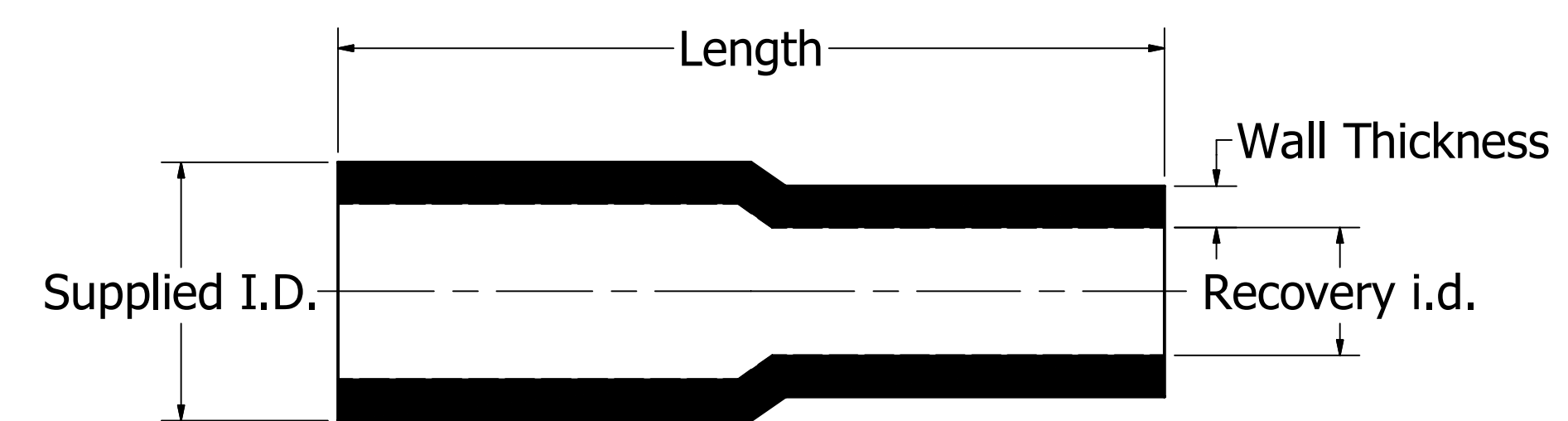


TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-387-6487 FOR PRODUCT INFO: http://www.burndy.com	THIN WALL HEAT SHRINK			
	ITEM NO: SEE TABLE			
	CAT. NO: SEE TABLE			
	DRAWN BY: R.VASANTH	3/16/2023		
	CHECKER: B.NADEAU	3/29/2023		
	DSN APRVL: B.NADEAU	4/26/2023		
	MFG APRVL: L.RUFFIN	5/26/2023		
	QA APRVL: J.BRODEUR	5/4/2023		
	MKT APRVL: B.MICHAUD	4/26/2023		
	PROJECT #: --	SIZE	DRAWING NO	REV
DOCUMENT TYPE: SALES	D	50139507	A	
REL LEVEL: Released		SHEET 10 OF 17		

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø id Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color								Product Color
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	
HSTPMX07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	7	3	3	-	3	3	3	-	Mixed
HSTPBK07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	Black
HSTPBK07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	5	-	-	-	-	-	-	-	Black
HSTPBK0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	Black
HSTPBK075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	Black
HSTPBK075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	Black
HSTPBL07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	Blue
HSTPBL07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	5	-	-	-	-	-	-	Blue
HSTPBL0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	Blue
HSTPBL075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	Blue
HSTPBL075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	Blue
HSTPCL07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	Clear
HSTPCL07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	5	-	-	-	-	-	Clear
HSTPCL0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	Clear
HSTPCL075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	Clear
HSTPCL075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	Clear
HSTPGR07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	Green
HSTPGR07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	5	-	-	-	-	Green
HSTPGR0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	Green
HSTPGR075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	Green
HSTPGR075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	Green
HSTPOR07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	Orange
HSTPOR07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	5	-	-	-	Orange
HSTPOR0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	Orange
HSTPOR075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	Orange
HSTPOR075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	Orange
HSTPRD07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	Red
HSTPRD07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	5	-	-	Red
HSTPRD0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	Red
HSTPRD075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	Red
HSTPRD075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	Red
HSTPWH07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	White
HSTPWH07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	5	-	White
HSTPWH0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	White
HSTPWH075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	White
HSTPWH075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	White
HSTPYL07506IPK25	3/4"	0.750	0.375	0.030	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	Yellow
HSTPYL07504FPK5EA	3/4"	0.750	0.375	0.030	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	5	-	Yellow
HSTPYL0750100FRL	3/4"	0.750	0.375	0.030	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	Yellow
HSTPYL075050FRL	3/4"	0.750	0.375	0.030	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	Yellow
HSTPYL075025FRL	3/4"	0.750	0.375	0.030	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	Yellow
HSTPYG07506IPK25	3/4"	0.750	0.236	0.033	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	Yellow/Green
HSTPYG07504FPK5EA	3/4"	0.750	0.236	0.033	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	-	5	Yellow/Green
HSTPYG0750100FRL	3/4"	0.750	0.236	0.033	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYG075050FRL	3/4"	0.750	0.236	0.033	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYG075025FRL	3/4"	0.750	0.236	0.033	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	Yellow/Green


REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

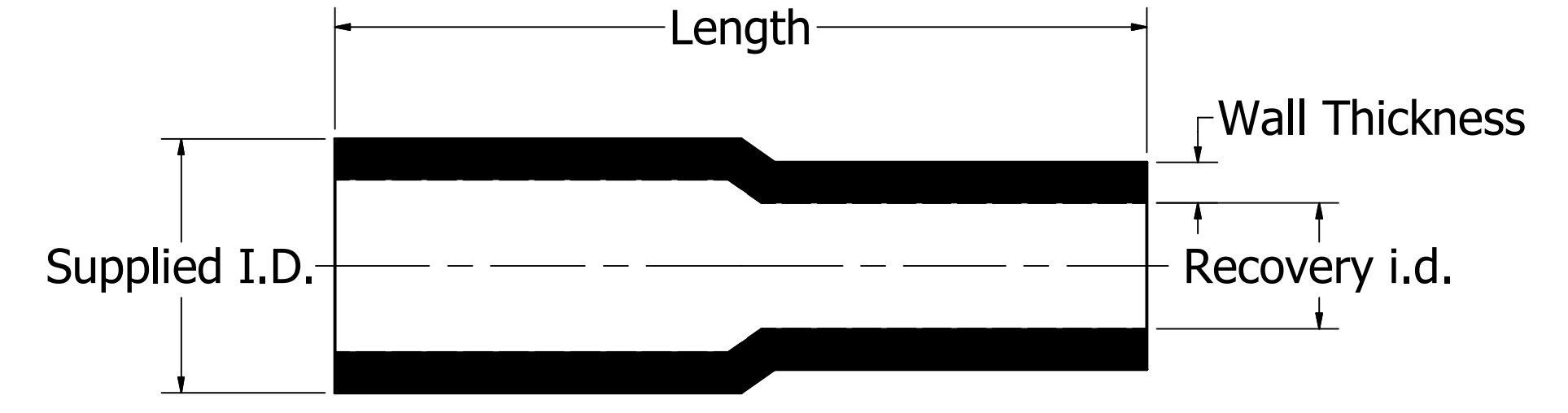

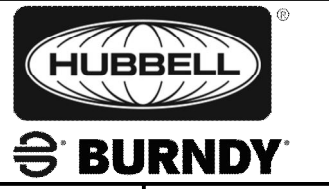TO ORDER BURNDY® PRODUCTS CALL		THIN WALL HEAT SHRINK	
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: SEE TABLE	
CANADA: 1-800-387-6487		CAT. NO: SEE TABLE	
FOR PRODUCT INFO: http://www.burndy.com		DRAWN BY: R.VASANTH 3/16/2023 CHECKER: B.NADEAU 3/29/2023 DSN APRVL: B.NADEAU 4/26/2023 MFG APRVL: L.RUFFIN 5/26/2023 QA APRVL: J.BRODEUR 5/4/2023 MKT APRVL: B.MICHAUD 4/26/2023	
			
		PROJECT #: -- SIZE: D DOCUMENT TYPE: SALES REL LEVEL: Released	
		DRAWING NO: 50139507 SHEET 11 OF 17	
		REV: A	

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø id Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color								Product Color	
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)		Yellow/Green (YG)
HSTPMX10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	7	3	3	3	-	3	3	3	-	Mixed
HSTPBK10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	25	-	-	-	-	-	-	-	-	Black
HSTPBK10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	5	-	-	-	-	-	-	-	-	Black
HSTPBK1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBL10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	25	-	-	-	-	-	-	-	Blue
HSTPBL10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	5	-	-	-	-	-	-	-	Blue
HSTPBL1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPCL10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	25	-	-	-	-	-	-	Clear
HSTPCL10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	5	-	-	-	-	-	-	Clear
HSTPCL1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPGR10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	25	-	-	-	-	-	Green
HSTPGR10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	5	-	-	-	-	-	Green
HSTPGR1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPOR10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	25	-	-	-	-	Orange
HSTPOR10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	5	-	-	-	-	Orange
HSTPOR1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPRD10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	25	-	-	-	Red
HSTPRD10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	5	-	-	-	Red
HSTPRD1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPWH10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	25	-	-	White
HSTPWH10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	5	-	-	White
HSTPWH1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPYL10006IPK25	1"	1.000	0.500	0.035	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	25	-	Yellow
HSTPYL10004FPK5EA	1"	1.000	0.500	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	-	5	-	Yellow
HSTPYL1000100FRL	1"	1.000	0.500	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL100050FRL	1"	1.000	0.500	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL100025FRL	1"	1.000	0.500	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYG10006IPK25	1"	1.000	0.315	0.039	600V	Multi-Pack (6" Lengths)	1	1 pack of 25 pieces	25	-	-	-	-	-	-	-	-	25	Yellow/Green
HSTPYG10004FPK5EA	1"	1.000	0.315	0.039	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	-	-	5	Yellow/Green
HSTPYG1000100FRL	1"	1.000	0.315	0.039	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYG100050FRL	1"	1.000	0.315	0.039	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green
HSTPYG100025FRL	1"	1.000	0.315	0.039	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	-	1	Yellow/Green


REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

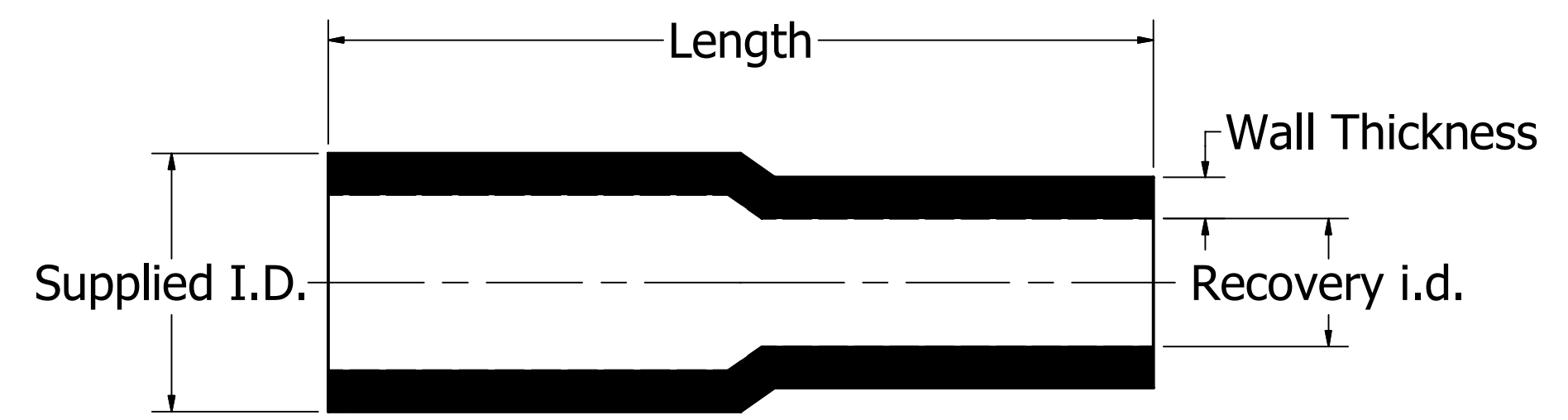

TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-387-6487 FOR PRODUCT INFO: http://www.burndy.com	THIN WALL HEAT SHRINK			
	ITEM NO: SEE TABLE			
	CAT. NO: SEE TABLE			
	DRAWN BY: R.VASANTH	3/16/2023		
	CHECKER: B.NADEAU	3/29/2023		
	DSN APRVL: B.NADEAU	4/26/2023		
	MFG APRVL: L.RUFFIN	5/26/2023		
	QA APRVL: J.BRODEUR	5/4/2023		
	MKT APRVL: B.MICHAUD	4/26/2023		
	PROD FAM: --		DRAWING NO	REV
PROJECT #: --	SIZE	50139507	A	
DOCUMENT TYPE: SALES	D	SHEET 12 OF 17		
REL LEVEL: Released				

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø id Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color									Product Color	
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)	Yellow/Green (YG)		
HSTPBK12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	5	-	-	-	-	-	-	-	-	-	Black
HSTPBK1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	-	Black
HSTPBK125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	-	Black
HSTPBK125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	-	Black
HSTPBL12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	5	-	-	-	-	-	-	-	-	Blue
HSTPBL1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	-	Blue
HSTPBL125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	-	Blue
HSTPBL125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	-	Blue
HSTPCL12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	5	-	-	-	-	-	-	-	Clear
HSTPCL1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	-	Clear
HSTPCL125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	-	Clear
HSTPCL125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	-	Clear
HSTPGR12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	5	-	-	-	-	-	-	Green
HSTPGR1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	-	Green
HSTPGR125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	-	Green
HSTPGR125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	-	Green
HSTPOR12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	5	-	-	-	-	-	Orange
HSTPOR1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	-	Orange
HSTPOR125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	-	Orange
HSTPOR125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	-	Orange
HSTPRD12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	5	-	-	-	-	Red
HSTPRD1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	-	Red
HSTPRD125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	-	Red
HSTPRD125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	-	Red
HSTPWH12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	5	-	-	-	White
HSTPWH1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	-	White
HSTPWH125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	-	White
HSTPWH125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	-	White
HSTPYL12504FPK5EA	1-1/4"	1.250	0.625	0.035	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	-	5	-	-	Yellow
HSTPYL1250100FRL	1-1/4"	1.250	0.625	0.035	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	-	Yellow
HSTPYL125050FRL	1-1/4"	1.250	0.625	0.035	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	-	Yellow
HSTPYL125025FRL	1-1/4"	1.250	0.625	0.035	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	-	Yellow

REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

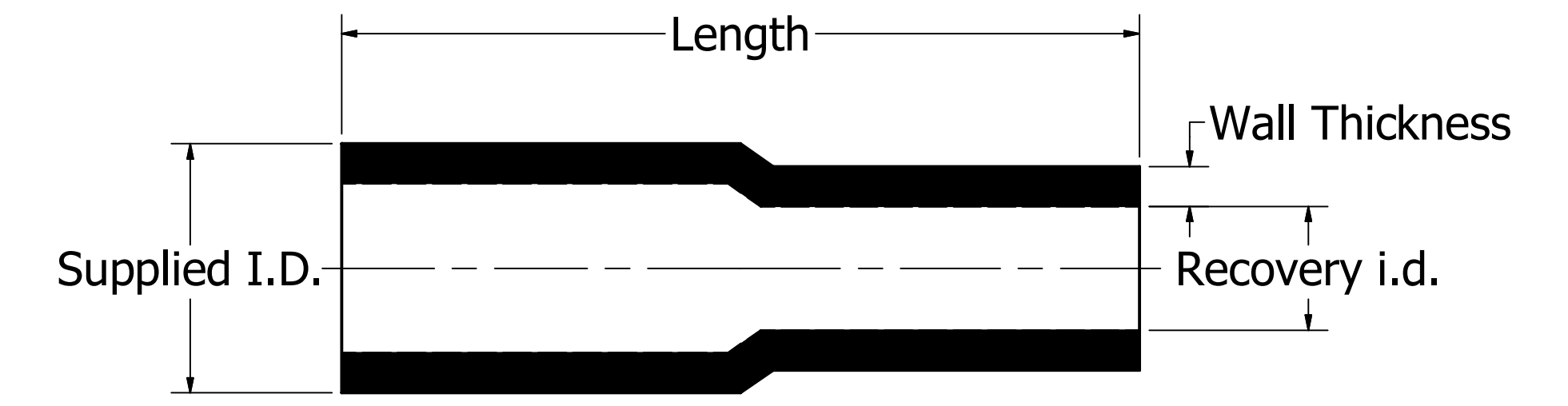



TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-387-6487 FOR PRODUCT INFO: http://www.burndy.com	THIN WALL HEAT SHRINK			
	ITEM NO: SEE TABLE			
	CAT. NO: SEE TABLE			
	DRAWN BY: R.VASANTH		3/16/2023	
	CHECKER: B.NADEAU		3/29/2023	
	DSN APRVL: B.NADEAU		4/26/2023	
	MFG APRVL: L.RUFFIN		5/26/2023	
	QA APRVL: J.BRODEUR		5/4/2023	
	MKT APRVL: B.MICHAUD		4/26/2023	
	PROD FAM: --		DRAWING NO	
PROJECT #: --		SIZE		
DOCUMENT TYPE: SALES		D		
REL LEVEL: Released		SHEET 13 OF 17		
			50139507	
			A	



Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø id Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color								Product Color	
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)		Yellow/Green (YG)
HSTPBK15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	5	-	-	-	-	-	-	-	-	Black
HSTPBK1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBL15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	5	-	-	-	-	-	-	-	Blue
HSTPBL1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPCL15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	5	-	-	-	-	-	-	Clear
HSTPCL1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPGR15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	5	-	-	-	-	-	Green
HSTPGR1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPOR15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	5	-	-	-	-	Orange
HSTPOR1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPRD15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	5	-	-	-	Red
HSTPRD1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPWH15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	5	-	-	White
HSTPWH1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPYL15004FPK5EA	1-1/2"	1.500	0.750	0.040	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	-	5	-	Yellow
HSTPYL1500100FRL	1-1/2"	1.500	0.750	0.040	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL150050FRL	1-1/2"	1.500	0.750	0.040	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL150025FRL	1-1/2"	1.500	0.750	0.040	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYG15004FPK5EA	1-1/2"	1.500	0.512	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	-	5	-	Yellow/Green
HSTPYG1500100FRL	1-1/2"	1.500	0.512	0.045	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green
HSTPYG150050FRL	1-1/2"	1.500	0.512	0.045	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green
HSTPYG150025FRL	1-1/2"	1.500	0.512	0.045	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow/Green

REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

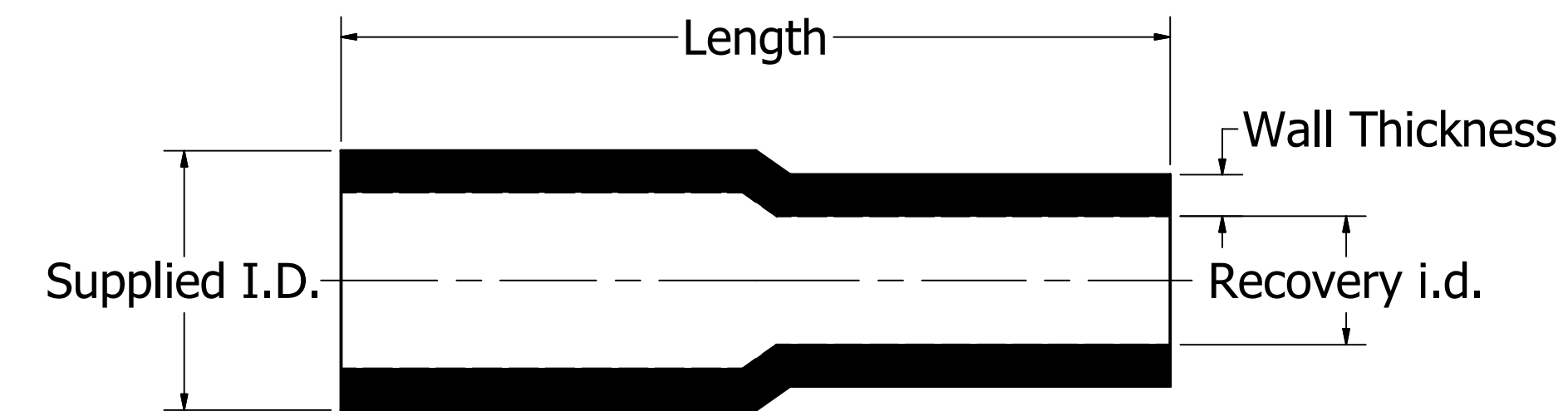


TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-387-6487 FOR PRODUCT INFO: http://www.burndy.com	THIN WALL HEAT SHRINK	
	ITEM NO: SEE TABLE	
	CAT. NO: SEE TABLE	
	DRAWN BY: R.VASANTH 3/16/2023 CHECKER: B.NADEAU 3/29/2023 DSN APRVL: B.NADEAU 4/26/2023 MFG APRVL: L.RUFFIN 5/26/2023 QA APRVL: J.BRODEUR 5/4/2023 MKT APRVL: B.MICHAUD 4/26/2023	
	PROJECT #: -- DOCUMENT TYPE: SALES REL LEVEL: Released	SIZE D

REV
A

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø ID Max.	Wall Thickness	Voltage Rating	Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color								Product Color	
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)		Yellow/Green (YG)
HSTPBK20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	5	-	-	-	-	-	-	-	-	Black
HSTPBK2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBL20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	5	-	-	-	-	-	-	-	Blue
HSTPBL2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPCL20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	5	-	-	-	-	-	-	Clear
HSTPCL2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPGR20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	5	-	-	-	-	-	Green
HSTPGR2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPOR20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	5	-	-	-	-	Orange
HSTPOR2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPRD20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	5	-	-	-	Red
HSTPRD2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPWH20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	5	-	-	White
HSTPWH2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPYL20004FPK5EA	2"	2.000	1.000	0.045	600V	Multi-Pack (4' Lengths) Sold by Each	5	5 piece increments	5	-	-	-	-	-	-	-	5	-	Yellow
HSTPYL2000100FRL	2"	2.000	1.000	0.045	600V	100 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL200050FRL	2"	2.000	1.000	0.045	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL200025FRL	2"	2.000	1.000	0.045	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPBK30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	2	-	-	-	-	-	-	-	-	Black
HSTPBK300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBL30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	2	-	-	-	-	-	-	-	Blue
HSTPBL300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPCL30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	2	-	-	-	-	-	-	Clear
HSTPCL300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPGR30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	-	2	-	-	-	-	-	Green
HSTPGR300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPOR30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	-	-	2	-	-	-	-	Orange
HSTPOR300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPRD30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	-	-	-	2	-	-	-	Red
HSTPRD300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPWH30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	-	-	-	-	2	-	-	White
HSTPWH300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPYL30004FPK2EA	3"	3.000	1.500	0.050	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	-	-	-	-	-	2	-	Yellow
HSTPYL300050FRL	3"	3.000	1.500	0.050	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL300025FRL	3"	3.000	1.500	0.050	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow


REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

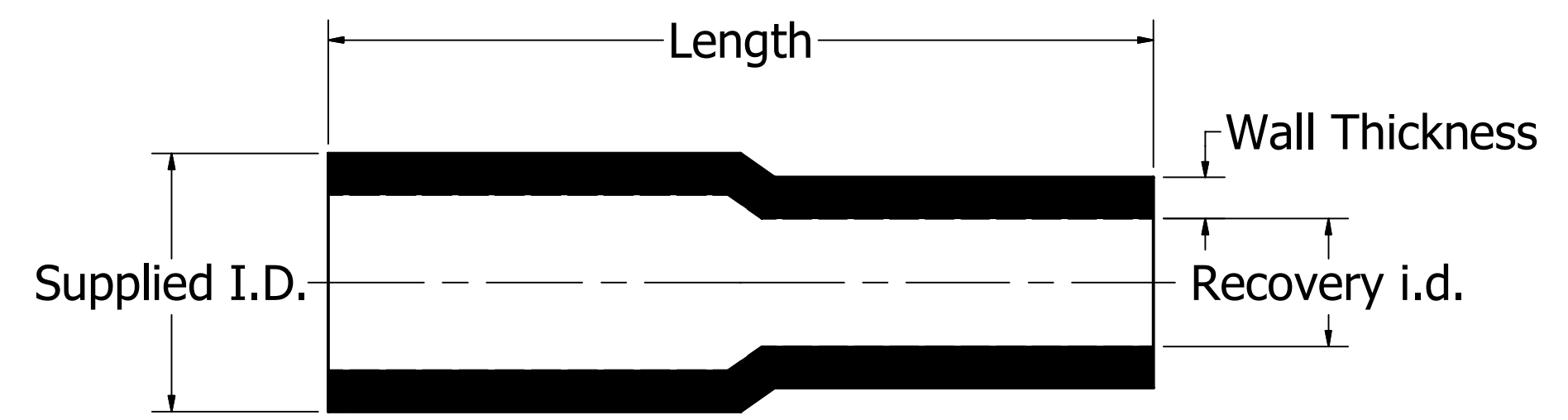

TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-387-6487 FOR PRODUCT INFO: http://www.burndy.com		THIN WALL HEAT SHRINK	
		ITEM NO: SEE TABLE CAT. NO: SEE TABLE	
DRAWN BY: R.VASANTH 3/16/2023 CHECKER: B.NADEAU 3/29/2023 DSN APRVL: B.NADEAU 4/26/2023 MFG APRVL: L.RUFFIN 5/26/2023 QA APRVL: J.BRODEUR 5/4/2023 MKT APRVL: B.MICHAUD 4/26/2023			
PROJECT #: -- DOCUMENT TYPE: SALES REL LEVEL: Released		DRAWING NO 50139507 SHEET 15 OF 17	
		SIZE D REV A	

Catalog Number	Nominal Size	Supplied Ø ID Min.	Recovery Ø id Max.	Wall Thickness	Voltage Rating	2 Package Type	Min Order Quantity	Package Quantity	Total Pieces Per Pack	Quantity of Each Color								Product Color	
										Black (BK)	Blue (BL)	Clear (CL)	Green (GR)	Orange (OR)	Red (RD)	White (WH)	Yellow (YL)		Yellow/Green (YG)
HSTPBK40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	2	-	-	-	-	-	-	-	-	Black
HSTPBK400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBK400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1	1 Reel	1	1	-	-	-	-	-	-	-	-	Black
HSTPBL40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	2	-	-	-	-	-	-	-	Blue
HSTPBL400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPBL400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1	1 Reel	1	-	1	-	-	-	-	-	-	-	Blue
HSTPCL40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	-	2	-	-	-	-	-	Clear
HSTPCL400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPCL400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1	1 Reel	1	-	-	1	-	-	-	-	-	-	Clear
HSTPGR40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	-	2	-	-	-	-	-	Green
HSTPGR400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPGR400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1	1 Reel	1	-	-	-	1	-	-	-	-	-	Green
HSTPOR40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	-	-	2	-	-	-	-	Orange
HSTPOR400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPOR400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	1	-	-	-	-	Orange
HSTPRD40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	-	-	-	2	-	-	-	Red
HSTPRD400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPRD400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	1	-	-	-	Red
HSTPWH40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	-	-	-	-	2	-	-	White
HSTPWH400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPWH400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	1	-	-	White
HSTPYL40004FPK2EA	4"	4.000	2.000	0.055	600V	Multi-Pack (4' Lengths) Sold by Each	2	2 piece increments	2	-	-	-	-	-	-	-	2	-	Yellow
HSTPYL400050FRL	4"	4.000	2.000	0.055	600V	50 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow
HSTPYL400025FRL	4"	4.000	2.000	0.055	600V	25 Foot Reel	1	1 Reel	1	-	-	-	-	-	-	-	1	-	Yellow

REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR

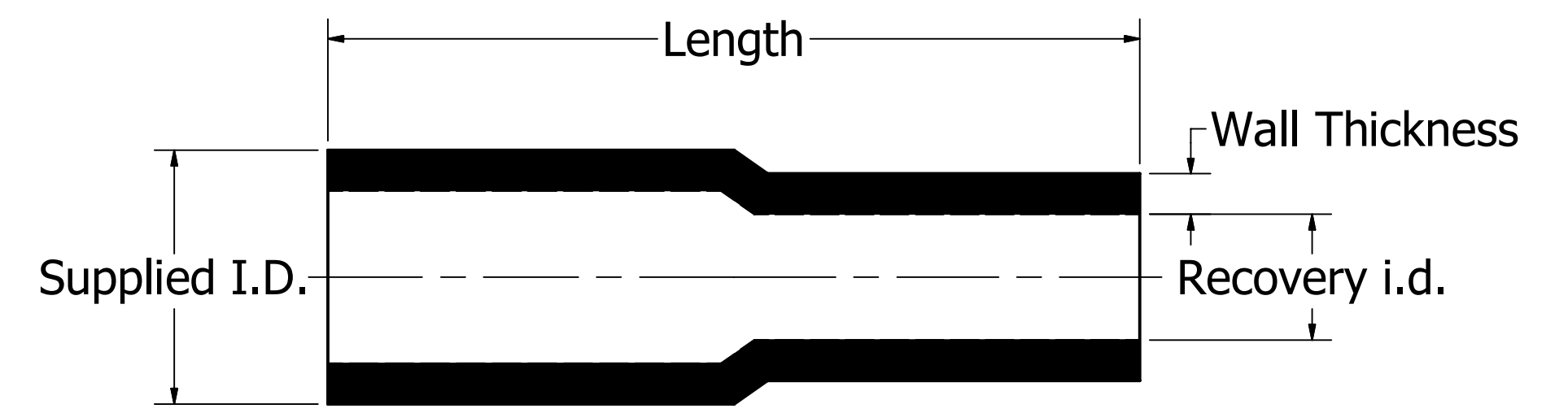

TO ORDER BURNDY® PRODUCTS CALL		THIN WALL HEAT SHRINK														
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: SEE TABLE														
CANADA: 1-800-387-6487		CAT. NO: SEE TABLE														
FOR PRODUCT INFO: http://www.burndy.com		<table border="1"> <tr> <td>DRAWN BY: R.VASANTH</td> <td>3/16/2023</td> <td rowspan="6"> </td> </tr> <tr> <td>CHECKER: B.NADEAU</td> <td>3/29/2023</td> </tr> <tr> <td>DSN APRVL: B.NADEAU</td> <td>4/26/2023</td> </tr> <tr> <td>MFG APRVL: L.RUFFIN</td> <td>5/26/2023</td> </tr> <tr> <td>QA APRVL: J.BRODEUR</td> <td>5/4/2023</td> </tr> <tr> <td>MKT APRVL: B.MICHAUD</td> <td>4/26/2023</td> </tr> </table>		DRAWN BY: R.VASANTH	3/16/2023		CHECKER: B.NADEAU	3/29/2023	DSN APRVL: B.NADEAU	4/26/2023	MFG APRVL: L.RUFFIN	5/26/2023	QA APRVL: J.BRODEUR	5/4/2023	MKT APRVL: B.MICHAUD	4/26/2023
DRAWN BY: R.VASANTH	3/16/2023															
CHECKER: B.NADEAU	3/29/2023															
DSN APRVL: B.NADEAU	4/26/2023															
MFG APRVL: L.RUFFIN	5/26/2023															
QA APRVL: J.BRODEUR	5/4/2023															
MKT APRVL: B.MICHAUD	4/26/2023															
		DRAWING NO	REV													
		50139507	A													
		SHEET 16 OF 17														

REV	DATE	DESCRIPTION	EC	BY	CHK.
A	03/16/2023	CREATED NEW SALES DRAWING	230316028751	RA	YR



Splice Installation Instructions



ATTENTION


REFERENCE MASTER CATALOG, SALES DRAWING, WEBSITE AND/OR CONNECT APPLICATION FOR TOOL/DIE & ADDITIONAL INSTALLATION INFORMATION.

INSTALLATION

- Strip the insulation to the appropriate length based on the wire strip length recommendations for the selected connector. Strip lengths can be found in the Burndy master catalog, website or sales drawing. Be careful not to nick the cable strands which may result in cut/broken wire.
- Slide heat shrink over cable, (figure 1)
- Fully insert the conductor into barrel 1. If the connector has an inspection window, the conductor will be visible in the window, confirming full wire insertion, (figure 2).
- Apply the proper number of crimps specified. Crimp between the markings, always crimp from center going outward, repeat crimping process for barrel 2, (figure 3).
- Once the splice is fully crimped, slide the heat shrink over the center of the completed assembly and apply heat until full shrinkage is obtained, (figure 4).
- The shrink temperature is 194°F (90°C) min. If using BMSG1100 tool, use low setting (500°F) and place heat gun approximately six inches from the tubing surface. DO NOT USE THE DEFLECTOR.
- Apply heat evenly, radially, starting at the center and working outwards. When shrink tube has taken contour of the item being covered, installation is complete, (finished installation image).

CAUTION

To prevent damage to the tubing, DO NOT OVERHEAT! Always apply heat uniformly using a back and forth motion. DO NOT FOCUS the heat gun over area. Focusing the heat over one area will cause the tube to melt/split.

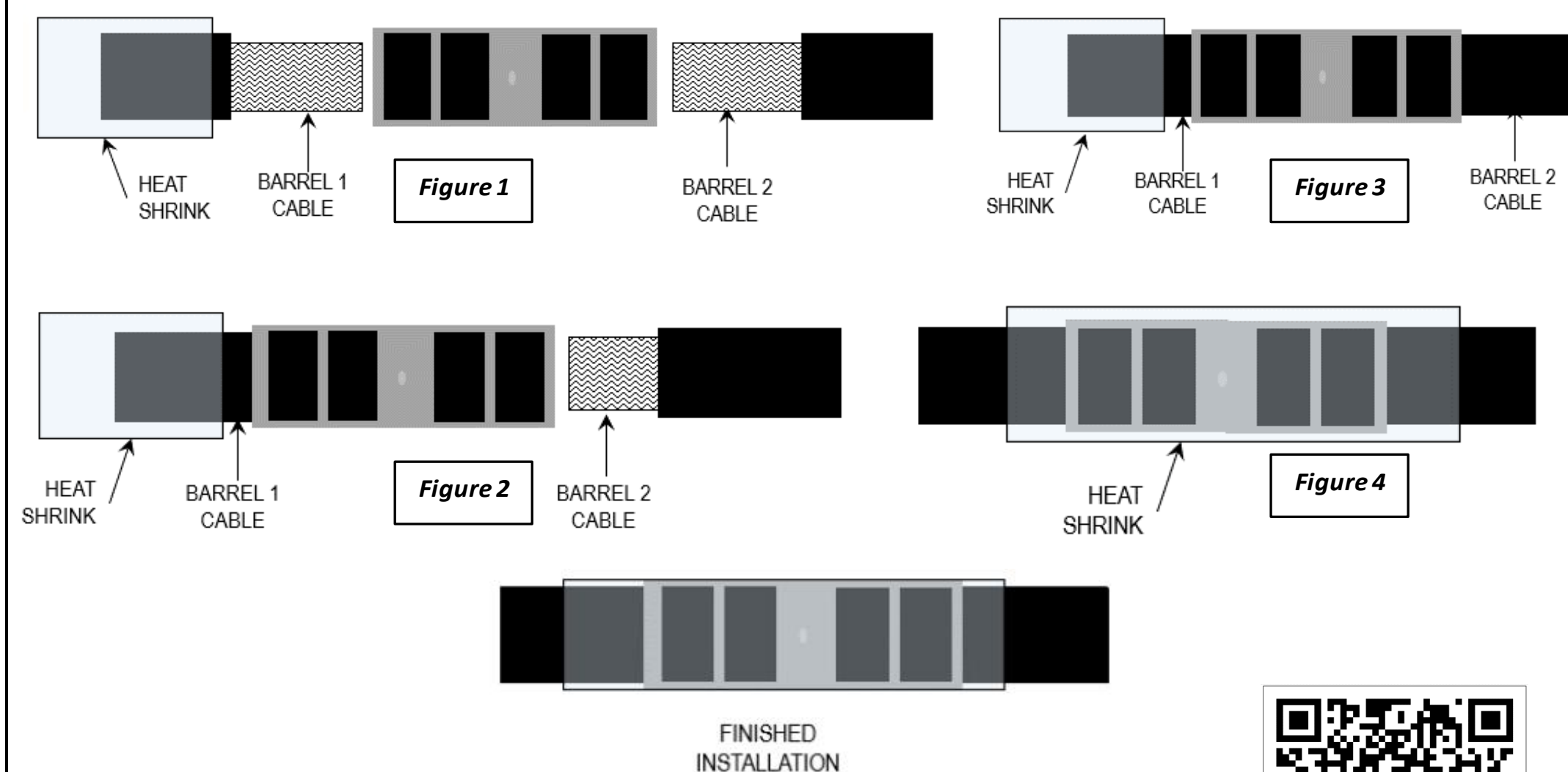

SCAN QR CODE FOR MEDIUM & LARGE HYDENT™ COMPRESSION CONNECTORS INSTALLATION INSTRUCTIONS SUPPORT, INCLUDING SALES DRAWINGS, AND HEAT SHRINK INSTALLATION VIDEOS.



2



Terminal Installation Instructions



ATTENTION


REFERENCE MASTER CATALOG, SALES DRAWING, WEBSITE AND/OR CONNECT APPLICATION FOR TOOL/DIE & ADDITIONAL INSTALLATION INFORMATION.

INSTALLATION

- Strip the insulation to the appropriate length based on the wire strip length recommendations for the selected connector. Strip lengths can be found in the Burndy master catalog, website or sales drawing. Be careful not to nick the cable strands which may result in cut/broken wire.
- Slide heat shrink over cable, (figure 1)
- Fully insert the conductor into the barrel. If the connector has an inspection window, the conductor will be visible in the window, confirming full wire insertion, (figure 2).
- Apply the proper number of crimps specified. Crimp within the crimp zone markings, always crimp starting on pad end going outward, repeat crimping process until all crimps are complete for barrel, (figure 3).
- Once the terminal is fully crimped, slide the heat shrink over the center of the completed assembly and apply heat until full shrinkage is obtained, (figure 3).
- The shrink temperature is 194°F (90°C) min. If using BMSG1100 tool, use low setting (500°F) and place heat gun approximately six inches from the tubing surface. DO NOT USE THE DEFLECTOR.
- Apply heat evenly, radially, starting at the terminal pad and working outwards. When shrink tube has taken contour of the item being covered, installation is complete, (finished installation image).

CAUTION

To prevent damage to the tubing, DO NOT OVERHEAT! Always apply heat uniformly using a back and forth motion. DO NOT FOCUS the heat gun over area. Focusing the heat over one area will cause the tube to melt/split.

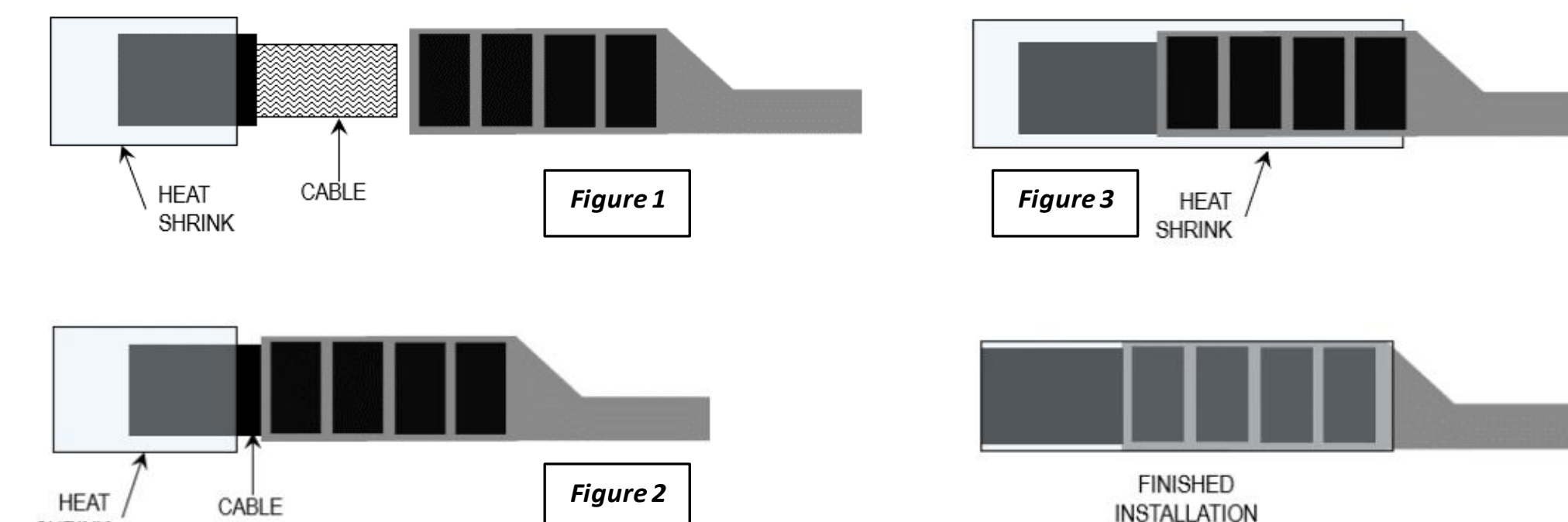

SCAN QR CODE FOR MEDIUM & LARGE HYDENT™ COMPRESSION CONNECTORS INSTALLATION INSTRUCTIONS SUPPORT, INCLUDING SALES DRAWINGS AND HEAT SHRINK INSTALLATION VIDEOS.



2

TO ORDER BURNDY® PRODUCTS CALL

UNITED STATES
1-800-346-4175 (LONDONDERRY, NH)

CANADA:
1-800-387-6487

FOR PRODUCT INFO: <http://www.burndy.com>

THIN WALL HEAT SHRINK

ITEM NO: SEE TABLE		DRAWING NO	
CAT. NO: SEE TABLE		REV	
DRAWN BY: R.VASANTH	3/16/2023		A
CHECKER: B.NADEAU	3/29/2023		
DSN APRVL: B.NADEAU	4/26/2023		
MFG APRVL: L.RUFFIN	5/26/2023		
QA APRVL: J.BRODEUR	5/4/2023		
MKT APRVL: B.MICHAUD	4/26/2023		
PROJECT #: --	SIZE	50139507	
DOCUMENT TYPE: SALES	D	SHEET 17 OF 17	
REL LEVEL: Released			