

ELECTRICAL VALUES

KV CLASS	15 kV	BIL	110 kV	Uy	10 kV
----------	-------	-----	--------	----	-------

CURRENT RATING

2000A BOTTOM CONNECTION IN 55°C RISE OIL

MIN. CREEP	21.00 [533.4]	MIN. STRIKE	10.00 [254.0]
CREEP/uy	2.10 [53.3]	STD.	IEEE C57.19.00



DWG.	CATALOG NUMBER	GLAZE COLOR
SD	B-89122-303	BROWN
SD	B-89122-303-70	LT. GRAY

TITLE IEEE STANDARD BUSHING


PRC BUSHING

2-12 THREAD TOP & BOTTOM
TERMINAL ADAPTORS
1.00 [25.4] LONGER BELOW FLANGE

DATE	08-25-03	REV. DATE	
MAXIMUM ALTITUDE	10000 ft [3000 m]		
NET WEIGHT	54 lb [24 kg]		
ANGLE OF INCLINATION FROM THE VERTICAL	0° TO 70°		
PCB CONTENT OF OIL IS LESS THAN 1 ppm			

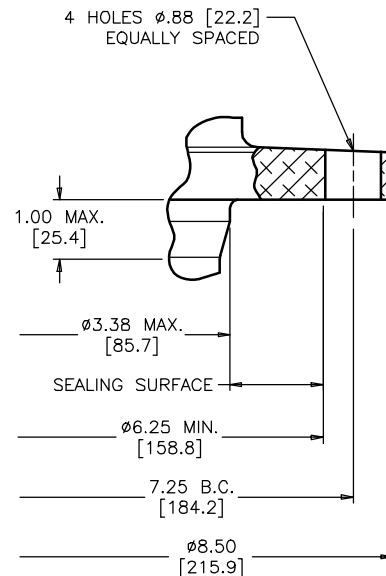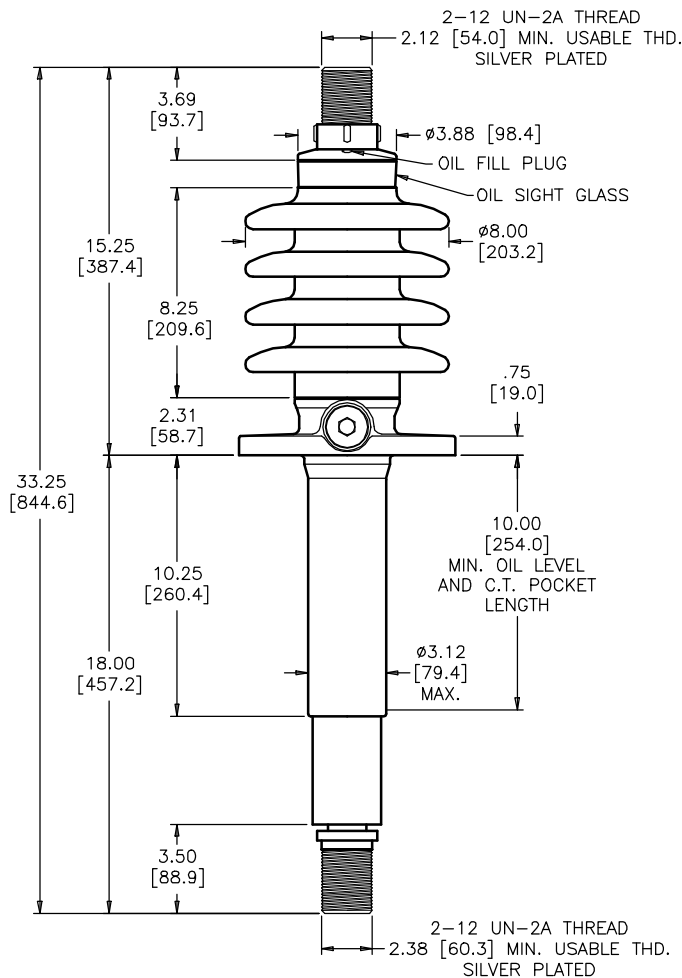

MOUNTING FLANGE DETAIL

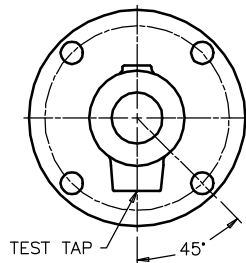

**FLANGE ALIGNMENT DIAGRAM
TOP VIEW**

DIMENSIONS IN INCHES [MILLIMETERS]

REVISION

SCALE 1/5

NOTE TO PURCHASER:
ALL SALES OF LAPP PRODUCTS ARE SUBJECT
TO OUR STANDARD TERMS AND CONDITIONS
AND THE LIMITED WARRANTIES THEREUNDER