



PCORE
ELECTRIC

KV CLASS 25 kV BIL 150 kV U_y 16 kV

CURRENT RATING

2000 AMP BOTTOM CONNECTION

DWG. CATALOG NUMBER GLAZE COLOR

SD B-89223-40 BROWN

SD B-89223-40-70 LT. GRAY

DATE 8-19-05 REV. DATE 1-9-20

MAXIMUM ALTITUDE 10000 ft [3000 m]

NET WEIGHT 105 lb [48 kg]

ANGLE OF INCLINATION FROM THE VERTICAL 0° TO 90°

MIN. CREEP 27.50 [698.5] MIN. STRIKE 12.00 [304.8]


CREEP/L-G 1.91 [48.4] STD. IEEE C57.19.00/01

PCB CONTENT OF OIL IS LESS THAN 1 ppm


TITLE

PRC BUSHING ASSEMBLY


HORIZONTAL/VERTICAL MOUNTING

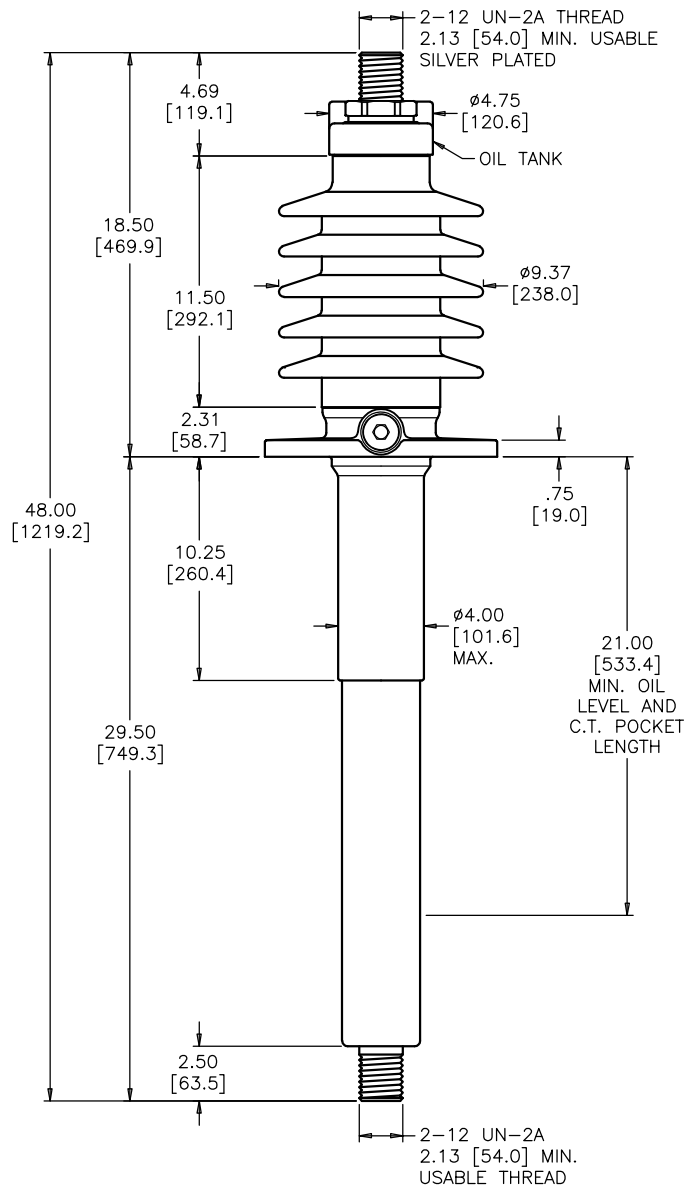


OIL TANK TO BE
INSTALLED UP
FOR NON-VERTICAL
APPLICATIONS

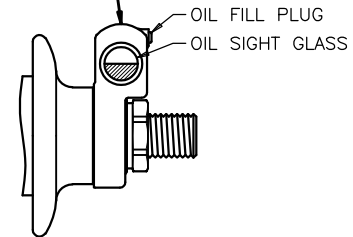

**OIL TANK DETAIL
SHOWN IN HORIZONTAL
MOUNTING POSITION**

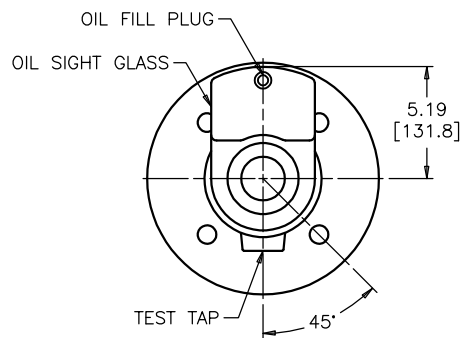

**FLANGE ALIGNMENT DIAGRAM
TOP VIEW**

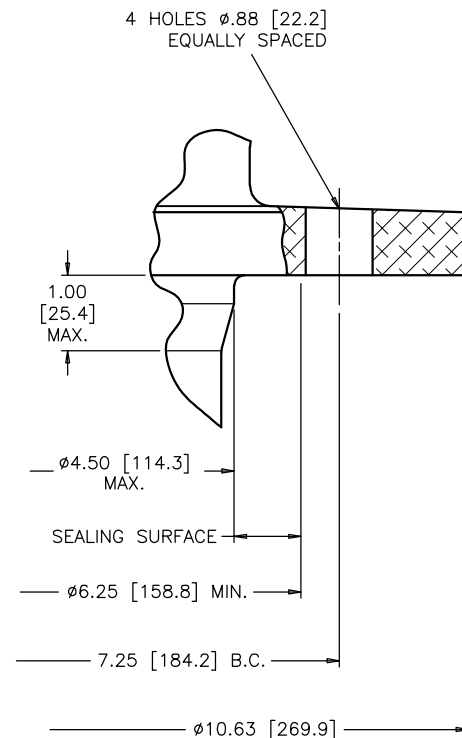

MOUNTING FLANGE

DIMENSIONS IN INCHES [MILLIMETERS]

REVISION NET WEIGHT WAS 102 lb

SCALE 1/6

NOTE TO PURCHASER:
ALL SALES OF PCORE PRODUCTS ARE SUBJECT
TO OUR STANDARD TERMS AND CONDITIONS
AND THE LIMITED WARRANTIES THEREUNDER