
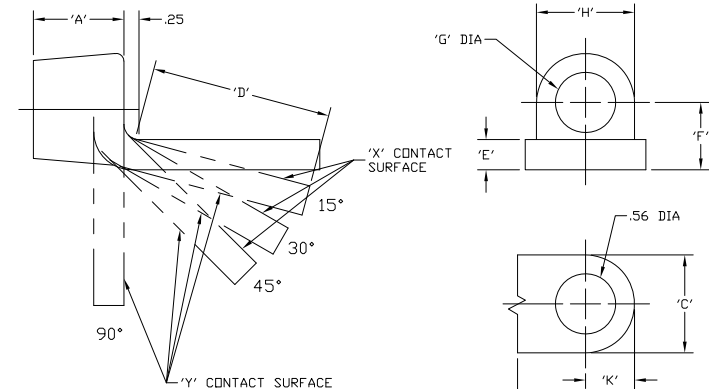


NOTES:

- 1) MATERIAL: 356-F ALUMINUM ALLOY.
- 2) CONNECTIONS CAN BE SUPPLIED WITH BONDED COPPER LINER BY ADDING SUFFIX 'C' TO CATALOG TYPE. EXAMPLE: WCF-39B
- 3) ANGLE CONNECTORS CAN BE SUPPLIED IN MULTIPLES OF 15° AS SHOWN TO OBTAIN CORRECT ANGLE TAKE-OFF, ADD ANGLE DESIRED AND LETTER DESIGNATING SURFACE DESIRED. EXAMPLE: WCF-39B-X45
- 4) HOLE SPACING OTHER THAN SHOWN MUST BE SPECIFIED BY CUSTOMER.
- 5) 'F' TONGUE WILL HAVE (4) .56 DIA HOLES DN 2.50 CENTERS
- 6) CONNECTORS WITH UNDRILLED TONGUES HAVE SAME DIMENSIONS AS CONNECTORS WITH DRILLED TONGUES.

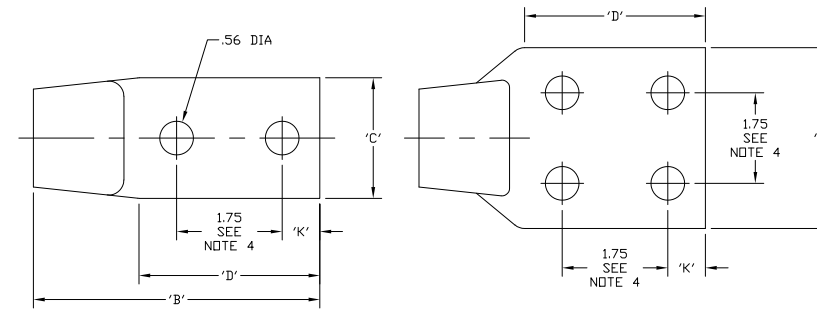

CABLE RANGE		CATALOG No.	FIG No.	DIMENSIONS IN INCHES										
DECIMAL	MCM DR AWG			A	B	C	D	E	F	G	H	K		
.368-.373	1/0	WCF-39B	1	.75	4.25	1.50	3.25	.25	.56	.39	.81	.63		
.398-.418	2/0	WCF-45B	1	.75	4.25	1.50	3.25	.25	.56	.45	.81	.63		
.447-.470	3/0	WCF-50B	1	1.0	4.50	1.50	3.25	.31	.69	.50	1.0	.63		
.502-.528	4/0	WCF-56B	1	1.0	4.50	1.50	3.25	.31	.69	.56	1.0	.63		
.563-.593	250-266.8	WCF-63B	1	1.0	4.50	1.50	3.25	.31	.69	.63	1.0	.63		
.563-.593	250-266.8	WCF-63C	2	1.0	4.50	3.0	3.25	.31	.69	.63	1.0	.63		
.609-.642	300	WCF-67B	1	1.25	4.75	1.50	3.25	.38	.88	.67	1.31	.63		
.625-.670	300-336.4	WCF-67C	2	1.25	4.75	3.0	3.25	.38	.75	.69	1.31	.63		
.666-.684	336.4-350	WCF-72B	1	1.25	4.75	1.50	3.25	.38	.88	.72	1.31	.63		
.666-.684	336.4-350	WCF-72C	2	1.25	4.75	3.0	3.25	.38	.88	.72	1.31	.63		
.721-.728	397.5-400	WCF-78B	1	1.25	4.75	1.50	3.25	.38	.88	.72	1.31	.63		
.721-.728	397.5-400	WCF-78C	2	1.25	4.75	3.0	3.25	.38	.88	.72	1.31	.63		
.772-.795	450-477	WCF-83B	1	1.25	4.75	1.50	3.25	.38	.88	.83	1.31	.63		
.772-.795	450-477	WCF-83C	2	1.25	4.75	3.0	3.25	.38	.88	.83	1.31	.63		
.806-.846	500	WCF-88B	1	1.25	4.75	1.50	3.25	.38	.88	.88	1.31	.63		
.806-.846	500	WCF-88C	2	1.25	4.75	3.0	3.25	.38	.88	.88	1.31	.63		
.855-.883	550-556.5	WCF-92B2	1	1.50	5.0	2.0	3.25	.50	1.12	.92	1.63	.63		
.855-.883	550-556.5	WCF-92C	2	1.50	5.0	3.0	3.25	.50	1.12	.92	1.63	.63		
.891-.930	600-650	WCF-97B2	1	1.50	5.0	2.0	3.25	.50	1.12	.96	1.63	.63		
.891-.930	600-650	WCF-97C	2	1.50	5.0	3.0	3.25	.50	1.12	.96	1.63	.63		
.953-.977	700-715.5	WCF-103B2	1	1.50	5.0	2.0	3.25	.50	1.12	1.03	1.63	.63		
.953-.977	700-715.5	WCF-103C	2	1.50	5.0	3.0	3.25	.50	1.12	1.03	1.63	.63		
.990-1028	750-795	WCF-106B2	1	1.50	5.0	2.0	3.25	.50	1.12	1.06	1.63	.63		
.990-1028	750-795	WCF-106C	2	1.50	5.0	3.0	3.25	.50	1.12	1.06	1.63	.63		
1031-1081	800-874.5	WCF-113B2	1	1.75	5.25	2.0	3.25	.63	1.38	1.12	1.88	.63		
1031-1081	800-874.5	WCF-113C	2	1.75	5.25	3.0	3.25	.63	1.38	1.12	1.88	.63		
1093-1125	900-954	WCF-117B2	1	1.75	5.25	2.0	3.25	.63	1.38	1.17	1.88	.63		
1093-1125	900-954	WCF-117C	2	1.75	5.25	3.0	3.25	.63	1.38	1.17	1.88	.63		
1140-1172	1000-1033.5	WCF-123B2	1	1.75	5.25	2.0	3.25	.63	1.38	1.23	1.88	.63		
1140-1172	1000-1033.5	WCF-123C	2	1.75	5.25	3.0	3.25	.63	1.38	1.23	1.88	.63		
1209-1246	1100-1113	WCF-129B2	1	2.0	5.50	2.0	3.25	.75	1.69	1.30	2.25	.63		
1209-1246	1100-1113	WCF-129C	2	2.0	5.50	3.0	3.25	.75	1.69	1.30	2.25	.63		
.398-418	2/0	WCF-45A	3	.75	2.75	1.50	2.0	.25	.56	.45	.81	.75		
1263-1315	1200-1300	WCF-136B2	1	2.0	5.50	2.0	3.50	.75	1.69	1.36	2.25	.63		
1263-1315	1200-1300	WCF-136C	2	2.0	5.50	3.0	3.50	.75	1.69	1.36	2.25	.63		
1364-1412	1400-1500	WCF-147B2	1	2.0	5.50	2.0	3.50	.75	1.69	1.46	2.25	.63		
1364-1412	1400-1500	WCF-147C	2	2.0	5.50	3.0	3.50	.75	1.69	1.46	2.25	.63		
1454-1504	1590-1700	WCF-155C	2	2.50	6.0	3.0	3.25	.75	1.75	1.55	2.63	.63		
1526-1590	1750-1900	WCF-162C	2	2.50	6.0	3.0	3.25	.75	1.75	1.63	2.63	.63		
1630-1631	2000	WCF-172C	2	2.50	6.0	3.0	3.25	.75	1.75	1.72	2.63	.63		
1.340	1351-5	WCF-143B2	1	2.0	5.50	2.0	3.25	.75	1.69	1.39	2.25	.63		
.741	336.4-307.7	WCF-78C	2	1.25	4.75	3.0	3.50	.38	.88	.78	1.31	.63		
1.340	1351.5	WCF-143C	2	2.0	5.50	3.0	3.25	.75	1.69	1.39	2.25	.63		
2.400		WCF-240-D	2	2.75	7.25	4.0	4.25	1.0	2.50	2.46	3.50	1.12		
.609-.642	300	WCF-67-B2	1	1.25	4.75	2.0	3.50	.38	.88	.67	1.31	.63		
.666-.684	336.4-350	WCF-72-B2	1	1.25	4.75	2.0	3.50	.38	.88	.72	1.31	.63		
.721-.728	397.5-400	WCF-78-B2	1	1.25	4.75	2.0	3.50	.38	.88	.78	1.31	.63		
.772-.795	450-477	WCF-83-B2	1	1.25	4.75	2.0	3.50	.38	.88	.83	1.31	.63		
.806-.846	500	WCF-88-B2	1	1.25	4.75	2.0	3.50	.38	.88	.88	1.31	.63		
.447-470	3/0	WCF-50-C	2	1.0	4.50	3.0	3.50	.56	.69	.50	1.0	.63		
.502-528	4/0	WCF-56-C	2	1.0	4.50	3.0	3.50	.56	.69	.56	1.0	.63		
.363	4/0 ACSR	WCF-59-B2	1	1.0	4.50	2.0	3.50	.38	.75	.59	1.25	.63		
.363	4/0 ACSR	WCF-59-C	2	1.0	4.50	3.0	3.50	.38	.75	.59	1.25	.63		
1.454-1.504	1590-1700	WCF-155-B2	1	2.50	6.0	2.0	3.50	.75	1.75	1.55	2.63	.63		
1.526-1.590	1750-1900	WCF-162-B2	1	2.50	6.0	2.0	3.50	.75	1.75	1.63	2.63	.63		

CABLE RANGE		CATALOG No.	FIG No.	DIMENSIONS IN INCHES										
DECIMAL	MCM DR AWG			A	B	C	D	E	F	G	H	K		
1.630-1.631	2000	WCF-172-B2	1	2.50	6.0	2.0	3.50	.75	1.75	1.72	2.63	.63		
1.454-1.504	1590-1700	WCF-155-D	2	2.50	6.75	4.0	4.12	.63	1.63	1.55	2.63	1.12		
.772-.795	450-477	WCF-83-D	2	1.25	5.75	4.0	4.50	.38	.88	.83	1.31	1.12		
		WCF-240-D	2	2.75	7.25	4.0	4.25	1.0	2.50	2.47	3.50	1.12		
1031-1081	800-874.5	WCF-113-B2-90	1	1.75							1.12	1.88	.63	
1209-1246	1100-1113	WCF-129-D-Y90	2	2.0							1.30	2.25	1.12	
1263-1315	1200-1300	WCF-136-D-Y90	2	2.0							1.36	2.25	1.12	
1364-1412	1400-1500	WCF-147-D-Y90	2	2.0							1.47	2.25	1.12	
1209-1246	1100-1113	WCF-129-D-X/Y-45	2	2.0							1.30	2.25	1.12	
1263-1315	1200-1300	WCF-136-D-X/Y-45	2	2.50							1.55	2.62	1.12	
.447-470	3/0	WCF-50-C-Y-90	2	1.0							.50	1.0	.63	
.502-528	4/0	WCF-56-C-Y-90	2	1.0							.56	1.0	.63	
.363-.593	250-266.8	WCF-63-C-Y-90	2	1.0							.63	1.0	.63	
.772-.795	450-477	WCF-83-C-Y-90	1	1.25							.83	1.31	.63	
1.729-1.762	2250-2335.4	WCF-181-D-X/Y-45	2	2.75							1.81	3.25	1.12	
1.823-1.824	2500-918.27	WCF-188-D-X/Y-45	2	2.75							1.88	3.25	1.12	
		WCF-197-D-X/Y-45	2	2.75							1.97	3.25	1.12	
1.996-2.158	3000-3500	WCF-222-D-X/Y-45	2	2.75							2.22	3.25	1.12	
.953-.977	7000-715.5	WCF-103-F	-	1.50	7.75	6.0	6.0	50	1.12	1.03	1.63	1.75		
.666-.684	336.4-350	WCF-72-B2-Y90	1	1.25							.72	1.31	.63	
.990-1028	750-795	WCF-106-C-Y90	2	1.50							1.06	1.63	.63	
1.209-1.246	1100-1113	WCF-129-B2-Y90	1	2.0							1.30	2.25	.63	
.609-.642	300	WCF-67-B-X/Y-45	1	1.25							.67	1.31	.63	
.666-.684	336.4-350	WCF-72-B-X/Y-45	1	1.25							.72	1.31	.63	
.721-.728	397.5-400	WCF-78-B-X/Y-45	1	1.25							.78	1.31	.63	
.772-.795	450-477	WCF-83-B-X/Y-45	1	1.25							.83	1.31	.63	
.806-.846	500	WCF-88-B-X/Y-45	1	1.25							.88	1.31	.63	
.855-.883	500-556.5	WCF-92-C-X/Y-45	2	1.50							.92	1.63	.63	
.891-.930	600-650	WCF-97-C-X/Y-45	2	1.50							.97	1.63	.63	
.953-.977	700-715.5	WCF-103-C-X/Y-45	2	1.50							1.03	1.63	.63	
.990-1028	750-795	WCF-106-C-X/Y-45	2	1.50							1.06	1.63	.63	
.990-1028	750-795	WCF-106-B2-X/Y-45	1	1.50	4.0	2.0	3.25	.50			1.06	1.63	.63	
1.823-1.824	2500-918.27	WCF-188-C	2	2.75	6.75	3.0	3.25	1.0	2.38		1.88	3.25	.63	
1.454-1.504	1590-1700	WCF-155-D-X/Y-90	2	2.50							1.55	2.63	1.12	
1.729-1.762	2250-2335.4	WCF-181-D-X/Y-90	2	2.75							1.81	3.25	1.12	
1.823-1.824	250-918.27	WCF-188-D-X/Y-90	2	2.75							1.88	3.25	1.12	
.990-1028	750-795	WCF-106-D	2	1.50	6.0	4.0	4.25	.50	1.12	1.06	1.63	1.12		
.990-1028	750-795	WCF-106-D-15	2	1.50							1.06	1.63	1.12	
1.630-1.631	2000	WCF-172-D-15	2	2.50							1.72	2.63	1.12	
.609-.642	300	WCF-67-B-X/Y-90	1	1.25							.67	1.31	.63	
1.093-1.125	900-954	WCF-117-B2-X/Y-90	2	1.75							1.17	1.88	.63	
1.526-1.590	1750-1900	WCF-162-D-Y-90	2	2.50							1.63	2.63	1.12	
.772-.795	450-477	WCF-83-C-Y90	2	1.25										