



PCORE
ELECTRIC

KV CLASS 46 kV **BIL** 250 kV **Uy** 29 kV

CURRENT RATING

1200A BOTTOM CONNECTION

DWG. **CATALOG NUMBER** **GLAZE COLOR**

SD PRC250C1200B BROWN

SD PRC250F1200B LT. GRAY

DATE 9-28-17 **REV. DATE**

MAXIMUM ALTITUDE 10000 ft [3000 m]

NET WEIGHT 106 lb [48 kg]

ANGLE OF INCLINATION FROM THE VERTICAL 0° TO 90°

MIN. CREEP 49.00 [1244.6] **MIN. STRIKE** 20.00 [508.0]


CREEP/L-G 1.85 [46.9] **STD.** IEEE C57.19.00/01

REF B-89411

TITLE

PRC BUSHING

OIL-FREE

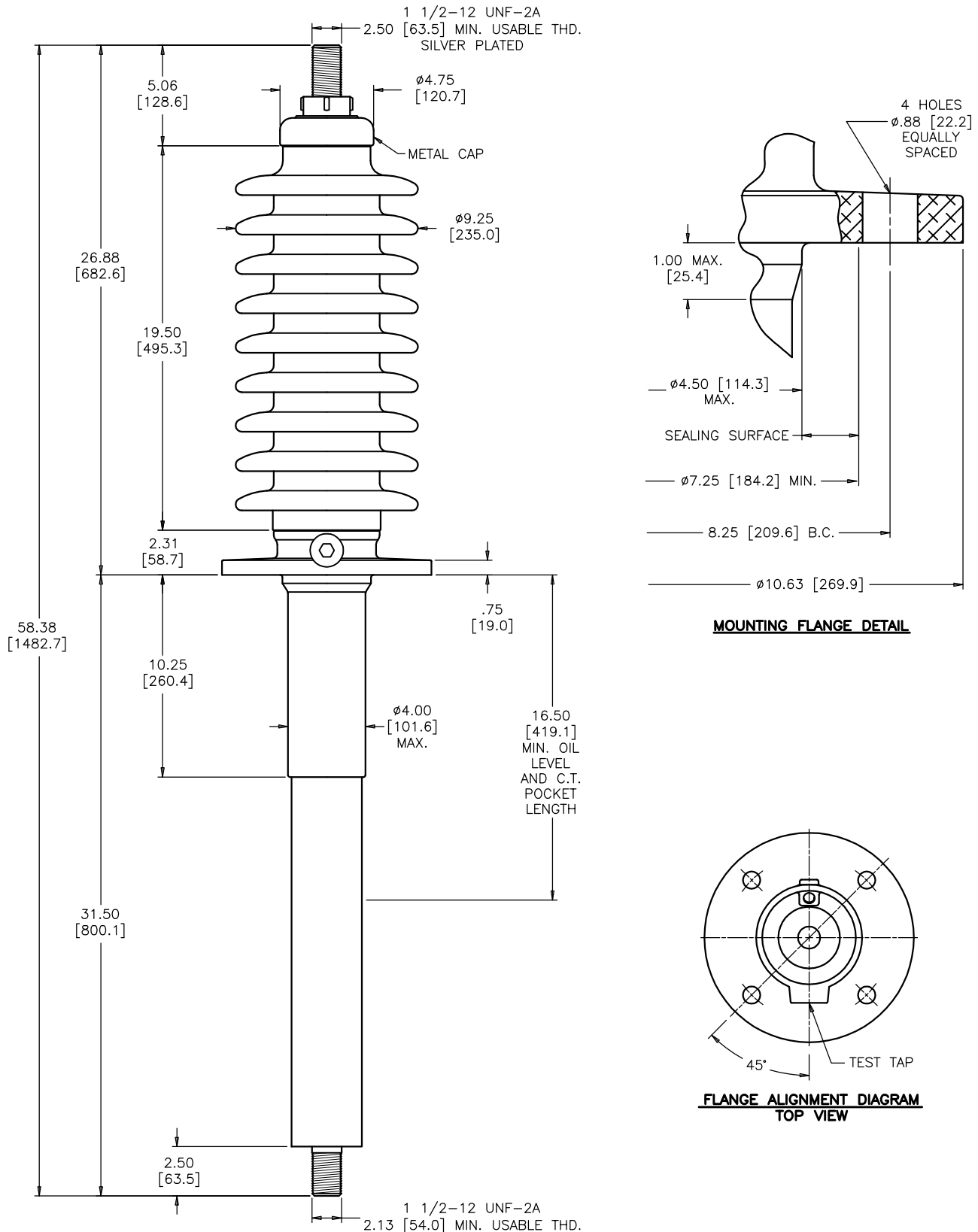

DIMENSIONS IN INCHES [MILLIMETERS]

REVISION

SCALE 1/5

NOTE TO PURCHASER:
ALL SALES OF PCORE PRODUCTS ARE SUBJECT
TO OUR STANDARD TERMS AND CONDITIONS
AND THE LIMITED WARRANTIES THEREUNDER