


CATALOG NUMBERING DESCRIPTION

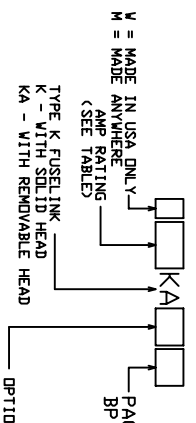

PACKAGING OPTION: BP

OPTIONS:
 FIBR K TYPE FUSELINKS
 W/SUFFIX 25 = 25' LG (OVERALL LENGTH)
 W/SUFFIX 26 = 26' LG (OVERALL LENGTH)
 W/SUFFIX 31 = 31' LG (OVERALL LENGTH)
 FOR K TYPE FUSELINKS (OVERALL LENGTH)
 W/SUFFIX 53 = 23' LG (OVERALL LENGTH)
 W/SUFFIX 56 = 26' LG (OVERALL LENGTH)
 W/SUFFIX 51 = 31' LG (OVERALL LENGTH)

CATALOG NUMBER EXAMPLE



AMP RATING	A' DIA.	B' DIA.	C' DIA.	D' DIA.	L' DIM
1 THRU 20	.50	.75	.311	.090	5-1/2
25 THRU 30	.50	.75	.311	.125	5-1/2
40 THRU 50	.50	.75	.311	.141	5-1/2
65 THRU 100	.75	---	.431	.203	5-1/2
140	1.00	---	.480	.290	6
200	1.00	---	.563	.406	6

CHANCE
 TOLERANCE CHART
 EC 72859 DATED 5/17/18

CONFIDENTIAL: THIS DRAWING AND ITS CONTENTS ARE CONFIDENTIAL AND THE EXCLUSIVE PROPERTY OF HUBBELL POWER SYSTEMS, INC. NO PART OF THIS DRAWING OR DISTRIBUTION OR COPIES MAY BE MADE WITHOUT THE WRITTEN CONSENT OF HUBBELL POWER SYSTEMS. UNPUBLISHED WORKS ARE RESERVED UNDER THE COPYRIGHT LAWS.

HUBBELL POWER SYSTEMS

TITLE: FUSE LINKS, TYPE K
 SOLID & REMOVABLE HD

SIZE: DWG NO. C
 PSSAKFUSELINK SEE CHART

CAT / PART / ASST NO. DATE: 04-02-07

DRN BY: CLARK SHEET 01 OF 01