

NOTE: FOR INSTRUCTION SHEET SCROLL DOWN TO NEXT SHEET

- NOTES:
1. ALL DIMENSIONS ARE IN INCHES AND [MILLIMETERS]
 2. BOX VOLUME: 42 IN³ [688.2 CM³]
 3. ACCEPTS ALL 4-11/16" COVERS, 707RAC & 709 PARTITIONS, ALL SOLD SEPARATELY
 4. UL LISTED
 5. KNOCKOUTS IN LOCATION "A" ARE ACCESSIBLE FOR 5-1/2" [140] & 6" [152.4] STUDS ONLY

KNOCKOUTS		
TRADE SIZE	LOCATION	QTY.
(1/2"-3/4") TKO®	B, C, D, E	3
(1/2"-3/4") TKO®	A (SEE NOTE 5)	3
1/2"	A (SEE NOTE 5)	1

LIST OF PARTS		
DESCRIPTION	MATERIAL	FINISH
SPACER	STEEL	GALVANIZED
SIDE	STEEL	GALVANIZED
FASTENERS	STEEL	GALVANIZED
FAR SIDE SUPPORT	STEEL	GALVANIZED
PIGTAIL	INSULATED STRANDED COPPER	N/A
STUD BRACKET	STEEL	GALVANIZED



INITIAL RELEASE	J.R.	06/22/2015
SYM.	REVISION DESCRIPTION	APP DATE

THE DESIGN AND DIMENSIONS OF THE PRODUCT SHOWN ON THIS DRAWING ARE SUBJECT TO CHANGE WITHOUT NOTICE

TITLE: **4-11/16" SQUARE WELDED BOX 2-1/8" DEEP WITH RAISED GROUND, STRANDED PIGTAIL, STUD BRACKET, AND FAR SIDE SUPPORT**

TOLERANCE UNLESS OTHERWISE SPECIFIED
 .XX DECIMAL ±.015
 .XXX DECIMAL ±.005
 ANGLE ±2°

RACO
 South Bend, Indiana

DRAWN BY: J.R. SCALE: 1:3
 APP. BY: N.S.
 DATE: 06/22/2015


257HS CUS

257HS DIMENSION SHEET FOR CAT. NO.

SIZE: **A**


Instructions for using the RACO® Universal Box Stabilizer

1-1/2" Deep Boxes

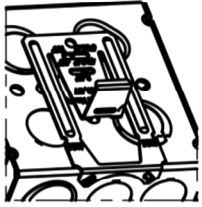


Bend center tab as shown

For 2-1/2" deep studs

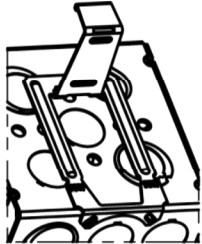


Bend center tab as shown - 2 places

For 3-1/2" deep studs

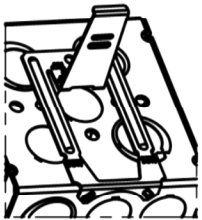


Bend center tab as shown

For 3-5/8" deep studs

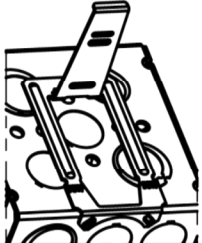


Bend center tab as shown

For 4" deep studs

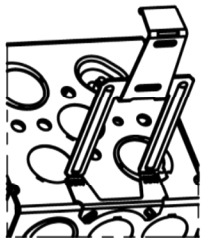

Bend both tabs as shown


For 5-1/2" deep studs

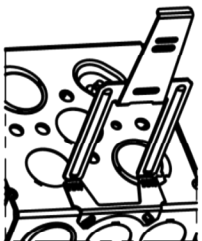


Bend both tabs as shown

For 6" deep studs


2-1/8" Deep Boxes

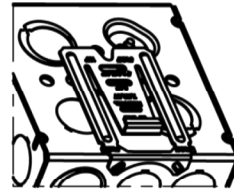

Comes preset

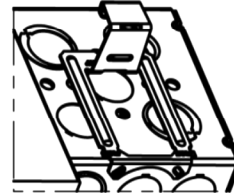


Bend center tab as shown - 2 places

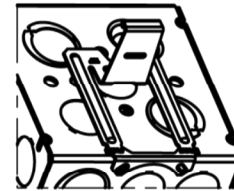


Bend center tab as shown



Bend center tab as shown

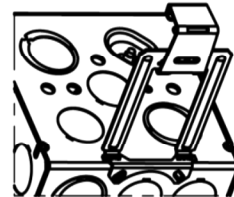

Bend both tabs as shown

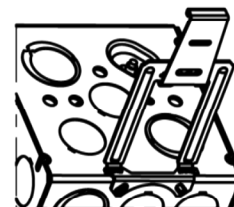

Bend both tabs as shown

NOTICE: Bottom knockouts are NOT usable with the FS support.