
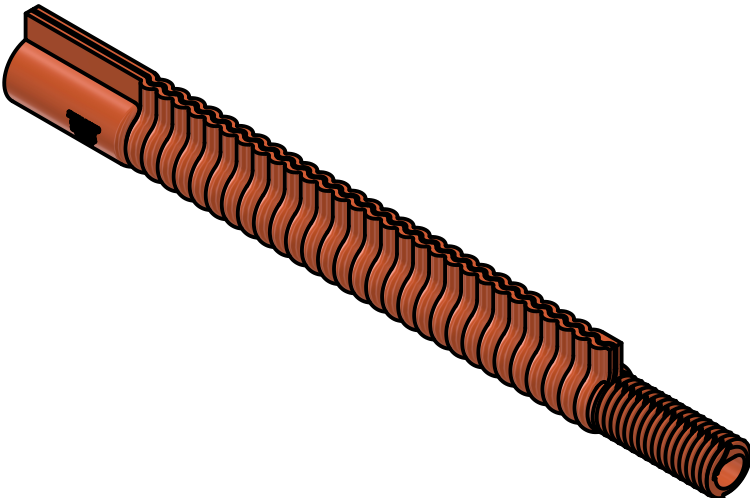



- 1. TESTED TO ASTM D1050 CLASS 3 REQUIREMENTS.
- 2. MAX USE VOLTAGE: 26.5 kV.
- 3. TYPE II (OZONE RESISTANT).
- 4. 100% ELECTRICALLY TESTED AND DATE STAMPED.
- 5. MAT'L: ORANGE EPDM ELASTOMER.
- 6. WEIGHT: 16 LB.

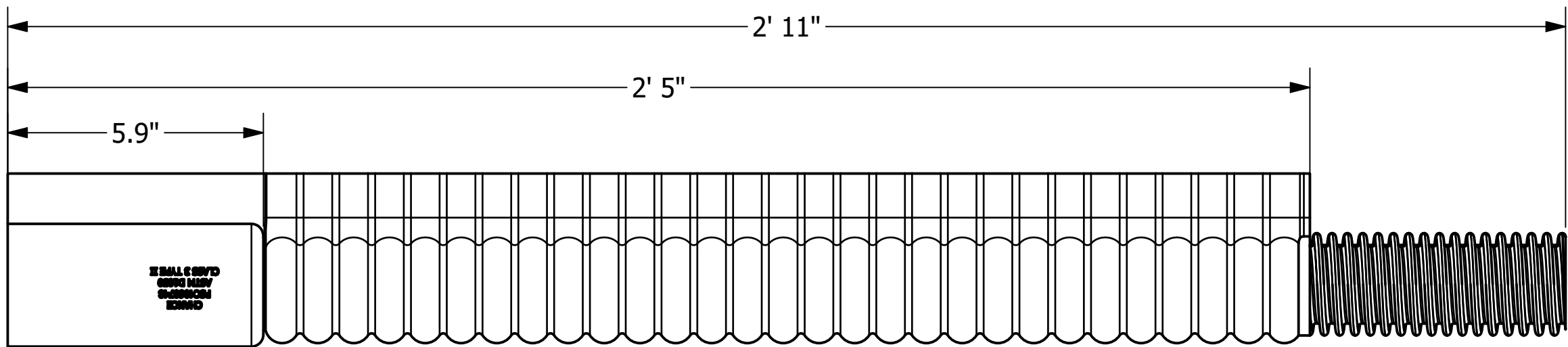

CHANCE [®]		 HUBBELL POWER SYSTEMS, INC.	
CONFIDENTIAL: THIS DRAWING AND ITS CONTENTS ARE CONFIDENTIAL AND THE EXCLUSIVE PROPERTY OF HUBBELL POWER SYSTEMS. NO PUBLICATION, DISTRIBUTION, OR COPIES MAY BE MADE WITHOUT THE WRITTEN CONSENT OF HUBBELL POWER SYSTEMS. HUBBELL POWER SYSTEMS UNPUBLISHED ALL RIGHTS RESERVED UNDER THE COPYRIGHT LAWS.		TITLE JUMPER COVER FLEXIBLE	
SIZE B	CAT / PART / ASSY NO. PSC4060674	DWG NO. SA4060674	REV A
DO NOT SCALE THIS DRAWING	DRN BY IMJ	DATE 10/9/2023	SHEET 1 OF 1