


ACCESSORIES	
CAT. NO	DESCRIPTION
PT208325	AIR BULB CONTROL, 25 FOOT LINE

REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
B	03/03/2016	FOCUS REQUEST FPN1601112	43144	CV	MB

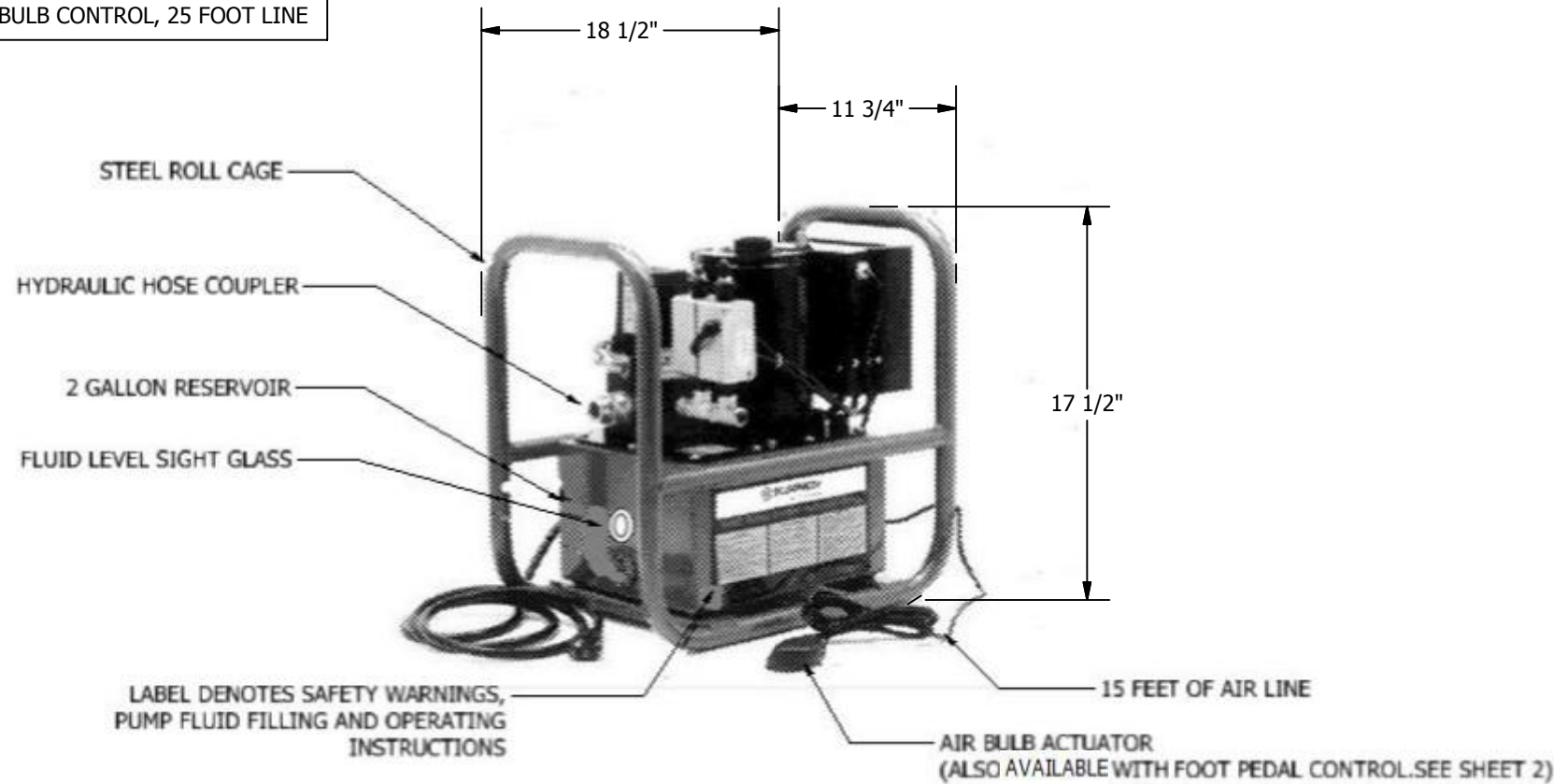

FEATURES:

1. HYDRAULIC FLUID: BURNDY ALFLUID™ (2 GALLONS) SUPPLIED WITH UNIT. SEE RESERVOIR LABEL FOR PUMP FLUID FILLING INSTRUCTIONS.
2. ROLL CAGE: HEAVY DUTY STEEL HELPS PROTECT RESERVOIR AND PUMP FROM DAMAGE. CAGE PROVIDES A STABLE STANCE AND EASES TRANSPORTATION.
3. AIR BULB ACTUATOR: PROVIDES OPERATOR SAFETY FROM ELECTRICAL SHOCK WITH 15 FEET OF AIRLINE STANDARD.
4. BLOWOFF VALVE: FACTORY PRESET FOR PROPER CRIMP PRESSURE.
5. SELECT MANUAL OR AUTOMATIC OPERATING MODE.
6. MANUAL MODE: SQUEEZE BULB AND HOLD TO START CRIMPING CYCLE. RELEASE BULB TO STOP CYCLE AT ANY TIME (CRIMP TOOL WILL HOLD AT PRESENT POSITION). TO FINISH CYCLE SQUEEZE BULB AND HOLD. TO ABORT CYCLE AT ANY TIME AND RETRACT TOOL POSITION PLACE CONTROL SWITCH TO "OFF" PUMP WILL STOP AND RESET.
7. AUTOMATIC MODE : SQUEEZE AND RELEASE BULB ONCE TO ADVANCE CRIMP TOOL TO THE HOLD POSITION. SQUEEZE AND RELEASE BULB AGAIN TO COMPLETE CRIMPING CYCLE. TO ABORT FROM THE HOLD POSITION. SQUEEZE BULB TWICE HOLD FEATURE WILL RELEASE AND TURN OFF PUMP. IF WHILE ADVANCING IN ANY CYCLE, THE BULB IS SQUEEZED AGAIN, THE PUMP WILL SHUT OFF AND RETRACT THE TOOL.

SPECIFICATIONS:


 
 
 
 
 
 



 
 
 
 
 
 
1. RESERVOIR CAPACITY: 2 GALLONS
2. HYDRAULIC FLUID TYPE: BURNDY ALFLUID™
3. LENGTH: 18 1/2"
4. WIDTH: 11 3/4"
5. HEIGHT: 17 1/2"
6. DRY WEIGHT: 68 LBS (INCLUDES ROLL CAGE)
7. WET WEIGHT :82 LBS (INCLUDES ROLL CAGE)
8. OUTPUT PRESSURE: SEE TABLE ON SHEET 2
9. HORSEPOWER: 1/2 HP @ 3450 RPM
10. VOLTAGE: 115 VOLT AC, 60 CYCLE
220/230 VOLT, 50 CYCLE \triangleleft 1
220/230 VOLT, 60 CYCLE \triangleleft 3

NOTES:

 



IF HIGHEST REVISION OF THIS SALES PRINT IS AFFECTED
UPDATE PRINT WSA208758 TO INCLUDE THE NEW REVISION


TO ORDER BURNDY® PRODUCTS CALL		EPAC SERIES ELECTRIC HYDRAULIC PUMP	
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: --	
CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)		CAT. NO: EPAC -- (TABLE)	
FOR PRODUCT INFO: http://www.burndy.com		DRAWN BY: JSG 7/9/92	
		CHECKER: DF 7/22/92	
		DSN APRVL: JL 7/7/92	
		MFG APRVL: --	
		QA APRVL: AL 8/7/92	
		MKT APRVL: MB 7/27/92	
		PROD FAM: --	
		DRAWING NO	
		REV	
		PROJECT #: --	
		SIZE	
		SE207892	
		B	
		SHEET 1 OF 2	
		B	

REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
B	03/03/2016	FOCUS REQUEST FPN1601112	43144	CV	MB

EPAC SERIES ELECTRIC HYDRAULIC PUMP		
CATALOG NUMBER	DESCRIPTION	OPERATING OUTPUT PRESSURE
EPAC10  	ELECTRIC HYDRAULIC PUMP, AIR BULB CONTROL WITH ROLL CAGE, 115 VOLT, 60 CYCLE	10,000 PSI
EPAC8 	ELECTRIC HYDRAULIC PUMP, AIR BULB CONTROL WITH ROLL CAGE, 115 VOLT, 60 CYCLE	8,800 PSI
EPAC6 	ELECTRIC HYDRAULIC PUMP, AIR BULB CONTROL WITH ROLL CAGE, 115 VOLT, 60 CYCLE	6,000 PSI
EPAC10-50HZ2  	ELECTRIC HYDRAULIC PUMP, AIR BULB CONTROL WITH ROLL CAGE, 220/230 VOLT, 50 CYCLE	10,000 PSI
EPAC8-50HZ2  	ELECTRIC HYDRAULIC PUMP, AIR BULB CONTROL WITH ROLL CAGE, 220/230 VOLT, 50 CYCLE	8,800 PSI
EPAC6-50HZ2  	ELECTRIC HYDRAULIC PUMP, AIR BULB CONTROL WITH ROLL CAGE, 220/230 VOLT, 50 CYCLE	6,000 PSI
EPAC10-60HZ2  	ELECTRIC HYDRAULIC PUMP, AIR BULB CONTROL WITH ROLL CAGE, 220/230 VOLT, 60 CYCLE	10,000 PSI
EPAC8-60HZ2  	ELECTRIC HYDRAULIC PUMP, AIR BULB CONTROL WITH ROLL CAGE, 220/230 VOLT, 60 CYCLE	8,800 PSI
EPAC6-60HZ2  	ELECTRIC HYDRAULIC PUMP, AIR BULB CONTROL WITH ROLL CAGE, 220/230 VOLT, 60 CYCLE	6,000 PSI

NOTES:

-  USES 220/230 VOLT, 50 CYCLE.
-  OPTION (NOT SHOWN): MAY ORDER UNIT WITH A FOOT PEDAL CONTROL BY ADDING AN "FC" SUFFIX TO THE ABOVE CAT. NO. FOOT PEDAL CONTROL INCLUDES MOMENTARY ACTION FOOT SWITCH WITH STEEL FOOT GUARD (ORANGE) PREWIRED WITH 10 FEET OF 3 PRONG GROUNDED CORDEST. ACTUATION OF FOOT SWITCH CONTROLS THE PUMP IN AN EQUIVALENT FASHION TO THAT OF SQUEEZING THE AIR BULB. SEE SHEET1 FOR MANUAL OR AUTOMATIC OPERATING MODE.
-  USES 220/230 VOLT, 60 CYCLE.
-  OPTION (NOT SHOWN): MAY ORDER UNIT WITH A FOOT PEDAL AND EMERGENCY CONTROL BY ADDING AN "ECFC" SUFFIX TO ABOVE CAT. NO. FOOT PEDAL CONTROL INCLUDES AN EMERGENCY STOP BUTTON ON TOP OF THE GUARD. WHEN OPERATING IN MANUAL CONTROL, THE PUMP WILL HAVE JOG AND HOLD FEATURES.

TO ORDER BURNDY® PRODUCTS CALL		EPAC SERIES ELECTRIC HYDRAULIC PUMP	
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: --	
CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)		CAT. NO: EPAC -- (TABLE)	
FOR PRODUCT INFO: http://www.burndy.com		DRAWN BY: JSG 7/9/92	
		CHECKER: DF 7/22/92	
		DSN APRVL: JL 7/7/92	
		MFG APRVL: --	
		QA APRVL: AL 8/7/92	
		MKT APRVL: MB 7/27/92	
PROJ #:	SIZE	DRAWING NO	REV
PROJECT #:	B	SE207892	B
DOCUMENT TYPE: SALES			
REL LEVEL: Released		SHEET 2 OF 2	