


M-12017 1

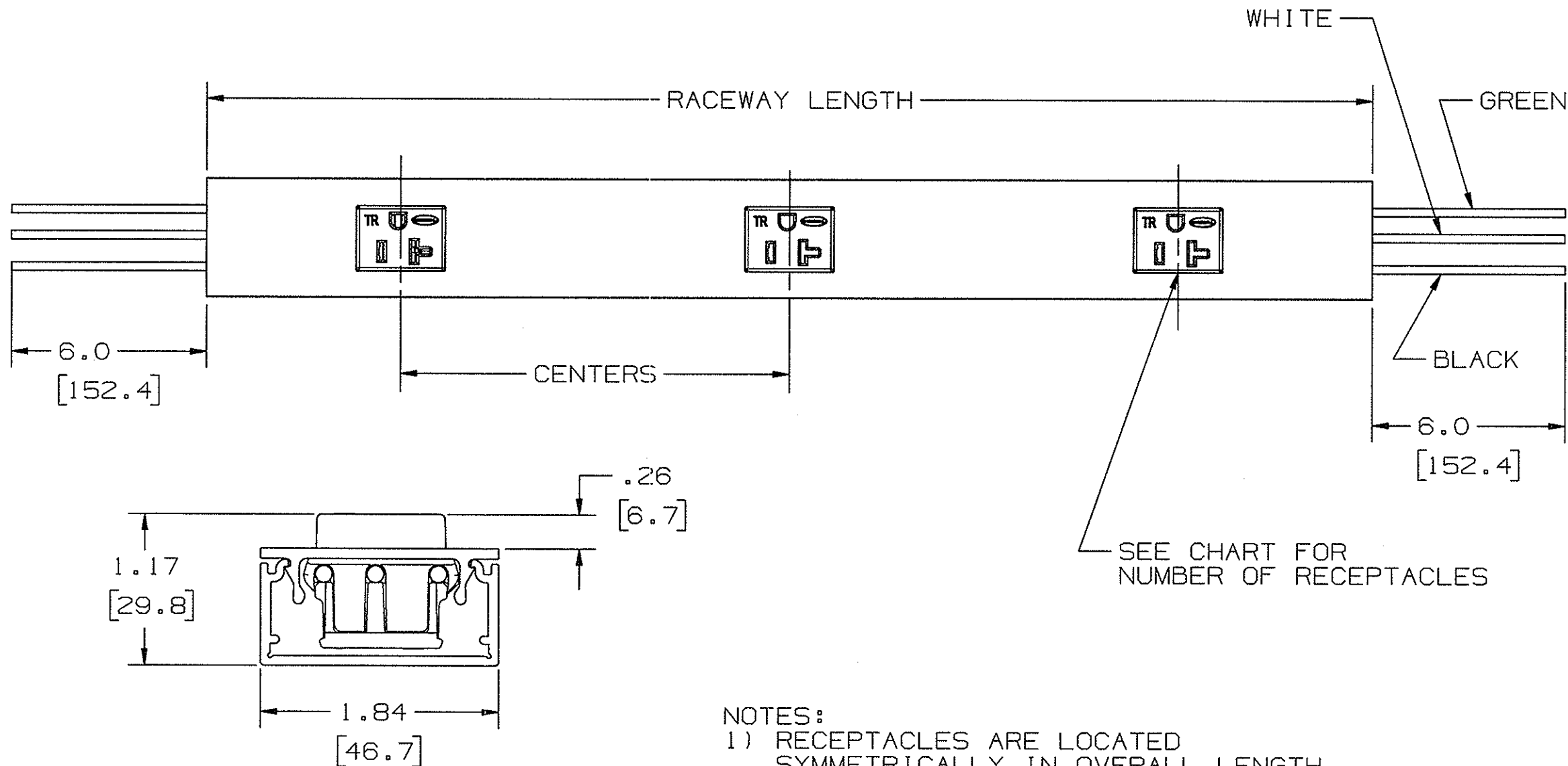

NOTES:

- 1) RECEPTACLES ARE LOCATED SYMMETRICALLY IN OVERALL LENGTH.
- 2) CONDUCTORS - #12 THHN STRANDED WIRE.

END VIEW

CATALOG NUMBER	CONFIGURATION	RACEWAY LENGTH	NO. OF CIRCUITS	CENTERS	NO. OF RECEPTACLES
HBLALU20GB306TR	15AMP PER NEMA 5-15R	3 FT [91 CM]	1	6.0 [152]	6
HBLALU20GB512TR	15AMP PER NEMA 5-15R	5 FT [152 CM]	1	12.0 [305]	5
HBLALU24GB306TR	20AMP PER NEMA 5-20R	3 FT [91 CM]	1	6.0 [152]	6
HBLALU24GB512TR	20AMP PER NEMA 5-20R	5 FT [152 CM]	1	12.0 [305]	5

ALL DIMENSIONS ARE IN INCHES AND [MILLIMETERS]

CODE 74545

LIST OF PARTS

DESCRIPTION	MATERIAL	FINISH
RACEWAY	ALUMINUM	CLEAR SATIN
RECEPTACLE	PVC	GRAY
CONTACTS	COPPER ALLOY	NONE

DIMENSION SHEET FOR CAT. NO. M-12017  
 REPAIRABLE  NON-REPAIRABLE   
 SEE TABLE  
 B  
 M-12017  
 1

1	RELEASED PER DCN18223	8/2/11
SYM	REVISIONS	APP DATE
THE DESIGN AND DIMENSIONS OF THE PRODUCT SHOWN ON THIS DRAWING ARE SUBJECT TO CHANGE WITHOUT NOTICE		
TITLE PLUGTRAK - TAMPER RESISTANT ALUMINUM RACEWAY, MULTI-OUTLET ASSEMBLIES		
TOLERANCES UNLESS OTHERWISE SPECIFIED		WIRING DEVICE-KELLEMS HUBBELL INCORPORATED BRIDGEPORT, CT
FRACTIONS ± 1/64	DR. BY SRE	APP. BY [Signature]
DECIMALS ± .005	TR. BY [Signature]	SCALE NONE
ANGLES ± 2°	CHK'D BY [Signature]	DATE 8/2/11