 



M-10103

1

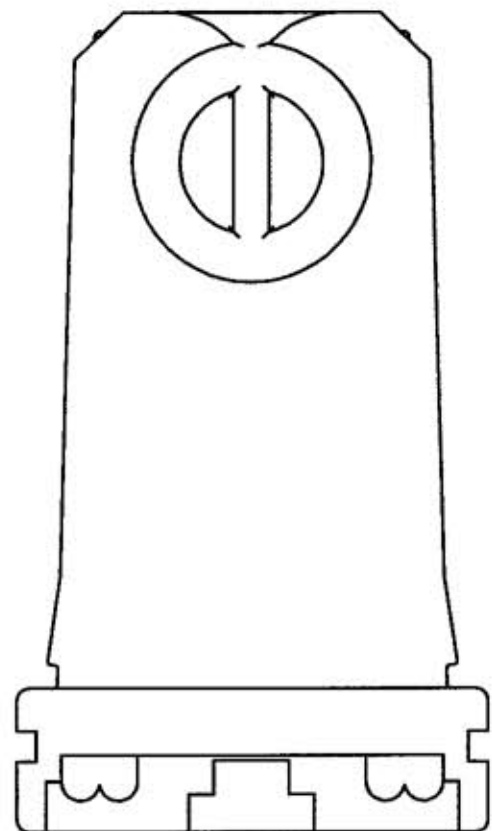

NOTES:

PRODUCT SPECIFICATIONS
 QUICK WIRE TERMINALS
 FOR T-8 & T-12 LAMPS
 660W-600V

CODE 74545

LIST OF PARTS

DESCRIPTION	MATERIAL	FINISH
CONTACTS	BRASS	
HOUSING	PLASTIC	

DIMENSION SHEET FOR CAT. NO. RL320

REPAIRABLE NON-REPAIRABLE

1	RELEASED TO PRODUCTION PER DCN #13353 AMZ	<i>RDK</i>	08/18/06
SYM	REVISIONS	APP	DATE

THE DESIGN AND DIMENSIONS OF THE PRODUCT SHOWN ON THIS DRAWING ARE SUBJECT TO CHANGE WITHOUT NOTICE

TITLE MEDIUM BI-PIN TURN-TYPE LAMPHOLDER (TALL PROFILE)

TOLERANCES UNLESS OTHERWISE SPECIFIED	HUBBELL WIRING SYSTEMS BRIDGEPORT, CT	
FRACTIONS ± 1/64	DR. BY AMZ	APP. BY <i>RDK</i>
DECIMALS ± .005	TR. BY	SCALE NONE
ANGLES ± 2°	CHK'D BY <i>RDK</i>	DATE 11/20/00

B M-10103 1