

M-11678 1

LIST OF PARTS

DESCRIPTION	MATERIAL	FINISH
HOUSING	STEEL	BLACK
MOUNTING BRACKET	STEEL	BLACK
STRAIN RELIEF	NYLON	BLACK
POWER CORD	TYPE SJT	BLACK
FLAG LABEL	MYLAR	WHITE
RECEPTACLE	THERMOPLASTIC	BLACK
FASTENERS	STEEL	BLACK OXIDE

QUESTION SHEET FOR C.A.T. NO. WSB021UEK

REPAIRABLE NON-REPAIRABLE

B

M-11678

1

108" (2.7 M) LONG
POWER CORD,
NEMA 5-15 PLUG

MOUNTING BRACKET

2X ϕ .19 [4.8]
MOUNTING HOLES

ID/WARNING LABEL

.85
[21.6]

1.88
[47.6]


2.75
[69.8]

6.50 [165.1]

2.26
[57.4]

(2) NEMA 5-15 RECEPTACLES

LOW VOLTAGE PLATE
SUPPLIED WITH 1-UNIT
HUBBELL "iSTATION" OPENING

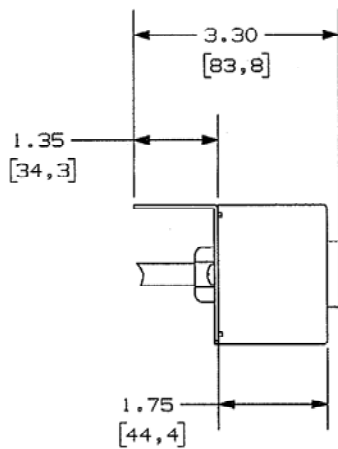

NOTES:
1) ALL DIMENSIONS ARE IN INCHES AND [MILLIMETERS]
2) LOW VOLTAGE PLATE ACCEPTS HUBBELL "iSTATION" MODULES, 1-UNIT.

1	RELEASED PER DCN16890	8/19/10
SYM	REVISIONS	APP DATE

THE DESIGN AND DIMENSIONS OF THE PRODUCT SHOWN ON THIS DRAWING ARE SUBJECT TO CHANGE WITHOUT NOTICE

TITLE
UNDERTABLE MOUNTED UNIT

TOLERANCES UNLESS OTHERWISE SPECIFIED FRACTIONS $\pm 1/64$ DECIMALS $\pm .005$ ANGLES $\pm 2'$	WIRING DEVICE-KELLEMS HUBBELL INCORPORATED BRIDGEPORT, CT	
	DR. BY SRE	APP. BY <i>fm</i>
	TR. BY	SCALE 1:2
	CHK'D BY <i>fm</i>	DATE 3/9/10