


M-12026 4

NOTES:

- 1) ALL DIMENSIONS ARE IN INCHES AND [MILLIMETERS]
- 2) PARTS ARE AVAILABLE WITH CHOICE OF FINISHES;
OFFICE WHITE, BLACK & WHITE.

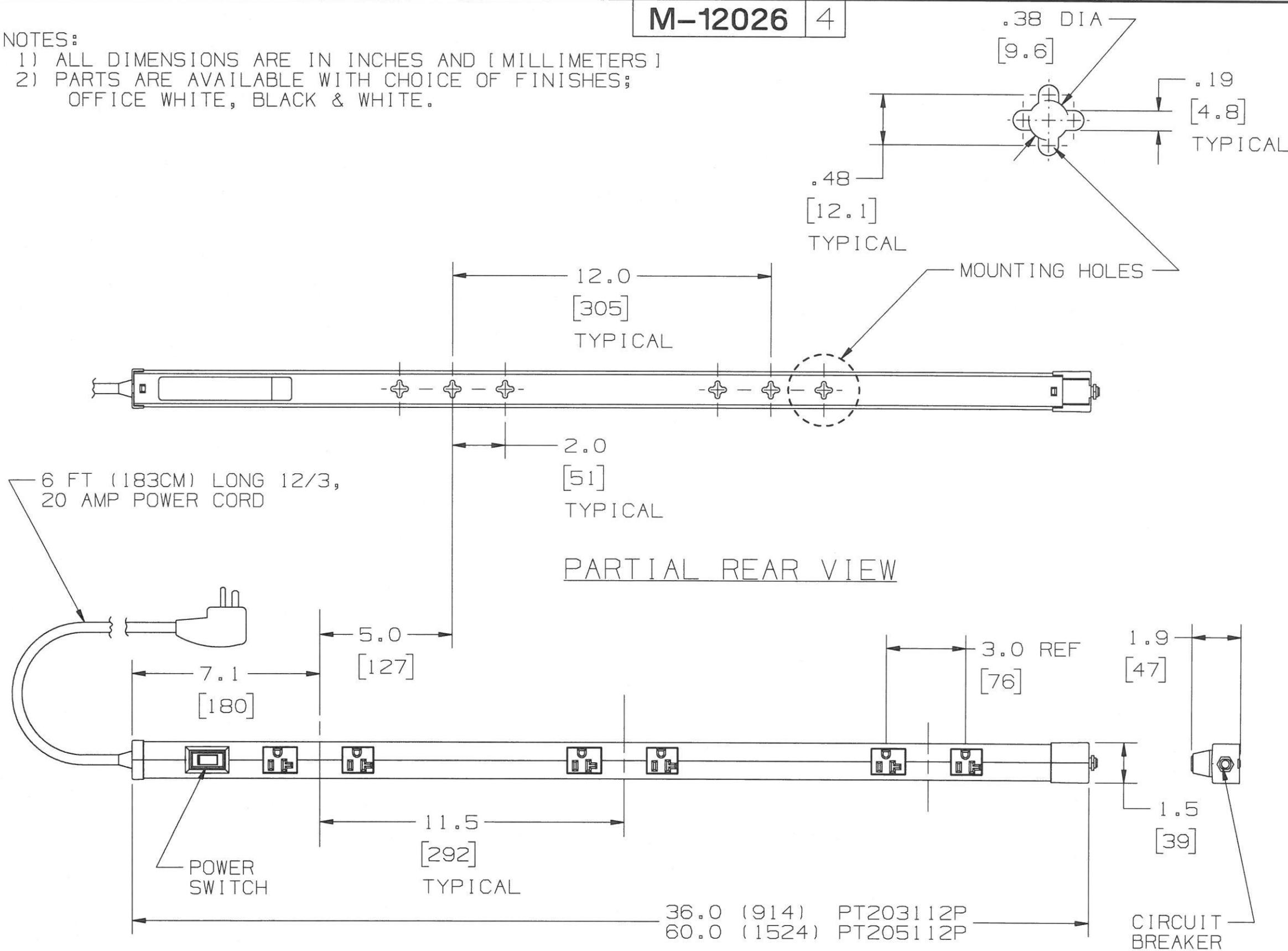

CATALOG NUMBER PT203112P SHOWN;
 CATALOG NUMBER PT205112P SAME EXCEPT
 OVERALL LENGTH AND ADDITIONAL OUTLETS
 AND MOUNTING KEY HOLES;
 CATALOG NUMBER PT205112N SAME AS
 PT205112P EXCEPT NO SWITCH.

CODE 74545

LIST OF PARTS

DESCRIPTION	MATERIAL	FINISH
HOUSING	PVC	SEE NOTE 2
RECEPTACLES	PVC	SEE NOTE 2
END CAPS	PVC	SEE NOTE 2
SWITCH HOUSING	PVC	SEE NOTE 2

4	IN LIST OF PARTS: ALL PARTS SEE NOTE 2 WAS OFFICE WHITE; ADDED NOTES 1 & 2 PER DCN 22918 RM	EN	3/20/17
3	UPDATED PER DCN21869	AD	1/12/16
2	UPDATED PER DCN20888	AD	11/6/14
1	RELEASED PER DCN19765	SRE	5/23/13
SYM	REVISIONS	APP	DATE

THE DESIGN AND DIMENSIONS OF THE
 PRODUCT SHOWN ON THIS DRAWING ARE
 SUBJECT TO CHANGE WITHOUT NOTICE

TITLE
 PORTABLE PLUGTRAK -
 NON-METALLIC
 RELOCATABLE POWER TAP, 20A

TOLERANCES UNLESS OTHERWISE SPECIFIED	WIRING DEVICE-KELLEMS HUBBELL INCORPORATED SHELTON, CT	
.XX = ±.01	DR. BY SRE	APP. BY
.XXX = ±.005	TR. BY	SCALE NONE
ANGLES = ±2°	CHK. BY	DATE 5/23/13

DIMENSION SHEET FOR CAT. NO. REPAIRABLE NON-REPAIRABLE M-12026 4