



M-13125


2

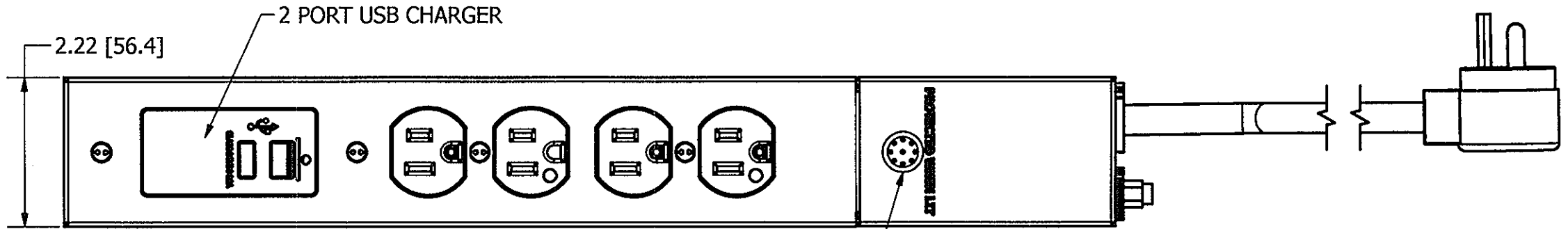

INDICATOR LED - PROTECTED WHEN LIT

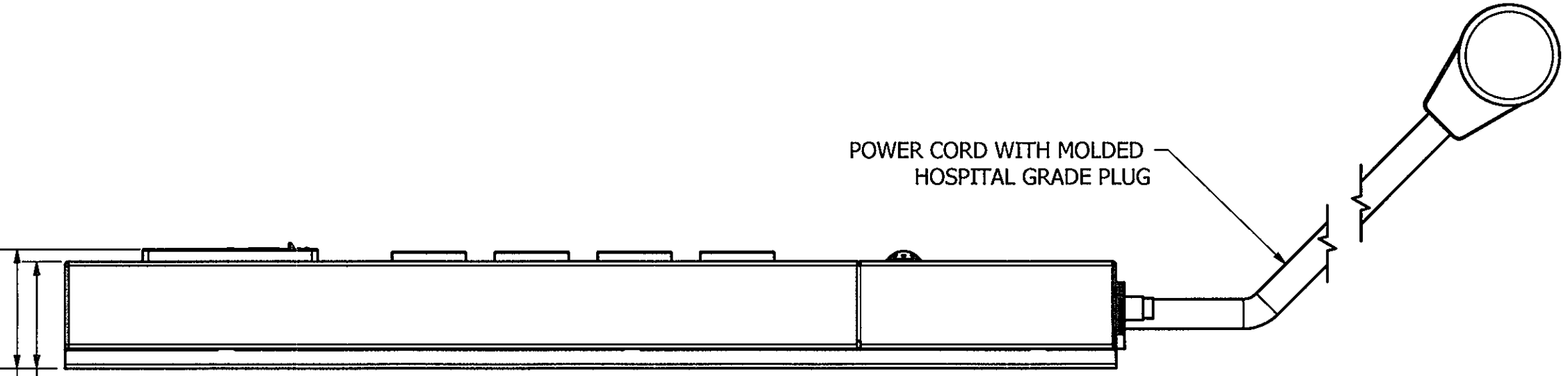

1.60 [40.5]
1.78 [45.2]

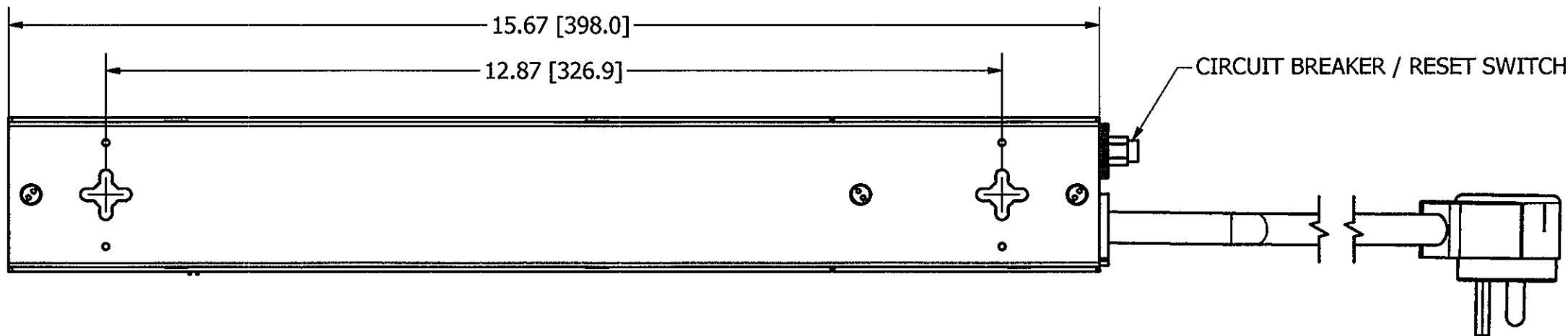

CODE 74545

CATALOG#	DESCRIPTION	CORD LENGTH	RATING
HBL6HG6USB	SURGE STRIP WITH 15A HOSPITAL GRADE RECEPTACLES AND USB 2- PORT CHARGER	6 FT	15A 125V

LIST OF PARTS

DESCRIPTION	MATERIAL	FINISH
BASE	GALV. STEEL	WHITE POWDERCOAT
MAIN ENCLOSURE	GALV. STEEL	WHITE POWDERCOAT
CIRCUIT HOUSING	GALV. STEEL	WHITE POWDERCOAT
POWER CORD	THERMOPLASTIC	WHITE
SCREWS	STEEL	ZINC
DUPLEX RECEPTACLES	THERMOPLASTIC	WHITE
USB 2-PORT CHARGER	THERMOPLASTIC	WHITE
CIRCUIT BREAKER	THERMOPLASTIC	BLACK

SYM	DESCRIPTION	APPRO	DATE
2	POWER CORD DESCRIPTION UPDATED PER DCN# 22263. <i>EMD</i>	EMD	7/7/2016
1	RELEASED PER DCN# 21618	EMD	10/2/15

THE DESIGN AND DIMENSIONS OF THE PRODUCT SHOWN ON THIS DRAWING ARE SUBJECT TO CHANGE WITHOUT NOTICE

TITLE
SURGE STRIP WITH USB CHARGER

TOLERANCES UNLESS OTHERWISE SPECIFIED	WIRING DEVICE-KELLEMS HUBBELL INCORPORATED SHELTON, CT	
FRACTIONS ±1/64	DR. BY EMD	APP. BY
DECIMALS ±.005	TR. BY	SCALE 1/2
ANGLES ±2°	CHK'D BY	DATE 10/2/2015

DIMENSION SHEET FOR CAT. NO.

 REPAIRABLE NON-REPAIRABLE

B **M-13125**

2