


M-13425

1

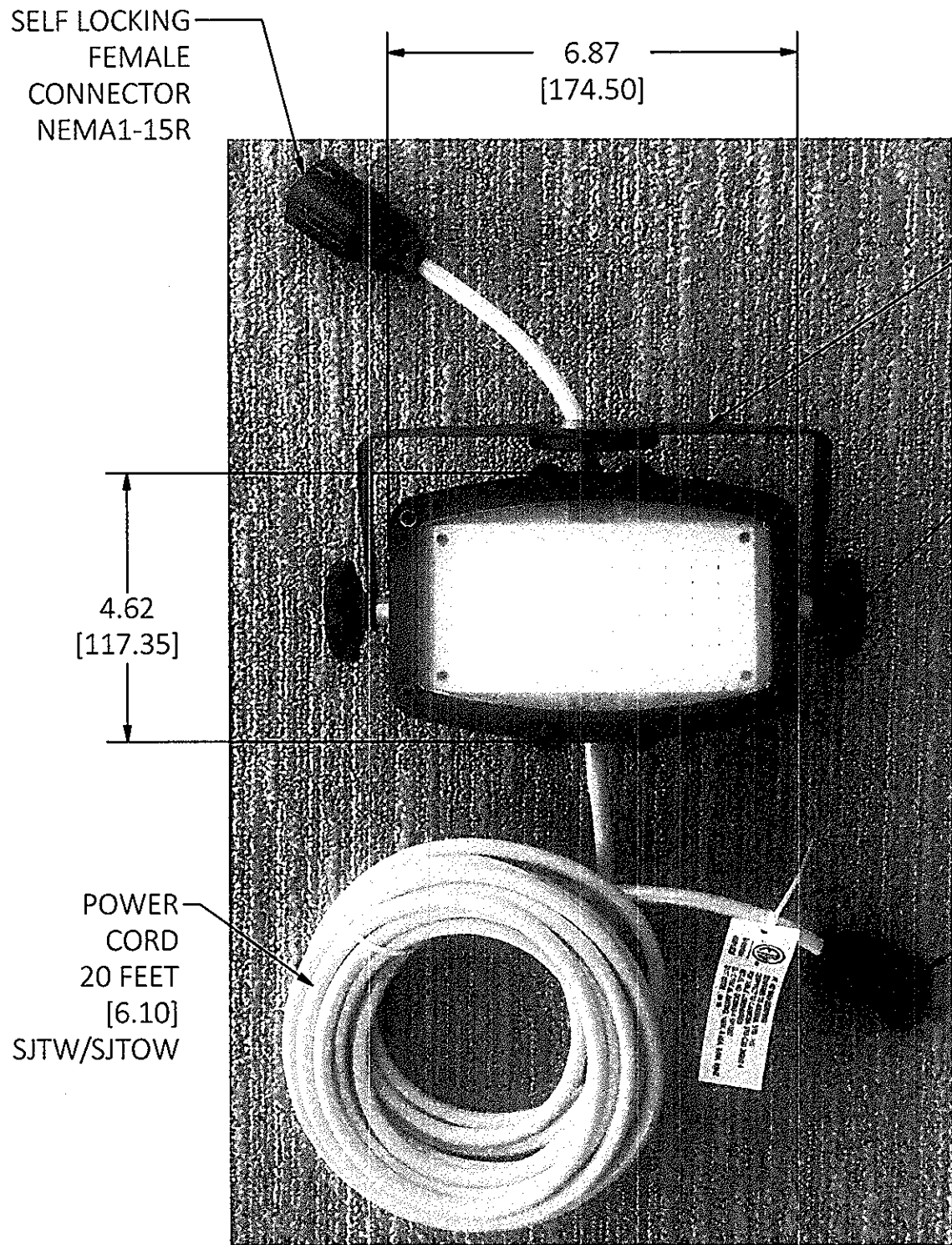



NOT DRAWN TO SCALE

FEATURES:

1. 1,100 LUMEN LED LIGHT.
2. 20 FEET [6.01] METER POWER CORD.
3. SELF LOCKING CONNECTOR.
4. MAGNETIC MOUNTING BRACKET.
5. HANGING HOOK.
6. BRACKET ADJUSTMENT KNOBS.
7. FOR WET LOCATIONS.

LAMP TYPE	LUMEN OUTPUT	INPUT VOLTAGE
LED	1,100	120VAC 60Hz 0.08A 9.6 WATTS

NOTES: UNLESS OTHERWISE SPECIFIED  
1-DIMENSIONS IN INCHES AND [MILLIMETERS].

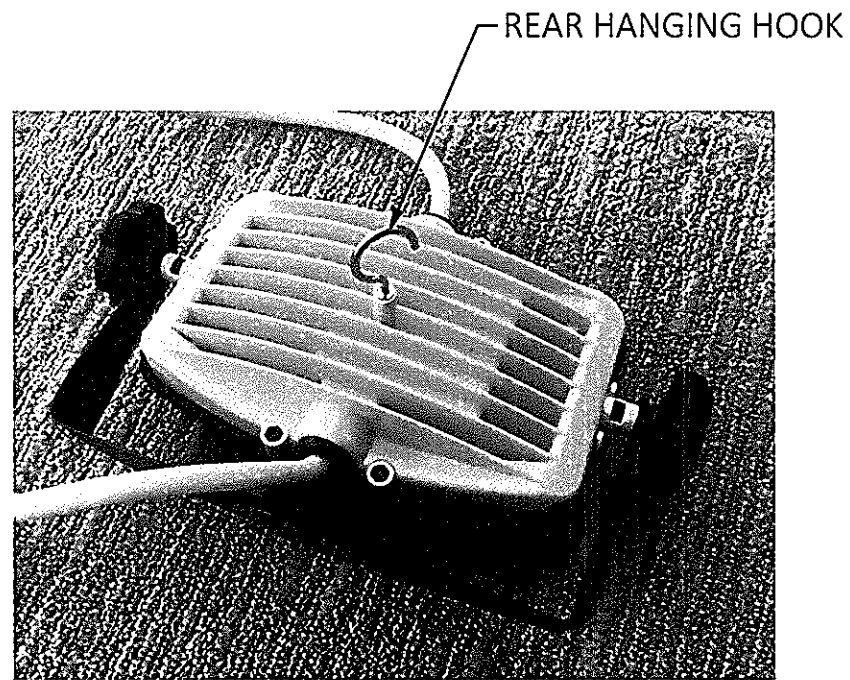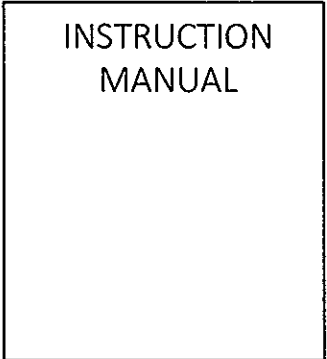

REAR HANGING HOOK

LIST OF PARTS

DESCRIPTION	MATERIAL	FINISH
ENCLOSURE	POLY CARBONATE	POLISHED
LENS	POLY CARBONATE	POLISHED
LENS GASKET	SILICONE	FLAT
MTG. BRACKET	STEEL	PAINTED, FLAT
HANGING HOOK	STEEL	PLATED
CORD	18/2 18AWG	YELLOW

REV	DESCRIPTION	APP	DATE
1	7/22/16 RELEASE PER DCN 22271. MJZ, EM	EM	7/22/16

THE DESIGN AND DIMENSIONS OF THE PRODUCT SHOWN ON THIS DRAWING ARE SUBJECT TO CHANGE WITHOUT NOTICE. DIMENSIONS ARE IN INCHES [mm].

TITLE LED STRING LIGHT, 20 FOOT, 1,100 LUMEN LIGHT

**HUBBELL** WIRING DEVICE-KELLEMS HUBBELL INCORPORATED SHELTON, CT

TOLERANCES UNLESS OTHERWISE SPECIFIED  
XX = ±.01  
XXX = ±.005  
ANGLE TOL. ±2

DR. BY MZ  
CHK. BY EM

SCALE NONE  
DATE 7/22/16

DIMENSION SHEET FOR CAT. NO. HBL182S20LEDH

B

M-13425

1