



SCP

SENSOR CONTROL PROGRAMMABLE



HUBBELL
Lighting



More than 60 million street and area lights are in operation in the U.S.. Many of them remain on for hours in vacant spaces wasting valuable energy resources. This waste represents a savings opportunity worth millions. New energy codes are recognizing this potential and beginning to mandate control in specific outdoor areas.

The **Sensor Control Programmable** accessory, or **SCP**, offers the simple solution to intelligently control outdoor lighting to maximize energy savings with the added benefit of extending luminaire lifetime. The **SCP** mounts to the side of any new or existing 3"-5" round straight pole or square straight pole and is field adjustable via a handheld wireless remote.

With state-of-the-art technology, the SCP is the only control system on the market specifically designed to meet the most demanding requirements of outdoor lighting. For example, the SCP enables any pole mounted luminaire in excess of 75 watts, to meet California Title 24 requirements. In addition, there is integral 20KV/10KA surge protection for added reliability and serviceability.



ORDERING INFORMATION

MODEL
SCP



Model	Pole	Color	Remote
1. MODEL Standard daylight photo-control with motion sensing coverage up to 40' sensor height. SCP 120-277 VAC SCP-HV3 347 VAC SCP-HV4 480 VAC	2. POLE The SCP may be ordered as an accessory to a configured pole or in the case of a stand alone unit, the pole contour must be communicated to the factory. R3 fits a 3" / 76.2 mm round pole R4 fits a 4" / 101.6 mm round pole R5 fits a 5" / 127 mm round pole S fits a square pole	3. COLOR ¹ AWT Arctic White ² BLK Black MTB Matte Black DGN Dark Green DBZ Dark Bronze WRZ Weathered Bronze BRM Bronze Metallic VBL Verde Blue ² CRT Corten MAL Matte Aluminum ³ MDG Medium Grey ATG Antique Green ² LGY Light Grey RAL Premium Color CUSTOM * * Contact Factory	REMOTE Handheld commissioning tool is required to separately configure or adjust any number of sensors. SCPREMOTE Commission Tool

NOTES:
¹ Bezel color shall be in black unless otherwise indicated
² Bezel color shall be in white
³ Bezel color shall be in grey

DIMENSIONS

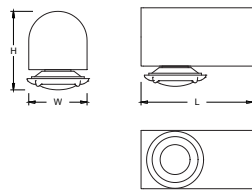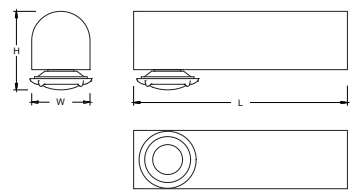SCP <ul style="list-style-type: none">Length: 5 3/4" / 136 mmWidth: 3" / 76 mmHeight: 4" / 102 mmWeight 1.5 lbs. / 0.7 kgEPA: 0.1IP Rating: 66 	SCP-HV3/SCP-HV4 <ul style="list-style-type: none">Length: 11" / 279 mmWidth: 3" / 76 mmHeight: 4" / 102 mmWeight 4 lbs. / 0.9 kgEPA: 0.2IP Rating: 66 
--	---

SENSOR PLACEMENT

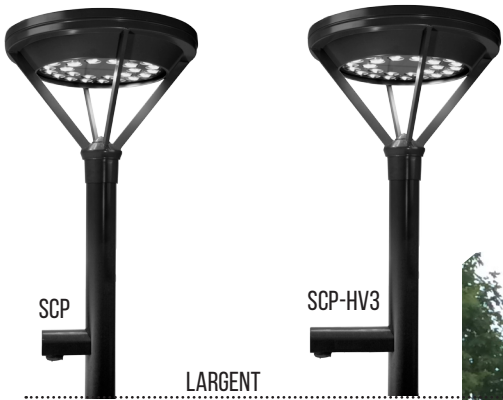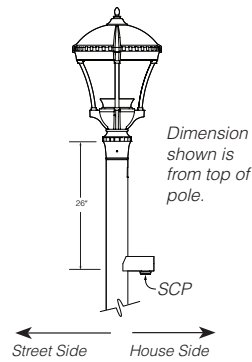

- CA Title 24 Solution
- Motion Sensing up to 40' mounting height
- Daylight Photo Control
- 0-10V Control Signal
- 20KV/10KA Surge Protection
- Hand Held Remote Adjustment
- For Round or Square Straight Poles
- AAL Poles include wire and mounting holes

The SCP delivers a comprehensive solution for challenging outdoor control applications as well as meeting the reliability and flexibility demanded today.

YouTube <https://youtu.be/-9-QNGNgsQ>
Or Search for "AAL SCP"





Architectural Area Lighting
16555 East Gale Ave. | City of Industry | CA 91745
T 626.968.5666 | F 626.369.2695 | www.aal.net



HUBBELL
Lighting