


3-Door Rear Access Industrial RE-BOX®

Effortless, All-Access Install

Hubbell's innovative 3-Door Industrial RE-BOX® cabinets offer unprecedented rear access to network equipment. The patented 3-door design allows the cabinet to be opened on three sides. Inside, equipment is mounted on 18-inch deep rails that are supported by high industrial strength slides. Open the side doors and slide the mounted equipment out of the cabinet for access from any angle. Plus, a perforated rear panel allows for convenient mounting of equipment and cable management accessories.

Industry first mounting bracket is included with all 3-door cabinets, simplifying wall mount installation. The sturdy mounting bracket supports the weight of the cabinet to ease installation mounting.

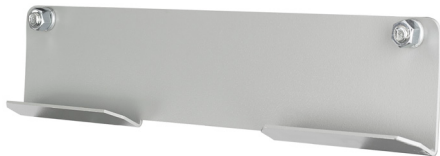

Features

- Weight rating: 250 lbs
- Equipment maximum depth: 21.5 inches
- 19U and 26U capacities, #12-24 threaded
- Rails extend 13 inches
- Perforated rear panel for mounting cable management and equipment
- Installation bracket mounts to wall first to ease mounting
- All doors have locking three-point latches to secure and seal

Specifications

- UL 1863 Listed, EIA-310-E Compliant
- Designed to meet NEMA 4/12 and 4X
- Tamper-Resistant per GR-CORE-63



Equipment slides out on industrial strength brackets for easy access



3-Door Rear Access Industrial RE-BOX®

Industrial RE-BOX® with 3-Door Rear Access

Includes: cabinet, perforated rear panel, slide out mounting rail, three doors with key locked twist handles

RU	Height	Width	Depth	Material	NEMA	Catalog No.
19	35.5"	23.9"	30.9"	Steel	4/12	IR323PG3
19	35.5"	23.9"	30.9"	Stainless Steel	4X	IR323PS3
26	47.8"	23.9"	30.9"	Steel	4/12	IR423PG3
26	47.8"	23.9"	30.9"	Stainless Steel	4X	IR423PS3



Universal Accessories

Description	Catalog No.
14" deep cantilevered shelf	MCCCS19
14" deep cantilevered shelf, perforated	MCCCS19P
11" perforated shelf	HSC11P




Cable Management Accessories

Description	Catalog No.
1RU horizontal cable manager, 3" deep	HS13C
2RU horizontal cable manager, 3" deep	HS23C
1RU plastic horizontal cable manager, 3" deep	HSD13
2RU plastic horizontal cable manager, 3" deep	HSD23
Screw mount VELCRO® fasteners, 10-pack of 9" straps	MCCMV9BS10



Dimensions

	IR323xx	IR423xx
A	35.5"	47.8"
B	23.9"	23.9"
C	30.9"	30.9"
D	16.0"	16.0"
E	25.5"	37.8"
F	23.7"	23.7"

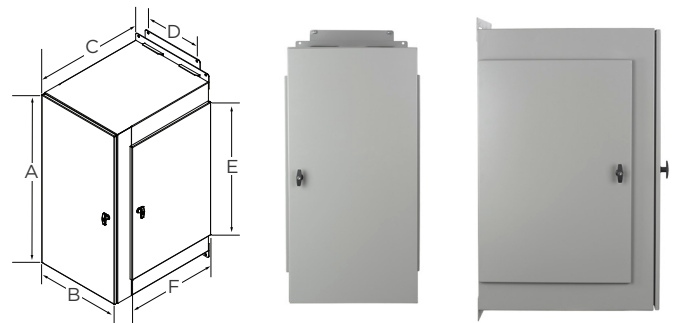

VELCRO® is a registered trademark of Velcro Industries B.V.



A proud member of the Hubbell family.

©2024 Wiring Device-Kellems. All rights reserved.
Hubbell and the Hubbell logo are registered trademarks or trademarks of Hubbell Incorporated. All other trademarks are the property of their respective owners.
40 Waterview Drive, Shelton, CT 06484
www.hubbell.com/wiringdevice-kellems | 800-288-6000

EP-WDK-SF-EN-02203 | 05/2024