


# IP69 Wash-Down Enclosures For Hygienic Applications




Built for the challenging demands of the food & beverage production environment, our new wall-mounted electrical enclosures stand up to rigorous washdown requirements. Constructed of 304 stainless steel, the design features sloped surfaces to shed water and minimize bacterial growth. It easily handles high temperatures, high pressure spray, and harsh cleaning chemicals.

## Features

- IP-69 compliant for high temperature and high pressure washdown
- External Silicone Gasket is high contrast blue and made from food-safe material
- Fully sloped design sheds water away from the enclosure
- Secondary gasketing for ultimate protection
- Internal hinges eliminate contamination points
- Reversible hinges for access convenience
- Hygienic door latch design sheds water and includes silicone gaskets

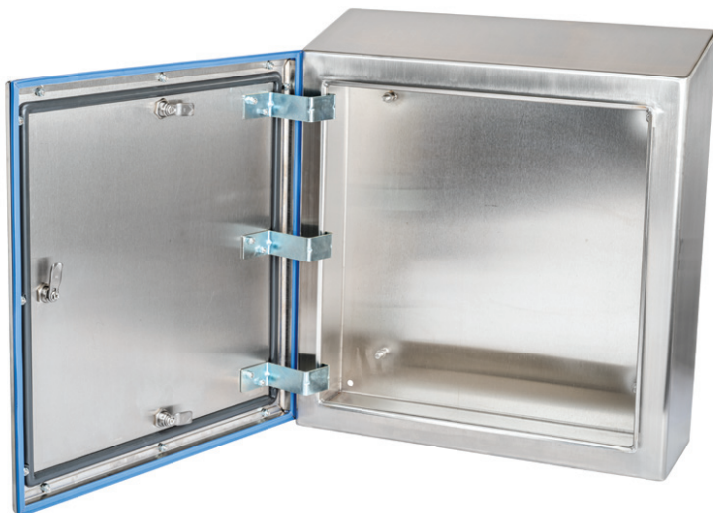

## PROTECT AGAINST

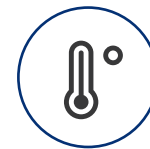

high temperature  
cleaning



high pressure  
cleaning



chemicals




weather

# IP69 Wash-Down Enclosures For Hygienic Applications

## Enclosures

## Back Panels

Catalog Number	Description	Dimensions (H X W X D)	Catalog Number		
			White	304 SS	Size (H X W)
<b>HYG161608SS</b>	HYG_SS 16X16X08 304SS	16 x 16 x 8 (406 x 406 x 203)	<b>HP1616</b>	<b>HP1616SS</b>	11.00 X 11.00 (279 X 279)
<b>HYG202008SS</b>	HYG_SS 20X20X08 304SS	20 x 20 x 8 (508 x 508 x 203)	<b>HP2020</b>	<b>HP2020SS</b>	15.00 X 15.00 (381 X 381)
<b>HYG202010SS</b>	HYG_SS 20X20X10 304SS	20 x 20 x 10 (508 x 508 x 254)	<b>HP2020</b>	<b>HP2020SS</b>	15.00 X 15.00 (381 X 381)
<b>HYG242408SS</b>	HYG_SS 24X24X08 304SS	24 x 24 x 8 (610 x 610 x 203)	<b>HP2424</b>	<b>HP2424SS</b>	19.00 X 19.00 (483 X 483)
<b>HYG242410SS</b>	HYG_SS 24X24X10 304SS	24 x 24 x 10 (610 x 610 x 254)	<b>HP2424</b>	<b>HP2424SS</b>	19.00 X 19.00 (483 X 483)
<b>HYG242412SS</b>	HYG_SS 24X24X12 304SS	24 x 24 x 12 (610 x 610 x 305)	<b>HP2424</b>	<b>HP2424SS</b>	19.00 X 19.00 (483 X 483)
<b>HYG362408SS</b>	HYG_SS 36X24X08 304SS	36 x 24 x 8 (914 x 610 x 203)	<b>HP3624</b>	<b>HP3624SS</b>	31.00 X 19.00 (787 X 483)
<b>HYG362410SS</b>	HYG_SS 36X24X10 304SS	36 x 24 x 10 (914 x 610 x 254)	<b>HP3624</b>	<b>HP3624SS</b>	31.00 X 19.00 (787 X 483)
<b>HYG362412SS</b>	HYG_SS 36X24X12 304SS	36 x 24 x 12 (914 x 610 x 305)	<b>HP3624</b>	<b>HP3624SS</b>	31.00 X 19.00 (787 X 483)
<b>HYG363010SS</b>	HYG_SS 36X30X10 304SS	36 x 30 x 10 (914 x 762 x 254)	<b>HP3630</b>	<b>HP3630SS</b>	31.00 X 25.00 (787 X 635)
<b>HYG363012SS</b>	HYG_SS 36X30X12 304SS	36 x 30 x 12 (914 x 762 x 305)	<b>HP3630</b>	<b>HP3630SS</b>	31.00 X 25.00 (787 X 635)
<b>HYG363016SS</b>	HYG_SS 36X30X16 304SS	36 x 30 x 16 (914 x 762 x 406)	<b>HP3630</b>	<b>HP3630SS</b>	31.00 X 25.00 (787 X 635)

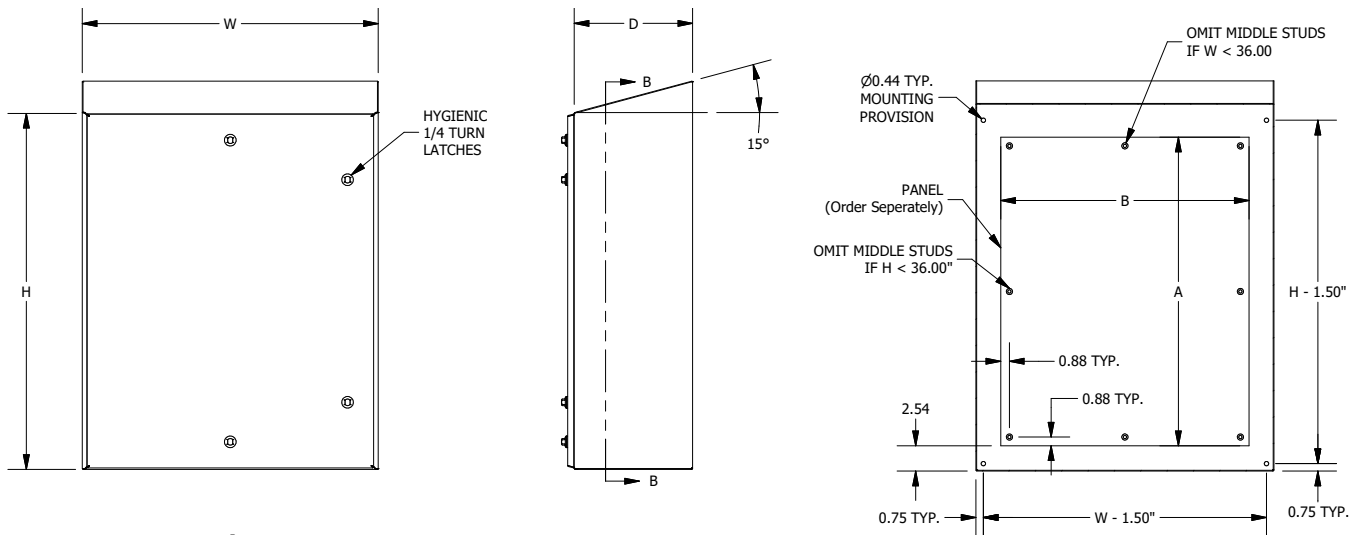

## Certifications/Standards

- UL508A Listed: Types 1, 3R, 4, 4X, 12
- cUL Listed per CSA C22.2 No. 14: Types 1, 3R, 4, 4X, 12
- NEMA/EEMAC Type 1, 3R, 4, 4X, 12
- EC 60529: IP69

Get protection beyond NEMA 4X! Contact your sales rep to find out more.



A proud member of the Hubbell family.

©2023 Wiegmann®. All rights reserved.  
 Hubbell and the Hubbell logo are registered trademarks  
 or trademarks of Hubbell Incorporated.  
 All other trademarks are the property of their respective owners.  
[hubbell.com/wiegmann/en](http://hubbell.com/wiegmann/en)  
 USA 618-539-3193 | Canada 905-839-1138 | Mexico 52-55-9151-9999

EP-WIEG-MULT-SF-EN-01046