


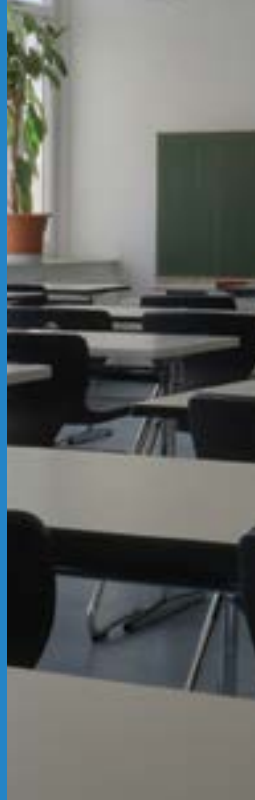

LJT
LED Troffer

LAW
LED Wraparound

LCS
LED Open Striplight



Three LED products that have it all.

- Simple fluorescent replacement
- Readily available in stock
- Affordably priced
- Long-life 60,000 hour LED at L80 lumen maintenance for reduced maintenance on site
- User friendly with access to LED boards and drivers from below
- Modular replacement of components
- Choice of LED color temperature
- Controls compatible
- Familiar shapes, sizes, and appearances for simplicity of use
- Integral battery pack option (1,400 lumens)

LED luminaires

LJT Troffer

- Replaces 1, 2, 3 and 4-lamp fluorescent troffers
- Up to 145 lumens per watt
- 1x4 Lumens: 2,255 up to 7,170
- 2x2 Lumens: 1,380 up to 4,715
- 2x4 Lumens: 2,560 up to 9,760
- 3000K, 3500K, 4000K, 5000K
- Recessed, surface, or cable
- Wet location and regressed aluminum door options available
- DLC® (DesignLights Consortium) Qualified, with some Premium Qualified configurations - see www.designlights.org



LAW LED Wraparound

- Replaces 1-lamp and 2-lamp fluorescent wraps
- Up to 128 lumens per watt
- 2' and 4'
- 2' lumens: from 2,685 up to 4,565
- 4' lumens: from 2,406 up to 7,074
- 3000K, 3500K, 4000K, 5000K
- Surface mount or suspended
- Lens hinges from either side for easy installation
- DLC® (DesignLights Consortium) Qualified - see www.designlights.org



LCS LED Striplight

- Replaces 1, 2, 3, 4, or 6-lamp fluorescent strips
- Up to 149 lumens per watt
- 2', 4' and 8'
- 2' Lumens: 3,041
- 4' Lumens: from 2,795 up to 11,334
- 8' lumens: from 5,590 up to 22,668
- 3000K, 3500K, 4000K, 5000K
- Surface mount or suspended
- Wire guard option
- DLC® (DesignLights Consortium) Qualified, with some Premium Qualified configurations - see www.designlights.org



ORDERING INFORMATION

LJT							
MODEL	COLOR TEMP	CEILING TYPE	SHIELDING	DRIVER	OPTIONS		
LJT LED Lensed Troffer	30 3000K 35 3500K 40 4000K 50 5000K	G Grid ¹ SM Surface Mount CM Cable Mount ²	A12 Pattern 12 Acrylic Lens A12125 Pattern 12 Acrylic Lens, 0.125" Nominal A12F Pattern 12 Frosted Acrylic Lens A12125F Pattern 12 Frosted Acrylic Lens, 0.125" Nominal A19 Pattern 19 Acrylic Lens, 0.156" Nominal A19F Pattern 19 Frosted Acrylic Lens .156"	E Fixed Output ED 0-10V Dimming ED1 0-10V 1% Dimming EDD 0-10V Dimming, Dim to Dark ⁴ ESD Step Dimming ^{6,5} LUTH Hi-lume 1% EcoSystem LED driver with Soft-on, Fade-to-Black dimming technology ^{4,5} LUTH5 5-Series EcoSystem LED driver ^{6,5}	ELL14 Emergency Battery Pack Installed, 1400 Lumens ^{5,6,7} GLR Fast Blow Fuse GTD Generator Transfer Device ^{5,8} DTS Dimming Bypass Module ^{5,9} C388 3-Wire Flex C488 4-Wire Flex C588 5-Wire Flex G1 Single Gasketing (Door to Housing) G2 Double Gasketing (G1 and Lens to Door) G3 Triple Gasketing (G2 and Housing to Ceiling) EOR End of Row (SM/CM only) ¹⁰ INT Intermediate (SM/CM only) ¹⁰ WL Wet Location (Select G2 or G3 Gasketing) ¹¹ CP Chicago Plenum		
SIZE	LUMEN OUTPUT	DOOR	VOLTAGE				
14 1' x 4' 22 2' x 2' 24 2' x 4'	XW Extra Low Watt (1x4, 2x4) VW Very Low Watt MW Medium Low Watt LW Low Watt ML Medium Lumen HL High Lumen VL Very High Lumen XL Extra High Lumen ⁵ (2x4 only) <i>See Product Availability table.</i>	FS White Flush Steel FA White Flush Aluminum RA Regressed Aluminum ³	U 120V-277V 347 347V				

ACCESSORIES (ORDER SEPARATELY)

- FK14 1' x 4' Single Flange Kit
- FK22 2' x 2' Single Flange Kit
- FK24 2' x 4' Single Flange Kit
- FKCR Flange Kit Row Adaptor (All Sizes)
- CM48Y2SC3F-KIT 48" Cable Mount Kit for 2' Wide CM Ceiling Type, 3 Wire Feed Cord
- CM48Y1SC3F-KIT 48" Cable Mount Kit for 1' wide Cable Mount Fixtures, 3-Wire

¹ For hard ceilings use flange kit accessory
² Order hanger accessories separately
³ Available on 2x2 and 2x4 only; on 2x4 RA increases fixture depth to 4 1/4"
⁴ Not available in all lumen packages, see specification sheet
⁵ Not available with 347V
⁶ For compatibility with Dual-Lite LiteGear® inverters in lieu of EL Battery Pack, contact Hubbell Lighting Representative
⁷ Not available with 1x4 or 2x2 surface or cable mount
⁸ Available for fixed output driver option only
⁹ For emergency circuit control loads including sensors and wireless systems listed to UL924. Only available with 0-10V driver
¹⁰ Provides ends with wiring access for continuous row mounting
¹¹ FA door and Grid Ceiling only
 Damp Label—standard. IC Rating—standard

PRODUCT AVAILABILITY

SIZE	LUMEN PACKAGE	LUMENS	WATTS	LPW
22	VW	1380-1570	13	105-120
	MW	1870-2130	18	103-117
	LW	2400-2740	24	102-116
	ML	3265-3720	31	104-119
	HL	3575-4070	33	109-125
24	VL	4140-4715	42	100-113
	XW	2560-2915	20	127-145
	VW	3340-3805	27	125-142
	MW	3770-4295	31	123-140
	LW	4140-4720	34	122-139
	ML	4580-5215	38	119-136
	HL	5285-6015	45	117-133
	VL	7190-8190	59	121-138
	XL	8570-9760	73	117-134

PRODUCT AVAILABILITY

SIZE	LUMEN PACKAGE	LUMENS	WATTS	LPW
14	XW	2255-2565	20	111-127
	VW	2835-3230	27	106-121
	MW	3330-3795	31	109-124
	LW	3655-4160	34	107-122
	ML	4035-4595	38	106-120
	HL	4620-5260	45	102-117
	VL	6300-7170	59	107-122

Based on A12 lens, range represents 3000K through 5000K.
 Lumens vary according to color temperatures and other factors. See specific photometric test(s).

LAW									
MODEL	SIZE	COLOR TEMP	LUMEN OUTPUT	DRIVER	VOLTAGE	OPTIONS			
LAW LED Wraparound	2 2' 4 4'	30 3000K 35 3500K 40 4000K 50 5000K	XW Extra Low Watt VW Very Low Watt MW Medium Low Watt LW Low Watt ML Medium Lumen HL High Lumen VL Very High Lumen	E Fixed Output ESD Step Dimming ED 0-10V Dimming LUTH Hi-lume 1% EcoSystem LED driver with Soft-on, Fade-to-Black dimming technology LUTH5 5-Series EcoSystem LED driver	U 120V-277V 347 347 (E,ED,ED1 only)	ELL14 Emergency Battery Pack Installed, 1400 Lumens ^{1,2} GLR Fast Blow Fuse PAF Paint After Fabrication NYC NYC Compliant			
ACCESSORIES (ORDER SEPARATELY)									
S18 18" Stem, Canopy								¹ For compatibility with Dual-Lite LiteGear® inverters in lieu of installed Battery Pack, contact Hubbell Lighting Representative.	
SS18 18" Swivel Stem—45° Swivel								² Only available in 4 ft.	

LCS									
MODEL	SIZE	COLOR TEMP	LUMEN OUTPUT	DRIVER	VOLTAGE	OPTIONS			
LCS LED Striplight	2 2' 4 4' 8 8'	30 3000K 35 3500K 40 4000K 50 5000K	LW Low Watt ML Medium Lumen HL High Lumen VL Very High Lumen	E Fixed Output ESD Step Dimming ³ ED 0-10V Dimming LUTH Hi-lume 1% EcoSystem LED driver with Soft-on, Fade-to-Black dimming technology LUTH5 5-Series EcoSystem LED driver	U 120V-277V 347 347 (E,ED only) 480 480V ⁴	ELL14 Emergency Battery Pack, 1400 Lumens ^{1,2} GLR Fast Blow Fuse PAF Paint After Fabrication			
ACCESSORIES (ORDER SEPARATELY)									
CSWG4 4' Wire Guard								¹ Not available in 2' size.	
S18 18" Stem, Canopy								² For compatibility with Dual-Lite LiteGear® inverters in lieu of installed Battery Pack, contact Hubbell Lighting Representative.	
SS18 18" Swivel Stem—45° Swivel								³ Only available in 4' ML, HL & VL packages.	
CSHC Chain Hanger Assembly								⁴ Consult factory for LW lumen package.	

