




**SEALING LOCKNUTS**

Sealing Locknuts Steel  
N/A

B38

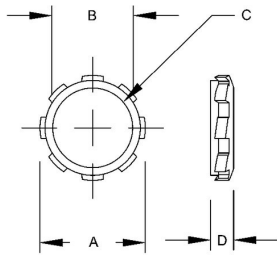

Catalog #: 1209

**APPLICATIONS**

For use on threaded rigid/IMC conduit to provide a liquidtight seal against water and oil  
RACO sealing locknuts may be used with either sheet metal or cast enclosures

**PRODUCT FEATURES**

- Fused-in-place gasket guarantees a liquidtight seal
- Use RACO sealing locknuts as an economical alternative to a threaded enclosure connector
- All steel construction insures mechanical protection
- Zinc electro plated for corrosion protection
- N/A

**UL LISTED**

Standard 514B (part numbers 1202-1210), UL File E195969

**CSA**

C22.2 No. 18 (part numbers 1202-1211)

**GENERAL PRODUCT INFORMATION**

Trade Size: 3 in.

**DRAWING DIMENSIONS**

- Dimension A: 4-3/16 in.
- Dimension B: 3-27/64 in.
- Thread Spec. C: 3 in. - 8 NPT
- Dimension D: 3/8 in.

**PACKAGING**

- Package Type: Carton
- Ship Carton Qty.: 25
- Product UPC-A Labeled: No
- Weight (Lbs. Per/C): 17.10
- Ship Carton Length (in.): 11.30
- Ship Carton Width (in.): 5.00
- Ship Carton Height (in.): 4.02
- Ctn Weight (Lbs.): 4.28
- UPC Number: 050169012093
- I2of5: 50050169012098