




SEALING LOCKNUTS

Sealing Locknuts Steel
N/A

B38

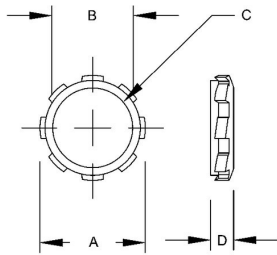

Catalog #: 1210

APPLICATIONS

For use on threaded rigid/IMC conduit to provide a liquidtight seal against water and oil
RACO sealing locknuts may be used with either sheet metal or cast enclosures

PRODUCT FEATURES

- Fused-in-place gasket guarantees a liquidtight seal
- Use RACO sealing locknuts as an economical alternative to a threaded enclosure connector
- All steel construction insures mechanical protection
- Zinc electro plated for corrosion protection
- N/A

UL LISTED

Standard 514B (part numbers 1202-1210), UL File E195969

CSA

C22.2 No. 18 (part numbers 1202-1211)

GENERAL PRODUCT INFORMATION

Trade Size: 3-1/2 in.

DRAWING DIMENSIONS

Dimension A: 4-11/16 in.
 Dimension B: 3-15/164 in.
 Thread Spec. C: 3-1/2 in. - 8 NPT
 Dimension D: 3/8 in.

PACKAGING

Package Type: Carton
 Ship Carton Qty.: 15
 Product UPC-A Labeled: No
 Weight (Lbs. Per/C): 22.20
 Ship Carton Length (in.): 5.98
 Ship Carton Width (in.): 5.63
 Ship Carton Height (in.): 5.98
 Ctn Weight (Lbs.): 3.34
 UPC Number: 050169012109
 I2of5: 50050169012104