




BONDING LOCKNUTS

Bonding Locknuts Steel
N/A

B37

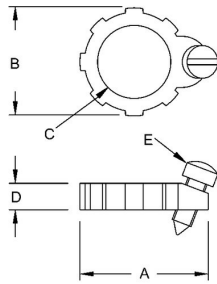

Catalog #: 1248

APPLICATIONS

For use on threaded rigid/IMC conduit
Use bonding locknuts when additional locking and grounding connections are required in applications where severe vibration is encountered

PRODUCT FEATURES

All steel construction insures mechanical protection
Zinc electro plated for corrosion protection
N/A

UL LISTED

Standard 514B, UL Listed E195975

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size: 2 in.

DRAWING DIMENSIONS

Dimension A: 3.09 in.
Dimension B: 2.73 in.
Thread Spec. C: 2 in. - 11-1/2 NPT
Dimension D: .26 in.
Dimension E: 8-24 x 1/2 in.

PACKAGING

Package Type: Carton
Ship Carton Qty.: 20
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 14.70
Ship Carton Length (in.): 6.25
Ship Carton Width (in.): 4.50
Ship Carton Height (in.): 4.25
Ctn Weight (Lbs.): 2.94
UPC Number: 050169012482
I2of5: 50050169012487