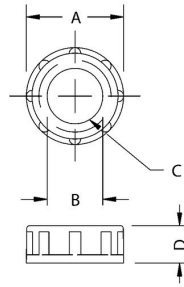


**INSULATING BUSHING****Insulating Bushings Polypropylene**
N/A**B39**

Catalog #: 1402

APPLICATIONS

For use on threaded rigid/IMC conduit
RACO bushings provide a smooth rounded surface at the entrance of raceways

PRODUCT FEATURES

Insulating bushings are made of high impact polypropylene that is temperature rated at 105 degrees Celsius
N/A

UL LISTED

Standard 514B, UL File E195973

GENERAL PRODUCT INFORMATION

Trade Size: 1/2 in.

DRAWING DIMENSIONS

Dimension A: 1-1/16 in.
Dimension B: 19/32 in.
Thread Spec. C: 1/2 in. - 14 NPT
Dimension D: 23/64 in.

PACKAGING

Package Type: Carton
Std. Pkg.: 100
Ship Carton Qty.: 400
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 0.70
Ship Carton Length (in.): 13.00
Ship Carton Width (in.): 10.75
Ship Carton Height (in.): 6.13
Ctn Weight (Lbs.): 2.80
UPC Number: 050169014028
I2of5: 50050169014023