




FLEXIBLE METAL COMBINATION COUPLINGS

Flex to Rigid/IMC Couplings, Threaded/Squeeze Malleable Iron
N/A

B66.1

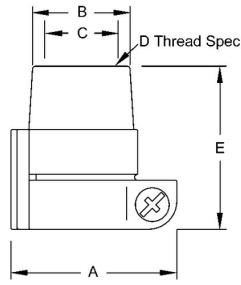

Catalog #: 1554

APPLICATIONS

For use when coupling flexible metal conduit to threaded Rigid/IMC conduit
N/A

PRODUCT FEATURES

All malleable iron construction insures mechanical protection for the raceway
All components are zinc electro plated for corrosion protection

UL LISTED

Listed

CULUS

UL File E195969

GENERAL PRODUCT INFORMATION

Trade Size: 1 in.

DRAWING DIMENSIONS

Dimension A:	2-5/16 in.
Dimension B:	1-21/32 in.
Dimension C:	1-7/32 in.
Thread Spec. D:	1 in. - 11-1/2 NPT
Dimension E:	1-53/64 in.

PACKAGING

Package Type:	Carton
Ship Carton Qty.:	25
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	34.00
Ship Carton Length (in.):	10.50
Ship Carton Width (in.):	7.50
Ship Carton Height (in.):	3.00
Ctn Weight (Lbs.):	8.50
UPC Number:	050169015544
I2of5:	50050169015549