




RIGID THREADED HUBS - DIE CAST ZINC

Conduit Hub, Insulated Throat Die Cast Zinc
N/A

B33

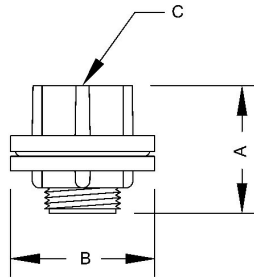

Catalog #: 1710

APPLICATIONS

For use with threaded rigid/IMC conduit to connect and bond conduit to a threadless opening in a box or enclosure
May be used in wet or dry locations

PRODUCT FEATURES

Rugged metallic construction insures mechanical protection
Insulated throat protects wires and reduces wire pulling effort
O-ring seals the assembly and provides a raintight seal
N/A

UL LISTED

Standard 514B, UL Listed E195969

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size: 2-1/2 in.

DRAWING DIMENSIONS

Dimension A: 2.605 in.
Dimension B: 3.708 in.
Dimension C: 2-1/2 in. - 8 NPT

PACKAGING

Package Type: Carton
Ship Carton Qty.: 5
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 176.60
Ship Carton Length (in.): 10.60
Ship Carton Width (in.): 5.90
Ship Carton Height (in.): 4.70
Ctn Weight (Lbs.): 8.83
UPC Number: 050169017104
I2of5: 50050169017109