




0° 1-Position Cutout / Arrester Standoff Bracket (No Hardware), 12"

by CHANCE Utility
Catalog ID: 1SBM12SGL

12" Medium Duty Fiberglass 0° 1-Position Cutout / Arrester Standoff Bracket (No Hardware)

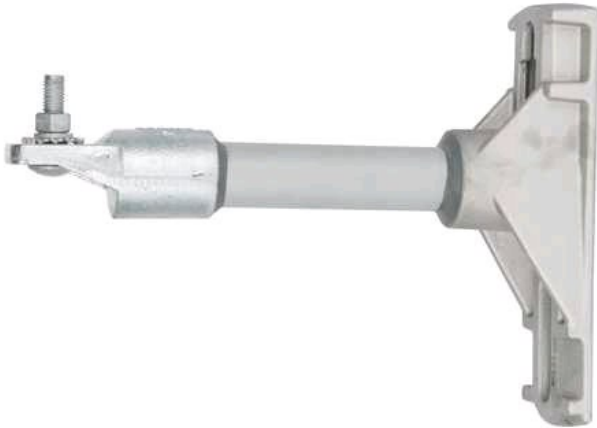

* Representative image

Product Details

General

Description - End Fitting	1 Position Apparatus Mount
Strength Rating - Minimum Ultimate, Longitudinal (L)	900 lb
Strength Rating - Minimum Ultimate, Transverse (T)	5,000 lb
Strength Rating - Minimum Ultimate, Vertical (V)	2,100 lb
UPC	096359474890

Dimensions

Diameter - Rod / Tube	1.5 in
Distance From Pole	12 in
Length	12.00 in
Mounting Bolt Spacing	<ul style="list-style-type: none"> • 6.00 in • 8.00 in
Weight	4.6 lb

Electrical Ratings

Phase	1-Phase
-------	---------

Logistics

Pallet Quantity	72 EA
Standard Package	1

For further technical assistance, please contact us

Domestic Customer Service

Hubbell Power Systems
210 N. Allen Centralia, MO 65240 USA
Phone: (573) 682-5521
Fax: (573) 682-8475
Email: hpscsc@hubbell.com

International Customer Service

Phone: +1-573-682-5521
Fax: +1-573-682-8516
Email: hpsintlcs@hubbell.com