


0° 1-Position Cutout / Arrester Standoff Bracket w/ Hardware, 15"

by CHANCE Utility
Catalog ID: 1SBM15SGLB

15" Medium Duty Fiberglass 0° 1-Position Cutout / Arrester Standoff Bracket w/ Hardware

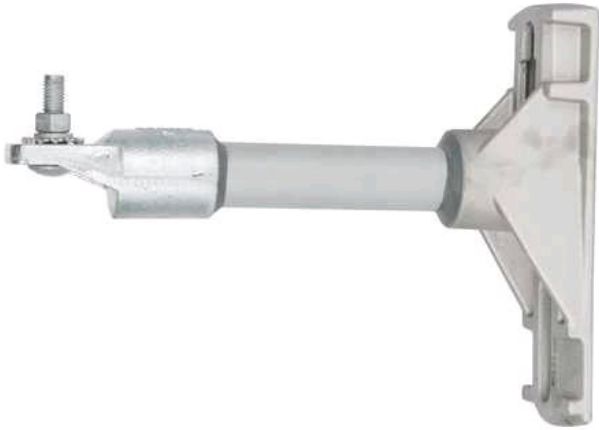

* Representative image

Product Details

General

Description - End Fitting	1 Position Apparatus Mount
Strength Rating - Minimum Ultimate, Longitudinal (L)	800 lb
Strength Rating - Minimum Ultimate, Transverse (T)	5,000 lb
Strength Rating - Minimum Ultimate, Vertical (V)	1,800 lb
UPC	096359467960

Dimensions

Diameter - Rod / Tube	1.5 in
Distance From Pole	15 in
Length	15.00 in
Mounting Bolt Spacing	<ul style="list-style-type: none"> • 6.00 in • 8.00 in
Weight	5.0 lb

Electrical Ratings

Phase	1-Phase
-------	---------

Logistics

Carton Quantity	5 EA
Pallet Quantity	120 EA
Standard Package	1

For further technical assistance, please contact us

Domestic Customer Service

Hubbell Power Systems
210 N. Allen Centralia, MO 65240 USA
Phone: (573) 682-5521
Fax: (573) 682-8475
Email: hpscsh@hubbell.com

International Customer Service

Phone: +1-573-682-5521
Fax: +1-573-682-8516
Email: hpsintlcs@hubbell.com