


0° 2-Position Cutout / Arrester Standoff Bracket w/ Hardware & Spacer Bar, 18"

by CHANCE Utility
Catalog ID: 1SBM18SGLSB

18" Medium Duty Fiberglass 0° 1-Position Cutout / Arrester Standoff Bracket w/ Hardware & Spacer Bar

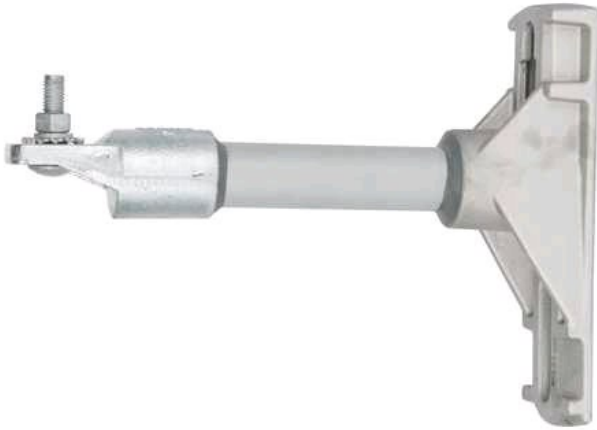

* Representative image

Product Details

General

Description - End Fitting	1 Position Apparatus Mount
Strength Rating - Minimum Ultimate, Longitudinal (L)	700 lb
Strength Rating - Minimum Ultimate, Transverse (T)	5,000 lb
Strength Rating - Minimum Ultimate, Vertical (V)	1,500 lb
UPC	096359509028

Dimensions

Diameter - Rod / Tube	1.5 in
Distance From Pole	18 in
Length	18.00 in
Mounting Bolt Spacing	<ul style="list-style-type: none"> • 6.00 in • 8.00 in
Weight	5.4 lb

Electrical Ratings

Phase	1-Phase
-------	---------

Logistics

Carton Quantity	7 EA
Pallet Quantity	168 EA
Standard Package	1

For further technical assistance, please contact us

Domestic Customer Service

Hubbell Power Systems
210 N. Allen Centralia, MO 65240 USA
Phone: (573) 682-5521
Fax: (573) 682-8475
Email: hpscshubbell.com

International Customer Service

Phone: +1-573-682-5521
Fax: +1-573-682-8516
Email: hpsintlcs@hubbell.com