




SINGLE GANG NON-METALLIC CABLE BOXES - BRACKETED

Single-gang with Brackets for Metal or Wood Studs - For Nonmetallic sheathed Cable
2-3/4 in. Deep, 18.0 Cu. in., 1/2 in. Setback, Bracket, Ground Screw

A77

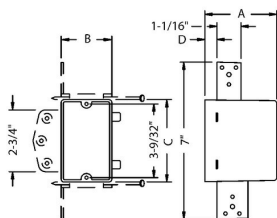

Catalog #: 2001RAC

APPLICATIONS

RACO[®] Nonmetallic cable boxes are used in branch circuit wiring to splice wires
Accommodates wiring devices such as switches and receptacles
Provide excellent protection for wiring system or devices

PRODUCT FEATURES

RACO[®] Nonmetallic cable boxes provide the installer with a cost alternative that is lightweight and easy to install
Single-gang boxes have knockouts that break out quickly and cleanly for faster installation
Positioning tabs for fast accurate mounting on studs or joists
N/A

CSA

CSA Listed

COMPLIANCES

Boxes are listed for Applications (Electrical Codes), UL Green Book
Boxes are listed for mechanical properties, including the 2-hour Fire Rating, (building codes) UL Orange Book
Federal Manufacturer's number 28488

FIRE RESISTANCE

2-hour fire rating, UL Orange Book

US PATENTS

4,580,689; 4,666,055

OTHER PATENTS

Canada 1,237,515; 1,260,599

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable
Color: Yellow

CONFIGURATION

Cable Knockouts(s): 4
Bracket Type: Flush
Bracket Setback: 1/2 in.

DRAWING DIMENSIONS

Dimension A: 2-3/4 in.
Dimension C: 3-21/32 in.
Dimension D: 1/2 in.

PRODUCT MEASUREMENTS

Depth: 2-3/4 in.
Cubic Inches (cm³): 18.0 (295.0)
Wt. Ea. (Lbs.): 0.208
Product Length (in.): 2.81
Product Width (in.): 2.90
Product Height (in.): 6.30

PACKAGING

Minimum Pack Qty.: 50
Std. Pkg.: 50
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 20.80
Ship Carton Length (in.): 21.75
Ship Carton Width (in.): 6.25
Ship Carton Height (in.): 13.88

Ctn Weight (Lbs.):	10.40
Pallet Qty:	2100
UPC Number:	805035049860
I2of5:	30805035049861