




EMT 90 DEGREE SHORT ANGLE CONNECTORS

90 Degree, Uninsulated Short Compression Connector Malleable Iron
N/A

B17

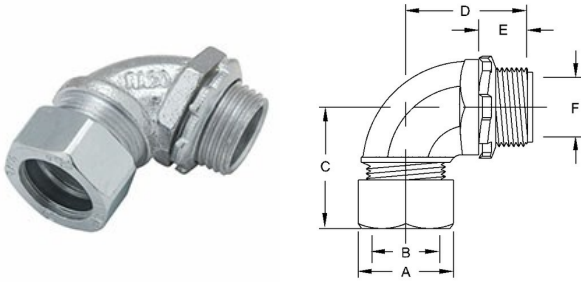

Catalog #: 2072

APPLICATIONS

To bond EMT conduit to a box or enclosure
Use RACO 90 degree short angle connectors when bending conduit is not practical

PRODUCT FEATURES

Malleable construction insures mechanical protection for the raceway
Hex compression nuts assure easy wrench installation
All components are zinc electroplated for corrosion protection
N/A

UL LISTED

Standard 514B

GENERAL PRODUCT INFORMATION

Trade Size: 1/2 in.

DRAWING DIMENSIONS

Dimension A: 1-1/8 in.
Dimension B: 23/32 in.
Dimension C: 1-9/32 in.
Dimension D: 1-7/32 in.
Dimension E: 1/2 in.
Thread Spec. E: 1/2 in. - 14 NPT
Dimension F: 5/8 in.

PACKAGING

Package Type: Carton
Std. Pkg.: 25
Ship Carton Qty.: 100
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 18.10
Ship Carton Length (in.): 18.00
Ship Carton Width (in.): 5.00
Ship Carton Height (in.): 6.25
Ctn Weight (Lbs.): 18.10
UPC Number: 050169020722
I2of5: 50050169020727