




**CONDUIT CLAMPS**

**Right Angle Clamp Galvanized Malleable Iron**  
N/A

**B85**

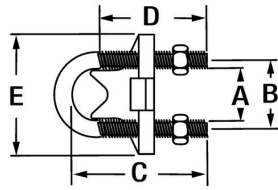

Catalog #: 2353RC

**APPLICATIONS**

To secure Rigid/IMC or EMT conduit across, parallel, or perpendicular to channel, beam, and angle supports  
N/A

**PRODUCT FEATURES**

- Three styles meet every installation need
- Heavy duty U-bolts, hex bolts and hex nuts
- Capable of supporting heavy loads
- Hot dipped galvanized malleable iron construction provides excellent weatherability and corrosion protection
- Perfect for commercial construction applications

**CULUS**

UL Listed E195968

**GENERAL PRODUCT INFORMATION**

Trade Size: 3/4 in.

**DRAWING DIMENSIONS**

Dimension A: 1-1/8 in.  
 Dimension B: 1-3/8 in.  
 Dimension C: 2-13/16 in.  
 Dimension D: 1-13/16 in.  
 Dimension E: 2-1/4 in.

**PACKAGING**

Package Type: Carton  
 Ship Carton Qty.: 50  
 Product UPC-A Labeled: No  
 Weight (Lbs. Per/C): 38.60  
 Ship Carton Length (in.): 10.00  
 Ship Carton Width (in.): 10.00  
 Ship Carton Height (in.): 5.00  
 Ctn Weight (Lbs.): 19.30  
 UPC Number: 050169986219  
 I2of5: 50050169986214