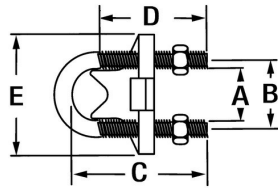


CONDUIT CLAMPS
Right Angle Clamp Galvanized Malleable Iron
 N/A

B85


Catalog #: 2364RC

APPLICATIONS

 To secure Rigid/IMC or EMT conduit across, parallel, or perpendicular to channel, beam, and angle supports
 N/A

PRODUCT FEATURES

 Three styles meet every installation need
 Heavy duty U-bolts, hex bolts and hex nuts
 Capable of supporting heavy loads
 Hot dipped galvanized malleable iron construction provides excellent weatherability and corrosion protection
 Perfect for commercial construction applications

CULUS

UL Listed E195968

GENERAL PRODUCT INFORMATION

Trade Size: 3-1/2 in.

DRAWING DIMENSIONS

 Dimension A: 4 in.
 Dimension B: 4-9/16 in.
 Dimension C: 5-7/8 in.
 Dimension D: 2-5/8 in.
 Dimension E: 5-5/8 in.

PACKAGING

 Package Type: Carton
 Ship Carton Qty.: 5
 Product UPC-A Labeled: No
 Weight (Lbs. Per/C): 136.00
 Ship Carton Length (in.): 9.00
 Ship Carton Width (in.): 7.00
 Ship Carton Height (in.): 5.00
 Ctn Weight (Lbs.): 6.80
 UPC Number: 050169986288
 I2of5: 50050169986283