




CONDUIT CLAMPS

Right Angle Clamp Galvanized Malleable Iron
N/A

B85

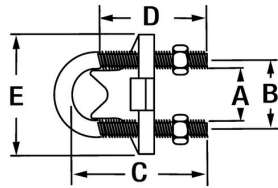

Catalog #: 2366RC

APPLICATIONS

To secure Rigid/IMC or EMT conduit across, parallel, or perpendicular to channel, beam, and angle supports
N/A

PRODUCT FEATURES

- Three styles meet every installation need
- Heavy duty U-bolts, hex bolts and hex nuts
- Capable of supporting heavy loads
- Hot dipped galvanized malleable iron construction provides excellent weatherability and corrosion protection
- Perfect for commercial construction applications

CULUS

UL Listed E195968

GENERAL PRODUCT INFORMATION

Trade Size: 4 in.

DRAWING DIMENSIONS

- Dimension A: 4-11/16 in.
- Dimension B: 5-1/16 in.
- Dimension C: 6-11/16 in.
- Dimension D: 2-5/8 in.
- Dimension E: 6-1/8 in.

PACKAGING

- Package Type: Carton
- Ship Carton Qty.: 5
- Product UPC-A Labeled: No
- Weight (Lbs. Per/C): 163.40
- Ship Carton Length (in.): 9.00
- Ship Carton Width (in.): 7.00
- Ship Carton Height (in.): 5.00
- Ctn Weight (Lbs.): 8.17
- UPC Number: 050169986295
- I2of5: 50050169986290