


## 4 IN. SQUARE WELDED BOXES - 2-1/8 IN. DEEP WITH ARMORED CABLE / METAL CLAD / FLEX CLAMPS

4 in. Square Welded Boxes - 2-1/8 in. Deep with Armored Cable / Metal Clad / Flex Clamps  
4 Square Box 2-1/8 in. Deep- Welded with (2) STAB-IT Connectors on Top  
600V, 8" #12 Solid Copper Pigtail

A18

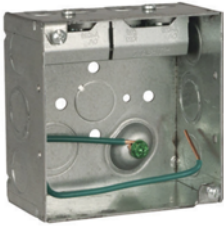

Catalog #: 244S

### APPLICATIONS

RACO® STABIT boxes are great for any job where flexible armored cable is being used  
RACO® Boxes are installed in walls or ceilings for lighting fixtures, switches or receptacles

### PRODUCT FEATURES

Designed for quick installation of flex, MC, MCI, MCI-A, AC, and HCF Cable  
TKO® Knockouts offer greater flexibility with RACO patented combination 1/2 in. and 3/4 in. knockout

### UL LISTED

File E195978

### COMPLIANCES

All RACO® single gang, two gang, 4 in. square, and single gang UL listed steel boxes are acceptable for use in 2-hour fire rated walls. For additional information, consult UL "Fire Resistance Directory" or the UL website at [www.ul.com](http://www.ul.com)  
600V Per UL 514-A, suitable for use without a bonding jumper in circuits up to 600 volts  
MSDS  
[www.hubbell-rtb.com/certifications/Hubbell-RACO\\_MSDS\\_for\\_Steel\\_Boxes\\_and\\_Covers.pdf](http://www.hubbell-rtb.com/certifications/Hubbell-RACO_MSDS_for_Steel_Boxes_and_Covers.pdf)

### FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

### GENERAL PRODUCT INFORMATION

Wiring System: Armored Cable/Metal Clad/MCI-A/Flex

### CONFIGURATION

Cable Priorts: 4  
Bracket Type: No Bracket  
Drawn or Welded: Welded  
Raised Ground: Yes  
Side Knockout(s): (4) 1/2 in., (2) 1/2 in. - 3/4 in. TKO  
Bottom Knockouts(s): (1) 1/2 in., (1) 1/2 in. - 3/4 in. TKO

### PRODUCT MEASUREMENTS

Depth: 2-1/8 in.  
Cubic Inches (cm3): 30.3 (496.5)  
Wt. Ea. (Lbs.): 1.027  
Product Length (in.): 2.188  
Product Width (in.): 4.00  
Product Height (in.): 4.00

### PACKAGING

Minimum Pack Qty.: 25  
Std. Pkg.: 25  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 105.828  
Ship Carton Length (in.): 18.750  
Ship Carton Width (in.): 7.375  
Ship Carton Height (in.): 8.50  
Ctn Weight (Lbs.): 26.457  
Pallet Qty: 1750  
UPC Number: 050169982440  
I2of5: 50050169982445