



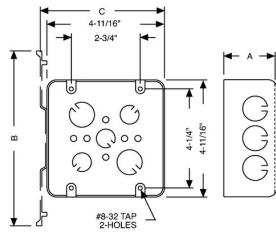

## 4-11/16 IN. SQUARE WELDED BOXES 2-1/8 IN. WITH CONDUIT KO'S

4-11/16 in. Square Bracketed Boxes, 2-1/8 in. Deep - Welded with Conduit KO's  
600V, Raised Ground, 10 in. #12 Stranded Copper Pigtail, UBS, HM

A26

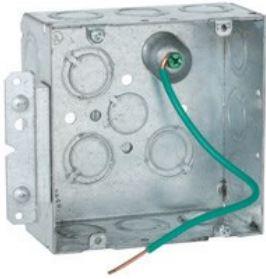

Catalog #: 257HS

### APPLICATIONS

RACO® 4-11/16" Boxes are used for a wide variety of industrial applications where larger sized conductors or wiring devices are needed and more volume is required  
N/A

### PRODUCT FEATURES

Reference the Box Selection section in the front of this catalog for complete description of bracket types and features  
Combination screw heads provide for faster installation  
TKO knockouts allow for design and installation flexibility  
UBS Support - Welded to box, preset bend points to work with wall thickness 2-1/2" to 6"

### UL LISTED

File E195978

### COMPLIANCES

600V Per UL 514-A, suitable for use without a bonding jumper in circuits up to 600 volts

### GENERAL PRODUCT INFORMATION

Wiring System: Conduit

### CONFIGURATION

Bracket Type: H, for Metal or Wood Studs  
Bracket Setback: 3/8 in.  
Drawn or Welded: Welded  
Raised Ground: Yes  
Side Knockout(s): (12) TKO®  
Bottom Knockouts(s): (1) 1/2 in. & (3) TKO®

### DRAWING DIMENSIONS

Dimension A: 2-1/8 in.  
Dimension C: 5-5/8 in.

### PRODUCT MEASUREMENTS

Depth: 2-1/8 in.  
Cubic Inches (cm3): 42.0 (688.2)  
Wt. Ea. (Lbs.): 1.096  
Product Length (in.): 2.75  
Product Width (in.): 4.69  
Product Height (in.): 5.60

### PACKAGING

Minimum Pack Qty.: 20  
Std. Pkg.: 20  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 109.60  
Ship Carton Length (in.): 18.13  
Ship Carton Width (in.): 7.88  
Ship Carton Height (in.): 11.63  
Ctn Weight (Lbs.): 21.92  
Pallet Qty: 1080  
UPC Number: 050169500392  
I2of5: 50050169500397