




RIGID HANDY ELLS - DIE CAST ZINC

90 Degree Threaded Handy Ells Female-Female Die Cast Zinc
N/A

B29

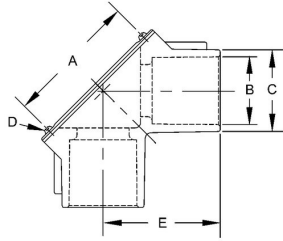

Catalog #: 2653

APPLICATIONS

For use to couple two ends of rigid/IMC conduit
Use handy ells when bending conduit is not practical

PRODUCT FEATURES

N/A

UL LISTED

Standard 514B, UL Listed E195969

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size: 3/4 in.

DRAWING DIMENSIONS

Dimension A:	1-13/16 in.
Dimension B:	3/4 in. - 14 NPSM
Dimension C:	1-15/64 in.
Dimension D:	8 - 32 x 1/4 in.
Dimension E:	1-13/32 in.

PACKAGING

Package Type:	Carton
Std. Pkg.:	5
Ship Carton Qty.:	50
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	30.00
Ship Carton Length (in.):	19.00
Ship Carton Width (in.):	10.63
Ship Carton Height (in.):	4.13
Ctn Weight (Lbs.):	15.55
UPC Number:	050169026533
I2of5:	50050169026538