




**RIGID HANDY ELLS - DIE CAST ZINC**

**90 Degree Threaded Handy Ells Female-Female Die Cast Zinc**  
N/A

**B29**

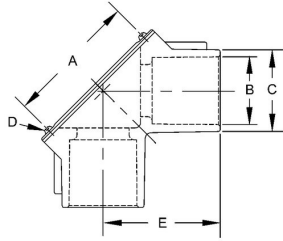

Catalog #: 2654

**APPLICATIONS**

For use to couple two ends of rigid/IMC conduit  
Use handy ells when bending conduit is not practical

**PRODUCT FEATURES**

N/A

**UL LISTED**

Standard 514B, UL Listed E195969

**CSA**

C22.2 No. 18

**GENERAL PRODUCT INFORMATION**

Trade Size: 1 in.

**DRAWING DIMENSIONS**

Dimension A: 2-51/64 in.  
Dimension B: 1 in. - 11-1/2 NPSM  
Dimension C: 1-35/64 in.  
Dimension D: 8 - 32 x 1/4 in.  
Dimension E: 1-27/32 in.

**PACKAGING**

Package Type: Carton  
Ship Carton Qty.: 25  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 62.00  
Ship Carton Length (in.): 8.68  
Ship Carton Width (in.): 8.70  
Ship Carton Height (in.): 6.20  
Ctn Weight (Lbs.): 15.50  
UPC Number: 050169026540  
I2of5: 50050169026545