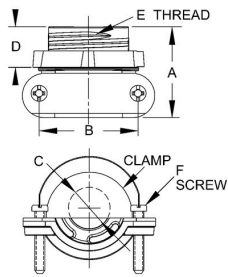


**NM CLAMP TYPE CONNECTORS**Clamp Type Cable Connectors Die Cast Zinc  
N/A**B77**

Catalog #: 2661

**APPLICATIONS**

- For use in dry locations to bond flexible metal conduit to a box or enclosure
- N/A
- For use in dry locations to bond armored cable to a box or enclosure
- For use in dry locations to bond MC/MCI cable to a box or enclosure
- For use in dry locations to connect Nonmetallic Sheathed Cable (NMSC) to a box or enclosure

**PRODUCT FEATURES**

- Rugged metallic construction insures mechanical protection for the raceway
- Rugged metallic construction will last the lifetime of the installation

**UL LISTED**

Standard 514B, UL File E195972

**CULUS**

Standard 514B, UL File E195969

**CSA**

C22.2 No. 18

**GENERAL PRODUCT INFORMATION**

Trade Size: 3/8 in.

**DRAWING DIMENSIONS**

Dimension A: 27/32 in.  
 Dimension B: 7/8 in.  
 Dimension C: 23/64 in.  
 Thread Spec. C: 3/8 in.  
 Dimension D: 1/2 - 14 NPSM  
 Dimension E: 8-32 x 3/4 in.

**PACKAGING**

Package Type: Carton  
 Std. Pkg.: 100  
 Ship Carton Qty.: 1000  
 Product UPC-A Labeled: No  
 Weight (Lbs. Per/C): 4.70  
 Ship Carton Length (in.): 18.89  
 Ship Carton Width (in.): 10.59  
 Ship Carton Height (in.): 6.81  
 Ctn Weight (Lbs.): 47.00  
 UPC Number: 050169026618  
 I2of5: 50050169026613